



112 LOOP HANGER WITH FLARED EDGES



CERTIFICATIONS



FEATURES

For steel and CPVC pipe

Flared edges help to protect plastic pipe

An integral fold-over washer (pipe sizes 2 1/2" to 8")

SPECIFICATIONS


Finish: Electrogalvanized

Material: Steel

Catalog Number	Item Name	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size(RS)	A	B	C	Static Load(F)	Certifications
1120050E G		1/2"	15	21 mm	3/8"	70.70 mm	29.2 mm	26.2 mm	1,334 N	cUL, UL
1120075E G		3/4"	20	27 mm	3/8"	76.40 mm	32.2 mm	26.5 mm	1,334 N	cUL, FM, UL
1120100E G		1"	25	34 mm	3/8"	83.70 mm	36.2 mm	27.1 mm	1,334 N	cUL, FM, UL
1120125E G		1 1/4"	32	43 mm	3/8"	92.10 mm	40.2 mm	26.7 mm	1,334 N	cUL, FM, UL

Catalog Number	Item Name	Pipe Size	NB/DN	Outer Diameter (OD)	Rod Size(RS)	A	B	C	Static Load(F)	Certifications
1120150EG		1 1/2"	40	48 mm	3/8"	98.20 mm	43.2 mm	26.7 mm	1,334 N	cUL, FM, UL
1120200EG		2"	50	60 mm	3/8"	110.20 mm	49.2 mm	26.7 mm	1,334 N	cUL, FM, UL
1120250EG		2 1/2"	65	76 mm	3/8"	138.20 mm	70.2 mm	41.3 mm	2,340 N	cUL, FM, UL
1120300EG		3"	80	89 mm	3/8"	154.10 mm	78.2 mm	41.4 mm	2,340 N	cUL, FM, UL
1120400EG		4"	100	114 mm	3/8"	193.80 mm	105.2 mm	55.7 mm	3,780 N	cUL, FM, UL
112M005OEG	297860	1/2"	15	21.3 mm	M10	70.70 mm	29.2 mm	26.2 mm	1,330 N	cUL, UL
1120500EG		5"	125	140 mm	1/2"	236.20 mm	125.9 mm	65.4 mm	3,780 N	cUL, FM, UL
1120600EG		6"	150	165 mm	1/2"	262.70 mm	138.9 mm	64.9 mm	3,500 N	cUL, FM, UL
1120800EG		8"	200	219 mm	1/2"	337.60 mm	187.9 mm	88.5 mm	6,000 N	cUL, FM, UL
112B0500EG		5"	125	141 mm	1/2"	236.20 mm	125.9 mm	65.4 mm	4,440 N	
112B0600EG		6"	150	165 mm	1/2"	262.70 mm	138.9 mm	64.9 mm	4,440 N	
112B0800EG		8"	200	219 mm	1/2"	337.60 mm	187.9 mm	88.5 mm	4,440 N	
112M0075EG	297870	3/4"	20	26.9 mm	M10	76.40 mm	32.2 mm	26.5 mm	1,330 N	cUL, FM, UL
112M010OEG	297880	1"	25	26.9 mm	M10	83.80 mm	36.2 mm	27.1 mm	1,330 N	cUL, FM, UL
112M0125EG	297890	1 1/4"	32	42.4 mm	M10	92.10 mm	40.2 mm	26.7 mm	1,330 N	cUL, FM, UL
112M015OEG	297900	1 1/2"	40	48.3 mm	M10	98.20 mm	43.2 mm	26.7 mm	1,330 N	cUL, FM, UL
112M020OEG	297910	2"	50	60.3 mm	M10	110.20 mm	49.2 mm	26.7 mm	1,330 N	cUL, FM, UL
112M025OEG	297920	2 1/2"	65	76.1 mm	M10	138.20 mm	70.2 mm	41.3 mm	2,340 N	cUL, FM, UL
112M030OEG	297930	3"	80	88.9 mm	M10	154.10 mm	78.2 mm	41.4 mm	2,340 N	cUL, FM, UL
112M040OEG	297940	4"	100	114.3 mm	M10	193.80 mm	105.2 mm	55.7 mm	2,890 N	cUL, FM, UL
112M060OEG	297960	6"	150	165 mm	M12	262.70 mm	138.9 mm	64.9 mm	4,450 N	cUL, FM, UL
112M050OEG	297950	5"	125	141 mm	M12	236.20 mm	125.9 mm	65.4 mm	2,890 N	cUL, FM, UL
112M080OEG	297970	8"	200	219.1 mm	M12	337.60 mm	187.9 mm	88.5 mm	6,000 N	cUL, FM, UL

DIAGRAMS

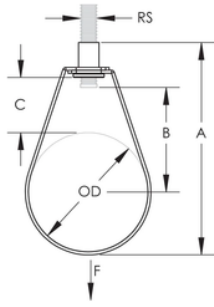

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER