



COPPER GROUND PLATE

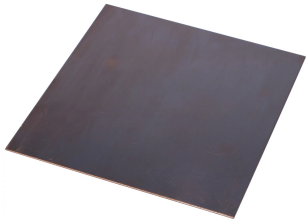

DIAGRAMS

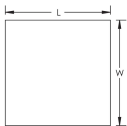

FEATURES

Provides a large surface area to dissipate current into the ground

Available in a variety of sizes and pigtail configurations

SPECIFICATIONS

Finish Bare
Material Copper

Catalog Number	Item Name	Width	Length	Pigtail Connection	Thickness
710190	710190	600 mm	600 mm	None	1.50 mm
504590	504590	900 mm	900 mm	None	3 mm
710200	710200	600 mm	600 mm	None	3 mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.