




## 4G24 TWIST CLIP WITH STUD

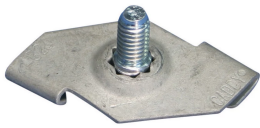

### CERTIFICATIONS



### FEATURES

Supports electrical fixtures from acoustical T-grid

No tools required for installation

Fast, easy and secure twist-on installation

Designed to reduce scratching of T-grid

Nut sold separately


### SPECIFICATIONS

**Material** Spring Steel;Steel

Catalog Number	Item Name	Finish	Color	Screw Length(L)	Flange Thickness(F T)	T-Grid Size	Screw Diameter(Sc)	Static Load(F)	Packing Quantity
4G24M11	171680	nVent CADDY Armour	Gray	11 mm	1.5 mm	24 mm	M6	220 N	1.0000
4G24M11 WH	171840	Painted	White	11 mm	1.5 mm	24 mm	M6	220 N	1.0000

Catalog Number	Item Name	Finish	Color	Screw Length(L)	Flange Thickness(F T)	T-Grid Size	Screw Diameter(Sc)	Static Load(F)	Packing Quantity
4G24M16	171710	nVent CADDY Armour	Gray	16 mm	1.5 mm	24 mm	M6	220 N	1.0000
4G24M16 WH	171860	Painted	White	16 mm	1.5 mm	24 mm	M6	220 N	1.0000
4G24M16 WHSP25	172290	Painted	White	16 mm	1.5 mm	24 mm	M6	220 N	1.0000
4G24M25	171730	nVent CADDY Armour	Gray	25 mm	1.5 mm	24 mm	M6	220 N	1.0000
4G24M25 WHSP25	172300	Painted	White	25 mm	1.5 mm	24 mm	M6	220 N	1.0000

## DIAGRAMS

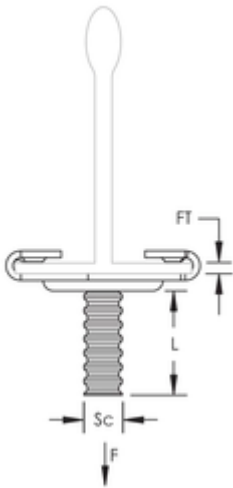

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
[nVent.com](http://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.