

# REBAR GROUNDING CLAMP, PARALLEL



## CERTIFICATIONS



## FEATURES

Universal use for rebar, rods or pipes

Lay-in feature cuts installation time

Bronze alloy construction with Stainless Steel 304 screws


Approved for direct burial in earth and concrete

## SPECIFICATIONS

Catalog Number	Item Name	Material	Connection Type	Conductor Size	Water Pipe Size(Ø)	Ground Rod Diameter, Actual(Ø)	Rebar Size, US	Rebar Size, Metric	Rebar Size, Canada
EK16	710355	Bronze, Stainless Steel 304 (EN 1.4301)	Parallel	#10 Solid - #2 Solid, 5.5 mm <sup>2</sup> Stranded - 25 mm <sup>2</sup> Stranded	12.7 – 25.4 mm	12.7 – 25.4 mm	#4 – #8	12 – 25 mm	10M – 25M

## DIAGRAMS

---

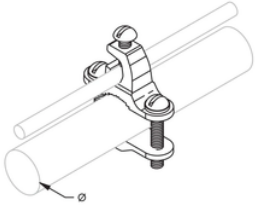

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**