



115M STANDARD DUTY LOOP HANGER



The 115M Standard Duty Loop Hanger is ideal for suspending stationary, non-insulated pipe lines, including CPVC pipes, in fire sprinkler systems. A knurled insert nut helps simplify vertical adjustments and flared edges on the base (1/2" to 4" sizes) help protect pipes from coming into contact with any sharp edges of the hanger.

CERTIFICATIONS



FEATURES

Flared edges help prevent any sharp surfaces from coming into contact with the pipe (1/2" to 4" sizes)

Retained insert nut helps ensure the loop hanger and insert nut stay together

Recommended for the suspension of stationary non-insulated pipe lines

Manufactured to use the minimum rod size permitted by NFPA® for fire sprinkler piping

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

SPECIFICATIONS


Finish Pregalvanized

Material Steel

Catalog Number	Item Name	Pipe Size	NB/DN	Outer Diameter(OD)	Rod Size(RS)	A	B	C	Ultimate Static Load(F)
115M0050 EG	597860	1/2"	15	21.3 mm	M10	71 mm	28.6 mm	25.4 mm	5,000 N
115M0075 EG	597870	3/4"	20	26.9 mm	M10	75.90 mm	30.2 mm	23.9 mm	5,000 N

Catalog Number	Item Name	Pipe Size	NB/DN	Outer Diameter(OD)	Rod Size(RS)	A	B	C	Ultimate Static Load(F)
115M0200 EG	597910	2"	50	60.3 mm	M10	108.60 mm	47.6 mm	23.9 mm	5,000 N
115M0100 EG	597880	1"	25	33.7 mm	M10	82.50 mm	34.9 mm	24.1 mm	5,000 N
115M0125 EG	597890	1 1/4"	32	42.4 mm	M10	90.60 mm	38.1 mm	24.1 mm	5,000 N
115M0150 EG	597900	1 1/2"	40	48.3 mm	M10	96.70 mm	41.3 mm	24.1 mm	5,000 N
115M0400 EG	597940	4"	100	114 mm	M10	192.50 mm	100.9 mm	48.9 mm	14,000 N
115M0300 EG	597930	3"	80	89 mm	M10	166.30 mm	88.2 mm	49.7 mm	14,000 N
115M0250 EG	597920	2 1/2"	65	76 mm	M10	150.80 mm	87.3 mm	50.8 mm	14,000 N
115M0500 EG	597950	5"	125	140 mm	M12	232.70 mm	120 mm	57.1 mm	20,000 N
115M0800 EG	597970	8"	200	219 mm	M12	327.10 mm	175.1 mm	73.4 mm	20,000 N
115M0600 EG	597960	6"	150	165 mm	M12	286.60 mm	160.4 mm	84.1 mm	20,000 N

DIAGRAMS

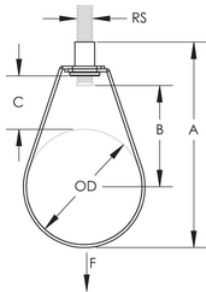

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.