


CAST TWO BOLT BEAM BONDING CLAMP

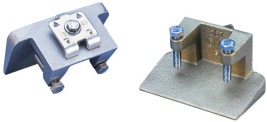

CERTIFICATIONS



FEATURES

Clamp for bonding cable to flat metal objects such as I-beams, angle irons and channel irons

Listed to UL® 96


SPECIFICATIONS

Conductor Size, UL: Class 1 - Class 2 (4/0 Max)

Finish: Tinned

Catalog Number	Material	Flange Thickness(FT)	Depth(D)	Width(W)	Height(H)	Contact Area	Unit Weight
LPA557	Aluminum	25.4 mm Max	69.85 mm	101.600 mm	50.80 mm	51.613 mm ² Min	0.315 kg
LPC557	Copper	25.4 mm Max	69.85 mm	101.600 mm	50.80 mm	51.613 mm ² Min	0.932 kg
LPC557L	Copper	25.4 mm Max	69.85 mm	101.600 mm	50.80 mm	51.613 mm ² Min	0.932 kg

DIAGRAMS

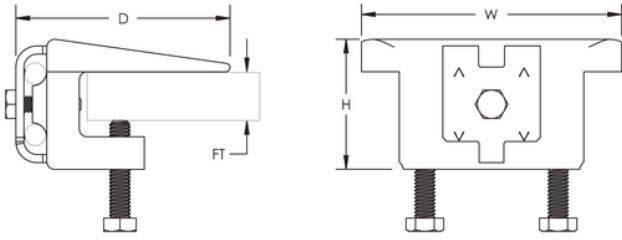

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER