


PCR PERFORATED C-SHAPED PROFILE

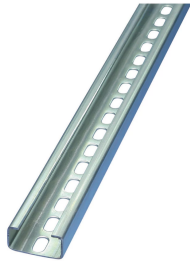

CERTIFICATIONS



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and DIN 46277

RoHS compliant


SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Catalog Number	Item Name	Height(H)	Width(W)	Length(L)	Thickness(T)	A	B	C	D	Unit Weight
PCR30X1 5-3M	557780	30 mm	15 mm	3,000 mm	1.50 mm	15 mm	7 mm	18 mm	8.2 mm	2.400 kg
PCR40X2 0-2M	557500	40 mm	20 mm	2,000 mm	1.50 mm	24 mm	7 mm	18 mm	8.2 mm	2.500 kg
PCR35X3 5-2M	557520	35 mm	35 mm	2,000 mm	2 mm	16 mm	7 mm	18 mm	8.2 mm	3 kg
PCR35X3 5-3M	557790	35 mm	35 mm	3,000 mm	2 mm	16 mm	7 mm	18 mm	8.2 mm	4.500 kg

DIAGRAMS

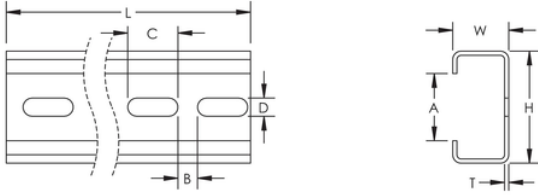

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER