

QCC NVENT ERIFLEX FLEXIBAR CLAMP



CERTIFICATIONS



FEATURES

Connects nVent ERIFLEX Flexibar to punched busbar

Allows for excellent electrical contact

Compact, space saving design

Installs quickly and easily

Ideal for on site modifications

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Catalog Number	Item Name	Conductor Width	Depth(D)	Width(W)	Height(H)	Thickness(T)	A	B	C	Unit Weight
QCC15-5-32	561210	15.5 – 32.0 mm	13 mm	70 mm	35 mm	5 mm	50 mm	10.5 mm	11 mm	0.112 kg
QCC40-63	561220	40 – 63 mm	13 mm	95 mm	35 mm	5 mm	75 mm	10.5 mm	11 mm	0.158 kg

ADDITIONAL PRODUCT DETAILS

Use one clamp when nVent ERIFLEX Flexibar thickness is less than 5 mm (0.2") and two clamps when nVent ERIFLEX Flexibar thickness is greater than 5 mm (0.2").

DIAGRAMS

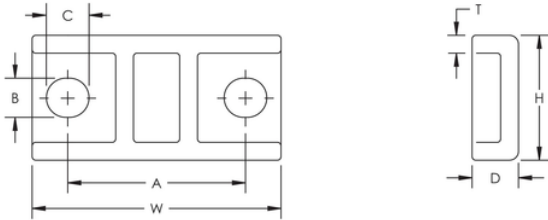

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER