




# NVENT CADDY PYRAMID EZ RUBBER-BASED ADJUSTABLE SUPPORT

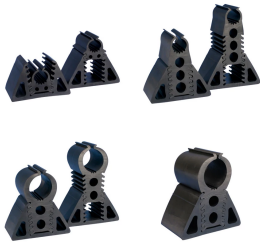

## CERTIFICATIONS



## FEATURES

Quick height adjustment accommodates for uneven roofs or sloped condensate lines

No tools or fasteners needed; fast snap-on installation

Design sheds water and helps reduce pipe corrosion

Roof-friendly; made of UV-stabilized EPDM material

## SPECIFICATIONS

**Material:** EPDM-SBR Rubber

Catalog Number	Item Name	NB/DN	Outer Diameter(O D)	Height(H)	Width(W)	Length(L)	Unit Weight	Ultimate Static Load(F)
RPSE1H24	182365	25	33 mm	45 – 102 mm	152 mm	102 mm	0.910 kg	756 N
RPSE2H46	182375	50	60 mm	102 – 152 mm	152 mm	102 mm	1.500 kg	1,112 N
RPSE4H46	182380	100	114 mm	100 – 150 mm	240 mm	102 mm	2.330 kg	3,920 N


## ADDITIONAL PRODUCT DETAILS

---

Ultimate load at 1/4" (6.35 mm) deflection. Contact project or roofing engineer for maximum allowable load on individual project roof system.

## DIAGRAMS

---

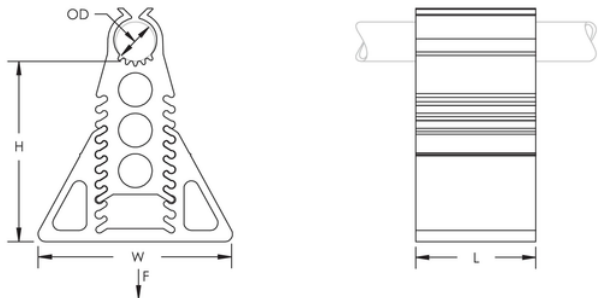

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**