



USC UNIVERSAL STRUT CLAMP FOR PIPE/CONDUIT



FEATURES

Consists of two clamps, nut and bolt

Fits into open side of strut channel

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 59)

SPECIFICATIONS


Finish: Electrogalvanized

Material: Steel

| Catalog Number | Item Name | Outer Diameter(OD) | Pipe Size | NB/DN | Width(W) | Thickness(T) | Static Load(F) |
|----------------|-----------|--------------------|-----------|-------|----------|--------------|----------------|
| USC026EG | 712065 | 25.4 – 26.9 mm | 3/4" | 20 | 32 mm | 1.50 mm | 2,000 N |
| USC022EG | 712050 | 21.5 – 22.2 mm | | | 32 mm | 1.50 mm | 2,000 N |
| USC033EG | 712085 | 32.8 – 33.4 mm | 1" | | 32 mm | 1.50 mm | 2,000 N |
| USC040EG | 712100 | 38.4 – 40.6 mm | | | 32 mm | 2 mm | 2,670 N |
| USC048EG | 712115 | 47.6 – 50.0 mm | 1 1/2" | 40 | 32 mm | 2 mm | 2,670 N |
| USC060EG | 712035 | 59.5 – 62.2 mm | 2" | 50 | 32 mm | 2.50 mm | 3,780 N |
| USC063EG | 712140 | 62.3 – 64.5 mm | | | 32 mm | 2.50 mm | 3,780 N |

| Catalog Number | Item Name | Outer Diameter(OD) | Pipe Size | NB/DN | Width(W) | Thickness(T) | Static Load(F) |
|----------------|-----------|--------------------|-----------|-------|----------|--------------|----------------|
| USC073EG | 712160 | 69.9 – 73.0 mm | 2 1/2" | | 32 mm | 2.50 mm | 3,780 N |
| USC086EG | 712180 | 84.0 – 88.9 mm | 3" | 80 | 32 mm | 2.50 mm | 3,780 N |
| USC101EG | 712200 | 98.4 – 102.6 mm | 3 1/2" | 90 | 32 mm | 2.50 mm | 3,780 N |

DIAGRAMS

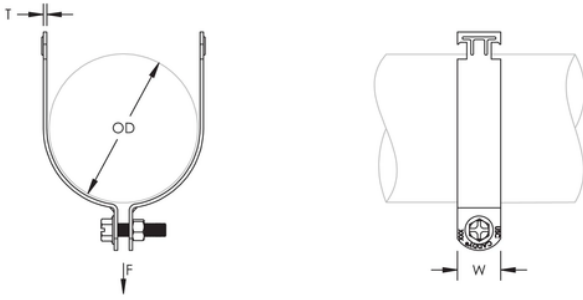

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER