

DRG ASYMMETRIC PROFILE



CERTIFICATIONS



FEATURES

Rapid assembly of all kinds of frameworks

High mechanical resistance

High corrosion resistance

Conforms to EN 60715 and 50035 and DIN 46277

RoHS compliant

 

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Catalog Number	Item Name	Height(H)	Width(W)	Length(L)	Thickness(T)	A	Unit Weight
DRG2M	558000	32 mm	15 mm	2,000 mm	1.50 mm	9 mm	1.400 kg
DRG3M	558010	32 mm	15 mm	3,000 mm	1.50 mm	9 mm	2.100 kg

DIAGRAMS

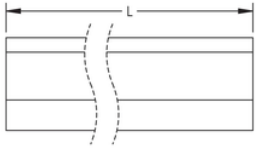

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER