



NVENT CADDY PYRAMID ST FIXED STRUT SUPPORT



CERTIFICATIONS



FEATURES

- Provides superior support for pipe, conduit, duct, cable tray and equipment
- Foam bottom offers low abrasion interface for better roof membrane protection
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Provides superior load distribution, even with varying rooftop surfaces
- Ready to use out of the box, saving installation time and labor
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Easy to transport to the roof
- Hot-dip galvanized and UV stabilized for long lasting performance

SPECIFICATIONS


Static Load Safety Factor:	3:1
Finish:	Hot-Dip Galvanized
Material:	Polyethylene;Polypropylene;Steel
Temperature:	-45 to 65 °C

Catalog Number	Item Name	Length 1(L1)	Length 2(L2)	Height(H)	Width(W)	Unit Weight	Surface Area	Static Load(F)	Certifications
PSF6C	360463	152 mm	203 mm	122 mm	152 mm	0.500 kg	26,452 mm ²	1,334 N	
PSF10C	360464	254 mm	317.5 mm	122 mm	203 mm	1 kg	59,355 mm ²	4,450 N	ITB
PSF10D	360465	254 mm	317.5 mm	163 mm	203 mm	1.500 kg	59,355 mm ²	4,450 N	ITB
PSF16C	360466	406 mm	483 mm	122 mm	203 mm	1.500 kg	91,613 mm ²	6,670 N	ITB
PSF16D	360467	406 mm	483 mm	163 mm	203 mm	2 kg	91,613 mm ²	6,670 N	ITB

ADDITIONAL PRODUCT DETAILS

Static load at 73.1 kPa (10.6 psi) roof loading. Contact project or roofing engineer for maximum allowable load on individual project roof system.

DIAGRAMS

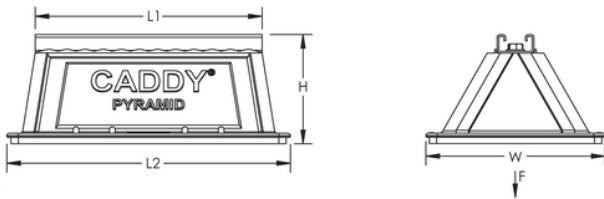

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER