




325 STEEL SIDE BEAM ATTACHMENT

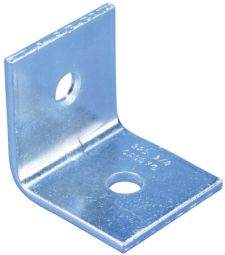

CERTIFICATIONS



FEATURES

Fastens to the wall or the side of a joist to support hanger rod

Conforms with Federal Specification WW-H-171 (Type 35), Manufacturers Standardization Society ANSI®/MSS-SP-58 (Type 34)

SPECIFICATIONS

Material Steel

Catalog Number	Finish	Hole Size(HS)	Width(W)	Length(L)	Height(H)	Thickness(T)	Static Load 1(F1)	Static Load 2(F2)	Certifications
3250037EG	Electrogalvanized	7/16"	1.900"	2"	2"	5/32"	650 lb	1,150 lb	OSHDP/HCAI
3250037PL	Plain	7/16"	1.900"	2"	2"	5/32"	650 lb	1,150 lb	
3250050EG	Electrogalvanized	9/16"	1.900"	2"	2"	5/32"	650 lb	1,150 lb	OSHDP/HCAI
3250050PL	Plain	9/16"	1.900"	2"	2"	5/32"	650 lb	1,150 lb	


ADDITIONAL PRODUCT DETAILS

Refer to Static Load 1 when used with lag screw. Refer to Static Load 2 with bolt to steel.

Follow fastener manufacturer's recommended shear and pull-out strength when fastening to the structure. Fastener not included.

Install in accordance with applicable code.

DIAGRAMS

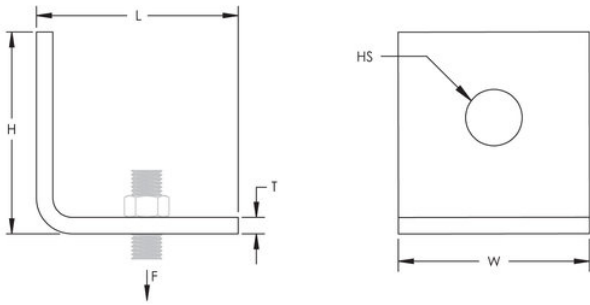

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.