



101 LOOP HANGER FOR COPPER TUBE, 3" PIPE, 3 1/8" OD, 1/2" ROD

CATALOG NUMBER

1010300CP



FEATURES

Recommended for the suspension of stationary non-insulated copper tube lines

Conforms with Federal Specification WW-H-171 (Type 10), Manufacturers Standardization Society (MSS) SP-58 (Type 10)

PRODUCT ATTRIBUTES

Material: Steel

Finish: Copper Electroplated;Electrogalvanized

Pipe Size: 3"

Outer Diameter: 3 1/8"

Rod Size: 1/2"


A: 5 11/16"

B: 2 1/2"

C: 1 5/16"

Static Load: 250 lb

DIAGRAMS

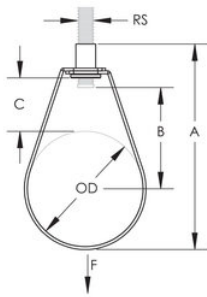

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER