




# LOW VOLTAGE ACCESSORY CLIP



## CERTIFICATIONS

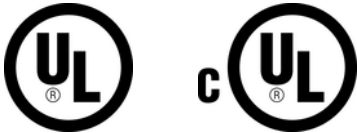

## FEATURES

Ideal for low voltage applications, such as security, video, Wireless Access Protocol (WAP), Power over Ethernet (PoE), fire, and control wire

Tool-free installation to existing wire basket pathway made easy with side retaining flaps

Designed to fit commonly available wire basket tray with bottom and side mount applications

Modular ganging feature for ease of installation expansion

Compliant with UL® 2043 and suitable for use in air handling (plenum) spaces

Meets ISO®/IEC 14763-2, ANSI®/TIA 568 and ANSI®/TIA 569

## SPECIFICATIONS

**Material** Polypropylene

Catalog Number	Color	Diameter(Ø)	Cable Capacity, Cat 5e	Cable Capacity, Cat 6	Cable Capacity, Cat 6A	Height(H)	Length(L)	Width(W)
LVACBA	Black	1"	22	15	8	2 3/8"	2 3/8"	7/8"
LVACRD	Red	1"	22	15	8	2 3/8"	2 3/8"	7/8"

## ADDITIONAL PRODUCT DETAILS

---

When there is no other pathway for the growing amount of cable that must be accommodated in a building, our Low Voltage Accessory Clip (LVAC) is the answer. Part of the larger nVent CADDY datacom family of products, the LVAC will connect to the bottom or side of an existing pathway so you can accommodate more cable without rethinking the path. Quick, tool-free installation makes it easy to install in tight spaces.


Increase your cable routing and hanging options with the Low Voltage Accessory Clip.

Non-continuous supports may not exceed spacing of 5' (1.5 m) per TIA 569-C.9.7 and EN 50174-2.

Cable capacity is calculated based on a 70% fill rate.

## DIAGRAMS

---

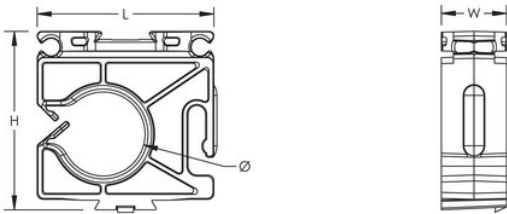

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.