



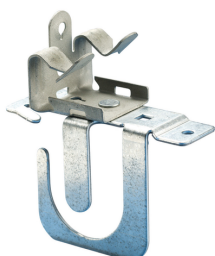

MC/AC CABLE SUPPORT BRACKET WITH FLANGE CLIP



CERTIFICATIONS

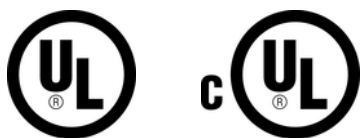

FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation


SPECIFICATIONS

Isolated Ground Cable Size	12-3 to 8-2
Finish	Electrogalvanized
Material	Steel

Catalog Number	MC/AC Cable Size	Super Neutral Cable Size	Cable Capacity	Flange Thickness(FT)	Outer Diameter(OD)
MCS10024	14-3 to 10-2	10-2	8	1/8" – 1/4"	0.430" – 0.560"
MCS10124	10-3 to 8-3	12-3 to 10-2	7	1/8" – 1/4"	0.560" – 0.690"
MCS5024	14-3 to 10-2	10-2	4	1/8" – 1/4"	0.430" – 0.560"
MCS10058	14-3 to 10-2	10-2	8	5/16" – 1/2"	0.430" – 0.560"
MCS10158	10-3 to 8-3	12-3 to 10-2	7	5/16" – 1/2"	0.560" – 0.690"
MCS5058	14-3 to 10-2	10-2	4	5/16" – 1/2"	0.430" – 0.560"
MCS100912	14-3 to 10-2	10-2	8	9/16" – 3/4"	0.430" – 0.560"

Catalog Number	MC/AC Cable Size	Super Neutral Cable Size	Cable Capacity	Flange Thickness(FT)	Outer Diameter(OD)
MCS50912	14-3 to 10-2	10-2	4	9/16" – 3/4"	0.430" – 0.560"
MCS101912	10-3 to 8-3	12-3 to 10-2	7	9/16" – 3/4"	0.560" – 0.690"

DIAGRAMS

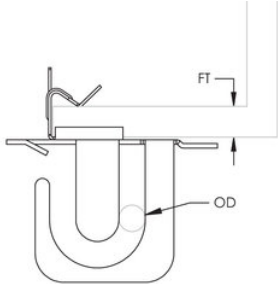

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.