




NVENT CADDY ALL-IN-ONE FLOOR-MOUNTED WITHOUT MUD RING



CERTIFICATIONS

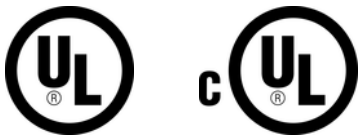

FEATURES

Preset to a finish height of 18" from the floor (adjustable to 12" or 15")

Integrated first means of support accepts conduit or MC/AC cable

Provides the flexibility to add a mud ring for non-standard drywall thicknesses

Box remains fixed in place when mud ring is removed

Accommodates additional nVent CADDY All-in-One box assemblies, support brackets and low-voltage mounting plates

Includes multiple 1/2" and 3/4" knockouts on each side of the box

Works with standard US and Canadian mud rings

SPECIFICATIONS

- | -

EMT Conduit Size	1/2";3/4"
MC/AC Cable Size	14-2 to 12-3
Knockout Sizes	(8) 1/2", 3/4";(3) 1/2"
Finish	Pregalvanized
Material	Steel


Catalog Number	Ground Wire Included	Box Volume	Depth(D)	A	B	C
A1FF0G	Yes	32.8 in ³	3 5/8"	22 3/16"	7 3/4"	2 11/16"

Catalog Number	Ground Wire Included	Box Volume	Depth(D)	A	B	C
A1FF0GS	Yes	32.8 in ³	2 1/2"	22 3/16"	7 3/4"	2 11/16"

ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

DIAGRAMS

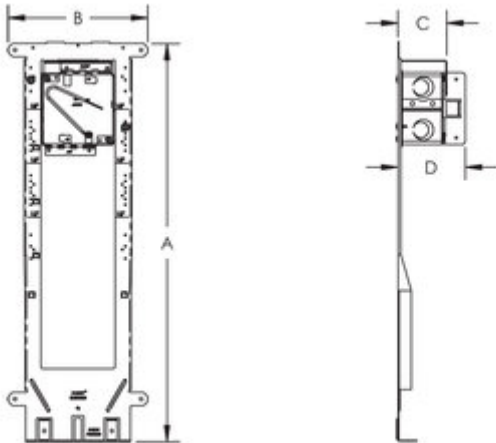

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.