




SLK15L1	1.5 mm	3.3'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	1.0000	SMACNA, cUL, UL
SLK15L10	1.5 mm	32.8'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	1.0000	cUL, UL, SMACNA
SLK15L2	1.5 mm	6.6'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	1.0000	cUL, UL, SMACNA
SLK15L2R2	1.5 mm	6.6'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	2.0000	UL, SMACNA, cUL
SLK15L3	1.5 mm	9.9'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	1.0000	cUL, UL, SMACNA
SLK15L3R2	1.5 mm	9.9'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	2.0000	cUL, UL, SMACNA
SLK15L5	1.5 mm	16.4'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	1.0000	SMACNA, cUL, UL
SLK15L5R2	1.5 mm	16.4'	0.710"	0.180"	1.890"	2.150"	3/4"	1/2"	90° Max	44 lb	2.0000	UL, cUL, SMACNA
SLK2L1	2 mm	3.3'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	cUL, SMACNA, UL
SLK2L10	2 mm	32.8'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	UL, cUL, SMACNA
SLK2L2	2 mm	6.6'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	SMACNA, cUL, UL
SLK2L2R2	2 mm	6.6'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	2.0000	SMACNA, cUL, UL
SLK2L3	2 mm	9.9'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	cUL, SMACNA, UL
SLK2L3R2	2 mm	9.9'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	2.0000	UL, SMACNA, cUL
SLK2L5	2 mm	16.4'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	cUL, SMACNA, UL
SLK2L7	2 mm	22.9'	0.870"	0.220"	2.240"	2.150"	3/4"	1/2"	90° Max	100 lb	1.0000	cUL, SMACNA, UL
SLK3L1	3 mm	3.3'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	1.0000	SMACNA
SLK3L10	3 mm	32.8'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	1.0000	SMACNA
SLK3L2	3 mm	6.6'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	1.0000	SMACNA
SLK3L3	3 mm	9.9'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	1.0000	SMACNA
SLK3L3R2	3 mm	9.9'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	2.0000	SMACNA
SLK3L5	3 mm	16.4'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	1.0000	SMACNA

SLK3L5R2	3 mm	16.4'	0.910"	0.240"	2.270"	2 1/2"	0.900"	0.600"	90° Max	200 lb	2.0000	SMACNA
----------	------	-------	--------	--------	--------	--------	--------	--------	---------	--------	--------	--------

## DIAGRAMS

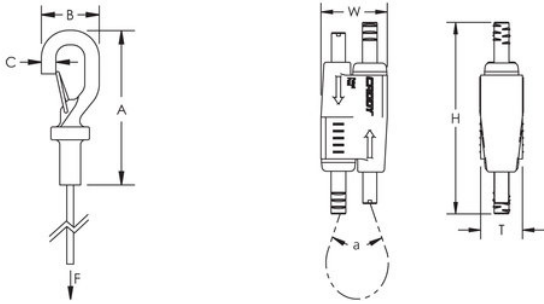

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.