



# NVENT CADDY SWIFT CLIP STRUT CLAMP FOR TUBE/PIPE



## FEATURES

Secures pipe while allowing it to expand, preventing cracked and fractured joints

Snap-in and twist installation requires no tools

Fits directly into vertical and horizontal strut channels

Use for installation of refrigeration, A/C tubing and PEX piping in horizontal and vertical channels

Compliant with UL® 2043 and suitable for use in air handling (plenum) spaces

## SPECIFICATIONS

**Material** Polyamide  
**Working Temperature** -40 to 284 °F

Catalog Number	Outer Diameter(OD)	Copper Tube Size	Pipe Size	Width(W)
TSM0037	3/8"	1/4"		1 5/8"
TSM0050	1/2"	3/8"		1 5/8"
TSM0062	5/8"	1/2"		1 5/8"
TSM0087	7/8"	3/4"	1/2"	1 5/8"
TSM0075	3/4"	5/8"		1 5/8"
TSM0112	1 1/8"	1"		1 5/8"
TSM0137	1 3/8"	1 1/4"		1 5/8"
TSM0162	1 5/8"	1 1/2"		1 5/8"

## ADDITIONAL PRODUCT DETAILS


---

Can also be used with PEX piping. For PEX pipe sizes, refer to the Copper Tube Size column.

Clip must be installed with temperature at or above 14 °F (-10 °C).

## DIAGRAMS

---

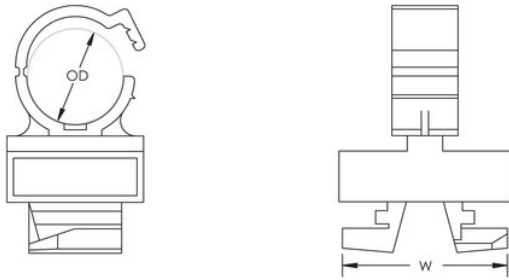

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**nVent.com** CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.