




TELESCOPING SCREW GUN BOX BRACKET

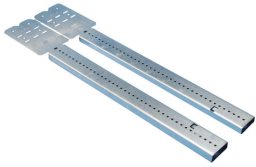

CERTIFICATIONS



FEATURES

Can mount multiple boxes

Notched and marked for easy identification and bending

Improved design with stamped inch markings and pilot holes accelerates precise box conduit mounting between studs

Pilot holes allow easy box attachment with a screwdriver

Requires only a screw gun to install

Can be mounted to face or inside of stud

Adjustable for non-standard stud spacing

Interlocking tab prevents accidental disassembly

Unique, one-piece, break apart design

SPECIFICATIONS

Finish Pregalvanized

Material Steel

Catalog Number	Stud Spacing	Box Depth	Packing Quantity
TSGB16	11" – 18"	1 1/2", 2 1/8"	1.0000
TSGB1624	15 3/4" – 25"	1 1/2", 2 1/8", 2 1/2"	1.0000

Catalog Number	Stud Spacing	Box Depth	Packing Quantity
TSGB24	17" – 26"	1 1/2", 2 1/8", 2 1/2"	1.0000

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.