

PREFABRICATED GATE JUMPER ASSEMBLY WITH GROUND LEADS, RIGHT HAND, 2 1/2" GATE, 1 1/2" POST, 1/0 STRANDED, 4' GROUND

CATALOG NUMBER

A239EC2S242C4RH



FEATURES

Ideal for when nVent ERICO Cadweld connections cannot be made to aluminum pipe or thin-wall steel tube

Jumper conductor is insulated

Stainless steel hardware included

Available in either left or right-hand orientation

PRODUCT ATTRIBUTES

Material: Copper;Stainless Steel 18-8 (EN 1.4305);Stainless Steel 304 (EN 1.4301)

Finish: Tinned

Orientation: Right Hand

Fixed Gate Diameter, Nominal: 2 1/2"

Fixed Gate Diameter, Actual: 2.88"

Post Frame Diameter, Nominal: 1 1/2"

Post Frame Diameter, Actual: 1.90"

Jumper Conductor Size: 4/0 Stranded

Jumper Length: 24"

Ground Lead Conductor Size: 1/0 Stranded


Ground Lead Length: 4'

ADDITIONAL PRODUCT DETAILS

"Fixed gate" refers to the pipe on the fence itself, while "post frame" refers to the post on the swinging door.

Left hand orientation shown in diagram.

DIAGRAMS

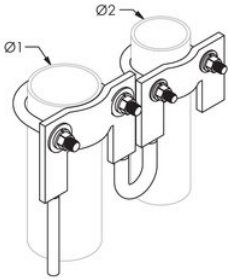

A239-EB-2S-24-2Q-4-RH		
A239	Series	
EB	Clamp Code	EB = 2 1/2" Gate, 1 1/4" Post EC = 2 1/2" Gate, 1 1/2" Post FB = 3" Gate, 1 1/4" Post FC = 3" Gate, 1 1/2" Post GB = 3 1/2" Gate, 1 1/4" Post GC = 3 1/2" Gate, 1 1/2" Post HB = 4" Gate, 1 1/4" Post HC = 4" Gate, 1 1/2" Post
2S	4/0 AWG Flexible Jumper Designation	
24	Jumper Length (inches)	
2Q	Ground Lead Cable Code (AWG)	2C = 1/0 Stranded 2G = 2/0 Stranded 2Q = 4/0 Stranded 9F = Copper-Clad Steel #9, 19-Strand
4	Ground Lead Length (feet)	
RH	Ground Lead Side	LH = Left Hand RH = Right Hand

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.