


SB/SBL HOLLOW CORE RAIL DRILL BIT, 35 MM DRILL BIT DIAMETER, 2.4"

CATALOG NUMBER

DHC35

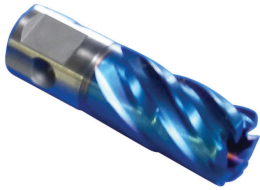

FEATURES

Designed for high-speed drilling applications

Withstands approximately 40 uses

Can be reground for further use

Specifically developed for rail steel

3/4" (19 mm) Weldon shank

Allows for short drill times

High durability provides extended lifetime

PRODUCT ATTRIBUTES

Material: High-Speed Steel

Finish: TiAlN Coating

Drill Bit Diameter: 35 mm

Length: 2.400"

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.