


EXTENDED STRAP CABLE/POINT TO PIPE SUPPORT

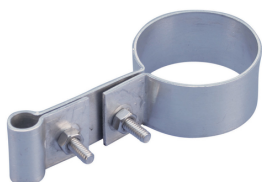

CERTIFICATIONS



FEATURES

Offset support for air terminals or conductors

SPECIFICATIONS


Finish Tinned

Catalog Number	Material	Diameter(Ø)	Outer Diameter(OD)	Height(H)	A	Unit Weight
LPA675	Aluminum	0.510" – 0.625"	1.900" – 2.400"	1 1/4"	2 1/2"	0.155 lb
LPA676	Aluminum	0.510" – 0.625"	2 3/8" – 2 7/8"	1 1/4"	2 1/2"	0.159 lb
LPA677	Aluminum	0.510" – 0.625"	3 1/2" – 4"	1 1/4"	2 1/2"	0.220 lb
LPA678	Aluminum	0.510" – 0.625"	4 1/2" – 5"	1 1/4"	2 1/2"	0.260 lb
LPC675	Copper	0.510" – 0.625"	1.900" – 2.400"	1 1/4"	2 1/2"	0.373 lb
LPC676	Copper	0.510" – 0.625"	2 3/8" – 2 7/8"	1 1/4"	2 1/2"	0.385 lb
LPC677	Copper	0.510" – 0.625"	3 1/2" – 4"	1 1/4"	2 1/2"	0.531 lb
LPC678	Copper	0.510" – 0.625"	4 1/2" – 5"	1 1/4"	2 1/2"	0.627 lb

ADDITIONAL PRODUCT DETAILS

Air terminals must be attached to a threaded base.

DIAGRAMS

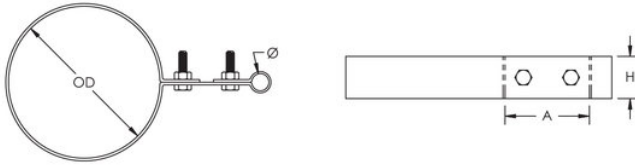

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.