

GROUND ROD CLAMP, U-BOLT, TINNED, ONE CONDUCTOR



FEATURES

Tinned finish provides a theft-deterrent appearance

Accepts conductors in both parallel and perpendicular orientations


SPECIFICATIONS

Material Bronze;Stainless Steel 304 (EN 1.4301)

Finish Tinned

Catalog Number	Ground Rod Diameter, Nominal	Conductor Size, UL
GC064	5/8" - 3/4"	#4 Sol - 2/0 Str, 16 mm ² Str - 50 mm ² Str
GC065	5/8" - 3/4"	2/0 Sol - 250 kcmil Str, 70 mm ² Str - 120 mm ² Str

DIAGRAMS

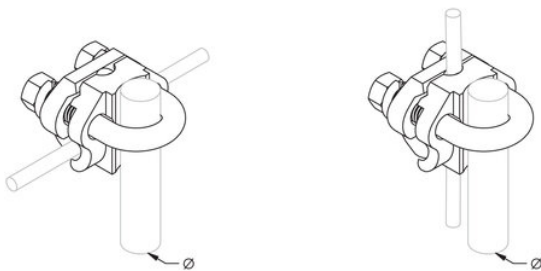

Conductor Orientation (Parallel or Perpendicular)	
GC064	Conductor Size

Nominal Ground Rod Diameter	#4 Sol	#4 Str	#2 Sol	#2 Str	1/0 Sol	1/0 Str- 3/0 Sol
5/8" copper-bonded ground rod	Par.	Par.	Par.	Par.	Both	Perp.
5/8" galvanized/stainless steel ground rod	Par.	Par.	Par.	-	Perp.	Perp.
3/4" copper-bonded ground rod	Par.	-	-	-	Perp.	Perp.
3/4" galvanized/stainless steel ground rod	-	-	-	-	Perp.	-
GC065	Conductor Size					
Nominal Ground Rod Diameter	#4 Sol-#4 Str		#2 Sol-4/0 Sol		4/0 Str	250 kcmil Str
5/8" copper-bonded ground rod	Par.		Both		Both	Par.
5/8" galvanized/stainless steel ground rod	Par.		Both		Both	Par.
3/4" copper-bonded ground rod	Par.		Both		Both	-
3/4" galvanized/stainless steel ground rod	Par.		Both		-	-

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.