


NVENT ERICO RAILCLIPS, CONCRETE TIE CLIP OR ASSEMBLY



DIAGRAMS

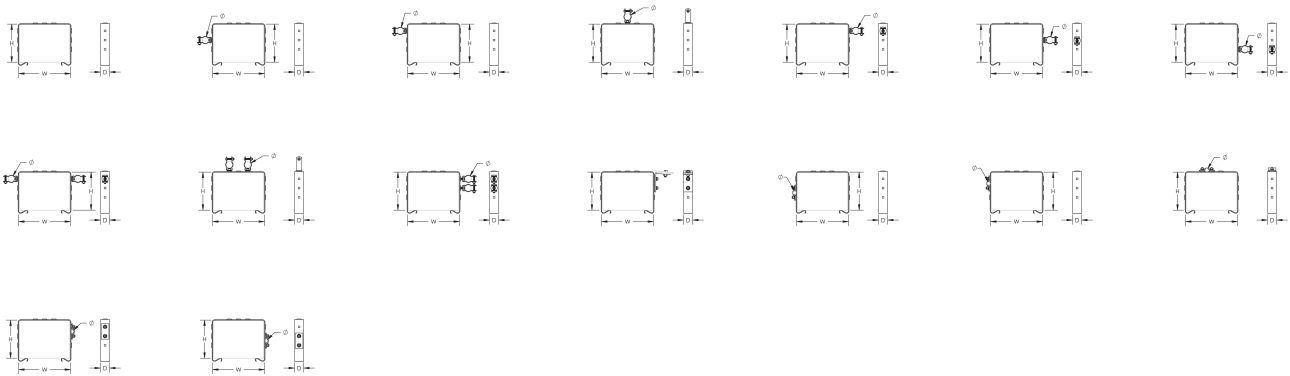

FEATURES

Eliminates the need to drill the concrete sleeper, respecting concrete sleeper integrity and improving safety

No tools required for installation

Resistant to corrosion-causing agents, including U.V., weather conditions, oil, greases, gasoline, solvents, rain and water

Versatile configuration: clip only or accessories attached to clip

Accessories attached to clip configuration come pre-assembled, but also allow adaptations at site (change of accessories and/or position if needed)

SPECIFICATIONS

Material Stainless Steel 301 (EN 1.4310)

Catalog Number	Clip Configuration	Width	Depth	Height	Diameter
SBA112120A078	Clip with PVC Wire Clamp, Positions 7/8	7"	1 1/2"	7 1/2"	3/8"

Catalog Number	Clip Configuration	Width	Depth	Height	Diameter
SBA114129A089	Clip with PVC Wire Clamp, Positions 8/9	7 1/8"	1 1/2"	8 1/16"	3/8"
SBA119105A089	Clip with PVC Wire Clamp, Positions 8/9	7 7/16"	1 1/2"	6 9/16"	3/8"
SBA120100A078	Clip with PVC Wire Clamp, Positions 7/8	7 1/2"	1 1/2"	6 1/4"	3/8"
SBA120131A078	Clip with PVC Wire Clamp, Positions 7/8	7 1/2"	1 1/2"	8 3/16"	3/8"
SBA120160A078	Clip with PVC Wire Clamp, Positions 7/8	7 1/2"	1 1/2"	10"	3/8"
SBA129128A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/16"	1 1/2"	8"	3/8"
SBA132100A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/4"	1 1/2"	6 1/4"	3/8"
SBA132128A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/4"	1 1/2"	8"	3/8"
SBA132131A012	Clip with PVC Wire Clamp, Positions 1/2	8 1/4"	1 1/2"	8 3/16"	3/8"
SBA132132A089	Clip with PVC Wire Clamp, Positions 8/9	8 1/4"	1 1/2"	8 1/4"	3/8"
SBA136100A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	6 1/4"	3/8"
SBA136100A089	Clip with PVC Wire Clamp, Positions 8/9	8 1/2"	1 1/2"	6 1/4"	3/8"
SBA136104A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	6 1/2"	3/8"
SBA136112A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	7"	3/8"
SBA136127A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	7 15/16"	3/8"
SBA136128A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	8"	3/8"
SBA136131A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	8 3/16"	3/8"
SBA136131A089	Clip with PVC Wire Clamp, Positions 8/9	8 1/2"	1 1/2"	8 3/16"	3/8"
SBA136136A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	8 1/2"	3/8"
SBA136140A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	8 3/4"	3/8"
SBA136144A078	Clip with PVC Wire Clamp, Positions 7/8	8 1/2"	1 1/2"	9"	3/8"
SBA138100A078	Clip with PVC Wire Clamp, Positions 7/8	8 5/8"	1 1/2"	6 1/4"	3/8"
SBA140109A089	Clip with PVC Wire Clamp, Positions 8/9	8 3/4"	1 1/2"	6 13/16"	3/8"
SBA140112A078	Clip with PVC Wire Clamp, Positions 7/8	8 3/4"	1 1/2"	7"	3/8"

Catalog Number	Clip Configuration	Width	Depth	Height	Diameter
SBA140136A078	Clip with PVC Wire Clamp, Positions 7/8	8 3/4"	1 1/2"	8 1/2"	3/8"
SBA140144A078	Clip with PVC Wire Clamp, Positions 7/8	8 3/4"	1 1/2"	9"	3/8"
SBA141100A078	Clip with PVC Wire Clamp, Positions 7/8	8 13/16"	1 1/2"	6 1/4"	3/8"
SBA142096A089	Clip with PVC Wire Clamp, Positions 8/9	8 7/8"	1 1/2"	6"	3/8"
SBA144114A078	Clip with PVC Wire Clamp, Positions 7/8	9"	1 1/2"	7 1/8"	3/8"
SBA144144A078	Clip with PVC Wire Clamp, Positions 7/8	9"	1 1/2"	9"	3/8"
SBA144152A078	Clip with PVC Wire Clamp, Positions 7/8	9"	1 1/2"	9 1/2"	3/8"
SBA144157A078	Clip with PVC Wire Clamp, Positions 7/8	9"	1 1/2"	9 13/16"	3/8"
SBA146139A089	Clip with PVC Wire Clamp, Positions 8/9	9 1/8"	1 1/2"	8 11/16"	3/8"
SBA148124A045	Clip with PVC Wire Clamp, Positions 4/5	9 1/4"	1 1/2"	7 3/4"	3/8"
SBA150108A089	Clip with PVC Wire Clamp, Positions 8/9	9 3/8"	1 1/2"	6 3/4"	3/8"
SBA150160A012	Clip with PVC Wire Clamp, Positions 1/2	9 3/8"	1 1/2"	10"	3/8"
SBA150160A078	Clip with PVC Wire Clamp, Positions 7/8	9 3/8"	1 1/2"	10"	3/8"
SBA154144A078	Clip with PVC Wire Clamp, Positions 7/8	9 5/8"	1 1/2"	9"	3/8"
SBA154144A089	Clip with PVC Wire Clamp, Positions 8/9	9 5/8"	1 1/2"	9"	3/8"
SBA156168A078	Clip with PVC Wire Clamp, Positions 7/8	9 3/4"	1 1/2"	10 1/2"	3/8"
SBA160112A023	Clip with PVC Wire Clamp, Positions 2/3	10"	1 1/2"	7"	3/8"
SBA160112A078	Clip with PVC Wire Clamp, Positions 7/8	10"	1 1/2"	7"	3/8"
SBA160128A023	Clip with PVC Wire Clamp, Positions 2/3	10"	1 1/2"	8"	3/8"
SBA160128A078	Clip with PVC Wire Clamp, Positions 7/8	10"	1 1/2"	8"	3/8"
SBA160144A023	Clip with PVC Wire Clamp, Positions 2/3	10"	1 1/2"	9"	3/8"
SBA160172A023	Clip with PVC Wire Clamp, Positions 2/3	10"	1 1/2"	10 3/4"	3/8"
SBA161112A078	Clip with PVC Wire Clamp, Positions 7/8	10 1/16"	1 1/2"	7"	3/8"
SBA164164A078	Clip with PVC Wire Clamp, Positions 7/8	10 1/4"	1 1/2"	10 1/4"	3/8"

Catalog Number	Clip Configuration	Width	Depth	Height	Diameter
SBA168152A078	Clip with PVC Wire Clamp, Positions 7/8	10 1/2"	1 1/2"	9 1/2"	3/8"
SBA132132B005	Clip with Conduit Hanger, Position 5	8 1/4"	1 1/2"	8 1/4"	3/4"
SBA136096B005	Clip with Conduit Hanger, Position 5	8 1/2"	1 1/2"	6"	3/4"
SBA144144B078	Clip with Conduit Hanger, Positions 7/8	9"	1 1/2"	9"	3/4"
SBA136100B107	Clip with Conduit Hanger, Position 7	8 1/2"	1 1/2"	6 1/4"	1"
SBA136120B103	Clip with Conduit Hanger, Position 3	8 1/2"	1 1/2"	7 1/2"	1"
SBA136123B103	Clip with Conduit Hanger, Position 3	8 1/2"	1 1/2"	7 11/16"	1"
SBA136123B137	Clip with Conduit Hanger, Positions 3/7	8 1/2"	1 1/2"	7 11/16"	1"
SBA136131B107	Clip with Conduit Hanger, Position 7	8 1/2"	1 1/2"	8 3/16"	1"
SBA136139B103	Clip with Conduit Hanger, Position 3	8 1/2"	1 1/2"	8 11/16"	1"
SBA136139B137	Clip with Conduit Hanger, Positions 3/7	8 1/2"	1 1/2"	8 11/16"	1"
SBA142132B109	Clip with Conduit Hanger, Position 9	8 7/8"	1 1/2"	8 1/4"	1"
SBA148108B103	Clip with Conduit Hanger, Position 3	9 1/4"	1 1/2"	6 3/4"	1"
SBA148140B178	Clip with Conduit Hanger, Positions 7/8	9 1/4"	1 1/2"	8 3/4"	1"
SBA154144B103	Clip with Conduit Hanger, Position 3	9 5/8"	1 1/2"	9"	1"
SBA154144B137	Clip with Conduit Hanger, Positions 3/7	9 5/8"	1 1/2"	9"	1"
SBA140145B207	Clip with Conduit Hanger, Position 7	8 3/4"	1 1/2"	9 1/16"	1 1/4"
SBA142132B209	Clip with Conduit Hanger, Position 9	8 7/8"	1 1/2"	8 1/4"	1 1/4"
SBA116100	Clip Only	7 1/4"	1 1/2"	6 1/4"	
SBA116131	Clip Only	7 1/4"	1 1/2"	8 3/16"	
SBA128104	Clip Only	8"	1 1/2"	6 1/2"	
SBA128109C078	Clip with L-Bracket, Positions 7/8	8"	1 1/2"	6 13/16"	
SBA128128	Clip Only	8"	1 1/2"	8"	
SBA136100	Clip Only	8 1/2"	1 1/2"	6 1/4"	
SBA136100B302	Clip with Conduit Hanger, Position 2	8 1/2"	1 1/2"	6 1/4"	1 1/2"
SBA136104	Clip Only	8 1/2"	1 1/2"	6 1/2"	
SBA136108	Clip Only	8 1/2"	1 1/2"	6 3/4"	
SBA136128	Clip Only	8 1/2"	1 1/2"	8"	
SBA136132	Clip Only	8 1/2"	1 1/2"	8 1/4"	
SBA136136	Clip Only	8 1/2"	1 1/2"	8 1/2"	
SBA138128	Clip Only	8 5/8"	1 1/2"	8"	
SBA138132	Clip Only	8 5/8"	1 1/2"	8 1/4"	
SBA140128	Clip Only	8 3/4"	1 1/2"	8"	
SBA140136C078	Clip with L-Bracket, Positions 7/8	8 3/4"	1 1/2"	8 1/2"	
SBA140140	Clip Only	8 3/4"	1 1/2"	8 3/4"	
SBA14096	Clip Only	8 3/4"	1 1/2"	6"	
SBA142100	Clip Only	8 7/8"	1 1/2"	6 1/4"	
SBA144100	Clip Only	9"	1 1/2"	6 1/4"	
SBA144104	Clip Only	9"	1 1/2"	6 1/2"	

Catalog Number	Clip Configuration	Width	Depth	Height	Diameter
SBA144108	Clip Only	9"	1 1/2"	6 3/4"	
SBA144114C078	Clip with L-Bracket, Positions 7/8	9"	1 1/2"	7 1/8"	
SBA144120C078	Clip with L-Bracket, Positions 7/8	9"	1 1/2"	7 1/2"	
SBA144128	Clip Only	9"	1 1/2"	8"	
SBA144140	Clip Only	9"	1 1/2"	8 3/4"	
SBA144144B346	Clip with Conduit Hanger, Positions 4/6	9"	1 1/2"	9"	1 1/2"
SBA145096	Clip Only	9 1/16"	1 1/2"	6"	
SBA146108C078	Clip with L-Bracket, Positions 7/8	9 1/8"	1 1/2"	6 3/4"	
SBA146136	Clip Only	9 1/8"	1 1/2"	8 1/2"	
SBA148096	Clip Only	9 1/4"	1 1/2"	6"	
SBA148116	Clip Only	9 1/4"	1 1/2"	7 1/4"	
SBA148128	Clip Only	9 1/4"	1 1/2"	8"	
SBA154144C078	Clip with L-Bracket, Positions 7/8	9 5/8"	1 1/2"	9"	
SBA160108B305	Clip with Conduit Hanger, Position 5	10"	1 1/2"	6 3/4"	1 1/2"
SBA160112C078	Clip with L-Bracket, Positions 7/8	10"	1 1/2"	7"	
SBA172176	Clip Only	10 3/4"	1 1/2"	11"	
SBA257A1	Clip Only	9 1/2"	1 1/2"	6 13/16"	
SBA257H1B1	Clip with Conduit Hanger, Position 8	9 5/8"	1 1/2"	6 23/32"	1 3/4"

ADDITIONAL PRODUCT DETAILS

Photos of the different clip configurations show the accessory in position 3 and are for reference only.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.