

HYDRAULIC FLEXIBLE/NON-FLEXIBLE BUSBAR PUNCHER



CERTIFICATIONS



FEATURES

Works with copper or aluminium busbar and nVent ERIFLEX Flexibar

Punches flat and clean hole edges

Punch pip to adjust the hole position

Quick setup with interchangeable punch and die system

Large range of round and oval punches and dies available

Can be tilted at a 45° angle for easier punching of formed busbar

Calibrated side and depth gauge and stop


Strong mechanical assembly

RoHS compliant

SPECIFICATIONS

Catalog Number	Item Name	Operating Pressure	Busbar Thickness	Width(W)	Height(H)	Depth(D)	A	Unit Weight
HYDR-BB-PUN	545680	10,000 psi	1/2" Max	4.720"	18 1/2"	12"	5.120"	119.050 lb

DIAGRAMS

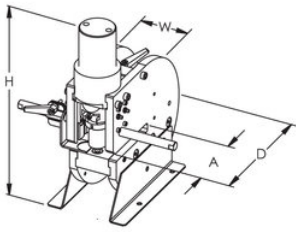

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.