


# UNIVERSAL BUSBAR SUPPORT WITH NEUTRAL CIRCUIT, HIGH AMPACITY

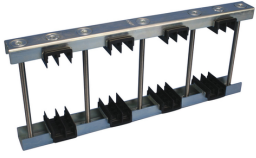

## CERTIFICATIONS



## FEATURES

Universal fixing system

Installs quickly and easily

Extremely robust construction

Screws are made from non-magnetic stainless steel

Halogen free insulators


## SPECIFICATIONS

<b>Max Working Voltage, IEC (Ui)</b>	1,000 VAC;1,500 VDC
<b>Material</b>	Steel;Glass Fibre Reinforced Polyamide
<b>Complies With</b>	IEC® 60439.1;IEC® 61439.1;IEC® 60695-2-11 (Glow Wire Test 960 °C)
<b>Flammability Rating</b>	UL® 94V-0
<b>Working Temperature</b>	-40 to 266 °F

Catalog Number	Item Name	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness	Width(W)	A
UBS1-10TN-160	561500	3,500 A	1	6.300"	0.39"	11.810"	2.760"
UBS2-10TN-160	561870	5,700 A	1 – 2	6.300"	0.39"	18.900"	4.330"
UBS2-10TN-200	561880	5,700 A	1 – 2	7.870"	0.39"	18.900"	4.330"

Catalog Number	Item Name	Typical Application Current Rating	Busbars per Phase	Busbar Width	Busbar Thickness	Width(W)	A
UBS3-10TN-160	561540	6,200 A	1 – 3	6.300"	0.39"	18.900"	4.330"

## DIAGRAMS

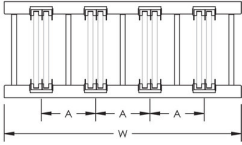

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.