

ELCP TAPERED PLASTIC SCREW-IN PLUG FOR A2



FEATURES

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Color coded for the appropriate coupler size

SPECIFICATIONS


Material High Density Polyethylene (HDPE)

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter(Ø)	Height(H)	Color
ELCP12	#4	10M	0.690"	0.390"	Red
ELCP16	#5	15M	0.880"	0.590"	Black
ELCP20	#6	20M	1.060"	0.590"	Yellow
ELCP22	#7		1.190"	0.590"	Blue
ELCP25	#8	25M	1.380"	0.590"	Red
ELCP28	#9	30M	1.500"	0.590"	Black
ELCP32	#10		1.750"	0.590"	Yellow
ELCP36	#11	35M	1.880"	0.670"	Blue
ELCP40			2.250"	0.670"	Green
ELCP43T	#14	45M	2.250"	0.670"	Red
ELCP57T	#18	55M	3"	0.670"	Blue

ADDITIONAL PRODUCT DETAILS

ELCP12 is a push-in style plug.

DIAGRAMS

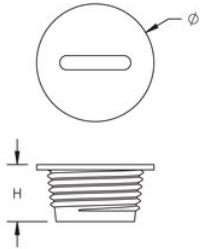

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.