

ELICP INTERNAL NVENT LENTON FORM SAVER PLUG FOR A2 COUPLERS



FEATURES

Designed for use with the A2 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

O-ring provides hydraulic seal

Color coded for the appropriate coupler size

SPECIFICATIONS


Material High Density Polyethylene (HDPE)

Catalog Number	Rebar Size, US	Rebar Size, Canada	Width 1(W1)	Width 2(W2)	A	Height(H)	Color
ELICP20	#6	20M	2.250"	0.500"	0.390"	0.440"	Yellow
ELICP22	#7		2.380"	0.500"	0.520"	0.440"	Blue
ELICP25	#8	25M	2.500"	0.500"	0.520"	0.440"	Red
ELICP28	#9	30M	2.630"	0.500"	0.520"	0.440"	Black
ELICP32	#10		2.750"	0.500"	0.520"	0.440"	Yellow
ELICP36	#11	35M	2.940"	0.500"	0.520"	0.440"	Blue
ELICP43	#14	45M	3.250"	0.500"	0.520"	0.440"	Red
ELICP57	#18	55M	4"	0.500"	0.520"	0.440"	Blue

ADDITIONAL PRODUCT DETAILS

ELICP36 can also be used with P8/P9 position couplers for form saving applications (sizes 20, 22, 25 only).

DIAGRAMS

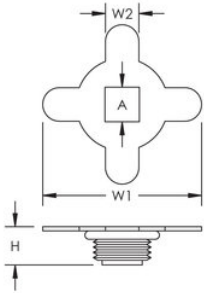

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.