


# P14 POSITION TRANSITION COUPLER, WORLDWIDE DESIGN

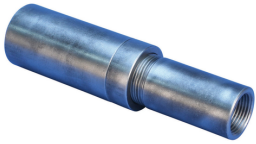

## CERTIFICATIONS



## FEATURES

Used to splice different diameter bars

Designed to splice two curved, bent or straight bars, when neither bar can be rotated and where the ongoing bar is free to move in its axial direction

## SPECIFICATIONS

<b>Finish</b>	Plain
<b>Material</b>	Steel
<b>Design Version</b>	Worldwide (Globally Available Materials)
<b>100% U.S. Domestic Content</b>	Yes

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Length 2(L2)	Length 1(L1)	Bar Depth 1(BD1)	Bar Depth 2(BD2)	Bar Gap 1(BG1)	Bar Gap 2(BG2)	Coupler Body(CB)	Certifications
EL2016P14L	#6, #5	20M, 15M	1.380"	6.430"	5.980"	1.38"	0.94"	2.28"	2.73"	2.98"	DIBt
EL2216P14L	#7, #5		1.570"	6.760"	6.310"	1.46"	0.94"	3.79"	4.24"	3.15"	

 
## Designed to Meet

AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600;BS EN 1992-1-1;BS EN 1992-2;CAN/CSA - N287.2/.3/.4;DIN EN 1992-1-1;Eurocode 2;IBC Type 1 (125% Specified Yield);IBC Type 2 (Specified Tensile);ISO 15835;NEN EN 1992-1-1;NF A 35-020-1;NF EN 1992-1-1;ÖNORM EN 1992-1-1;Sellafield Ltd. Std. ES\_0\_3110;US Army Corps of Engineers;CAN/CSA - A23.3

## ADDITIONAL PRODUCT DETAILS

Bar dimensions and weights listed may vary by region. Coupler sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**nVent.com** CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.