

T-SERIES VERTICAL LOW SLIP SLEEVE



FEATURES

Designed to connect vertical reinforcing bars and angular reinforcing bars greater than 45 degrees

Used to splice the same diameter bars

Additional length improves performance

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

SPECIFICATIONS

Finish	Plain
Material	Steel
100% U.S. Domestic Content	Yes

Catalog Number	Rebar Size, US	Rebar Size, Canada	Diameter 1(Ø1)	Diameter 2(Ø2)	Length 1(L1)	Length 2(L2)	Unit Weight
RBW6555A	#5	15M	1.380"	0.880"	6"	3"	1.500 lb
RBW6556A	#6	20M	1.500"	1"	7"	3.500"	1.900 lb
RBW6557A	#7		1.620"	1.130"	7"	3.500"	2.100 lb
RBW6558A	#8	25M	1.880"	1.250"	7"	3.500"	3 lb
RBW6559A	#9	30M	2.130"	1.500"	7"	3.500"	3.500 lb
RBW65510A	#10		2.250"	1.630"	7.500"	3.750"	4 lb
RBW65511A	#11	35M	2.500"	1.750"	8"	4"	5.600 lb
RBW65514A	#14	45M	3"	2.130"	9"	4.500"	8.900 lb
RBW65518A	#18	55M	3.750"	2.630"	11"	5.500"	17.500 lb

Designed to Meet

AASHTO;ABNT NBR 8548:1984;ACI 318 Type 1 (125% Specified Yield);ACI 318 Type 2 (Specified Tensile);ACI 349;ACI 359;AS3600;CAN/CSA - N287.2/.3/.4;IBC Type 1 (125% Specified Yield);IBC Type 2 (Specified Tensile);US Army Corps of Engineers;CAN/CSA - A23.3


ADDITIONAL PRODUCT DETAILS

The low slip vertical T-Series sleeve's increased sleeve length reduces slip (for extreme code requirements) and improves splice performance when the rib pattern or spacing does not meet the minimum product specifications.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

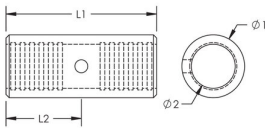

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.