


**Floor standing
enclosures Compact
version**
Stainless steel


MOUNTING INSTRUCTIONS

6885-0120-01 REV 9

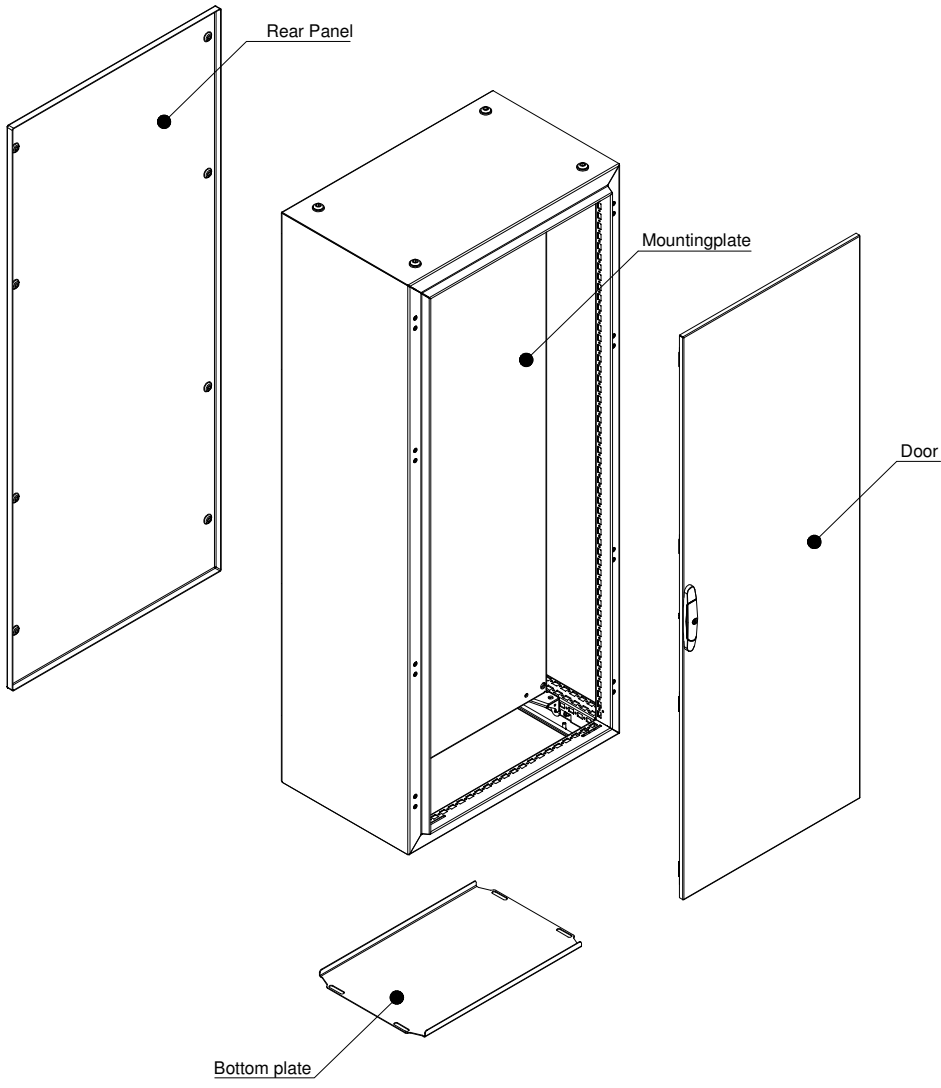





Standard Locking System

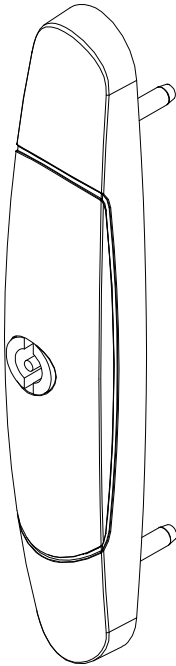








Lift Handle Locking System

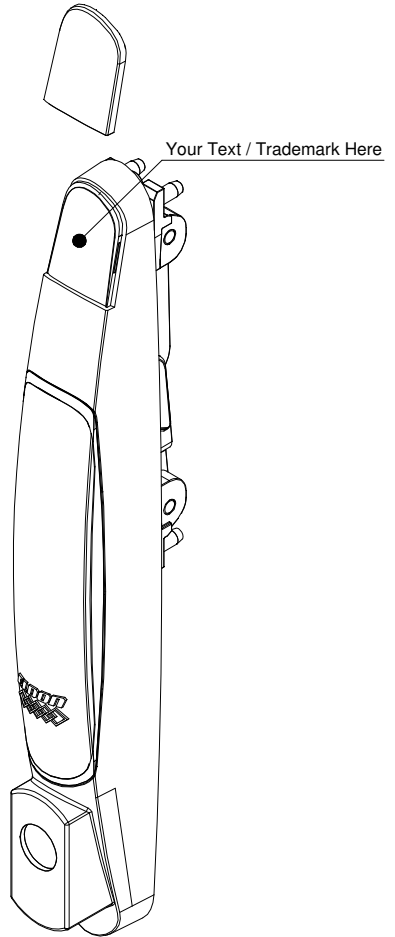

EKDS DOORS

 







Ref.	Pic.	Qty.
A	M5x10	8
B	M6x10	2
C	M6	2
D	M5x10	16
E		2
F		2

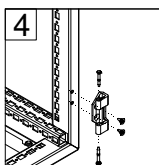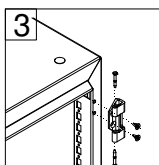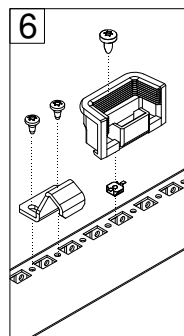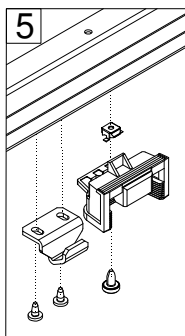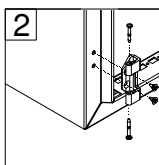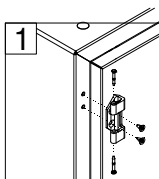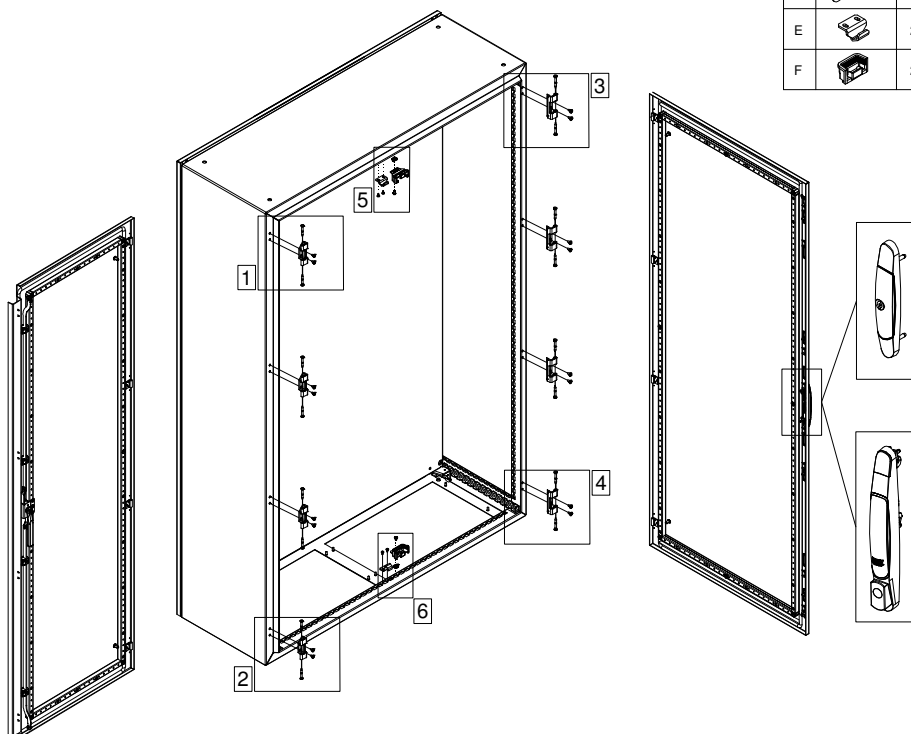

MOUNTING LSEL




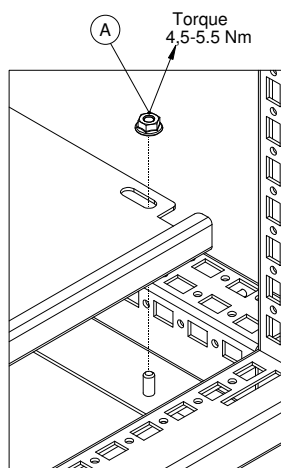
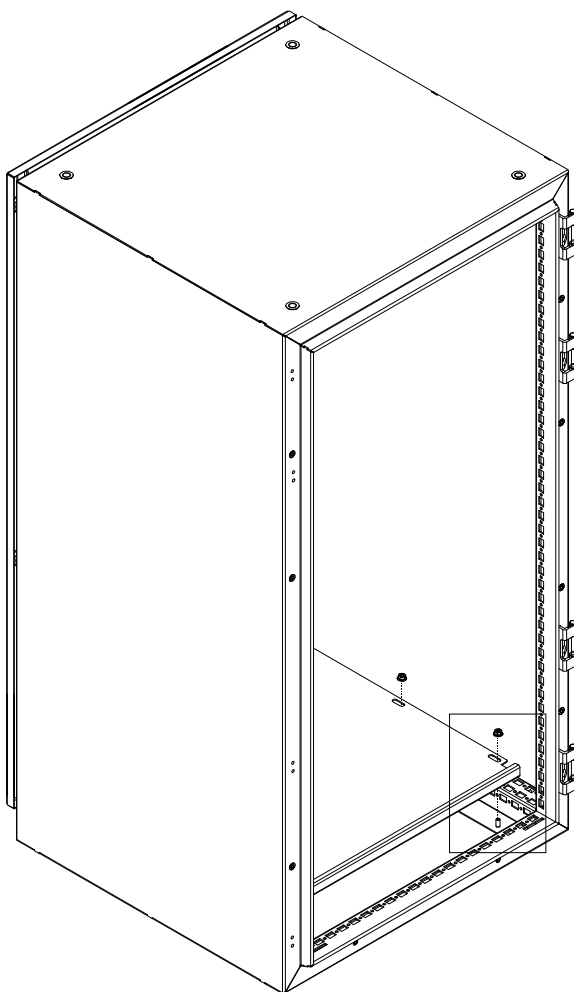
Ref.	Pic.	Qty.
A		6
B		4
C		8
D		1
E		1

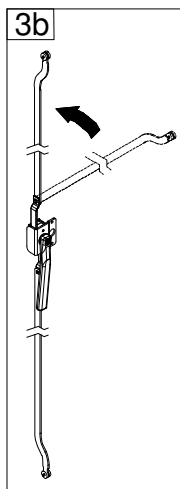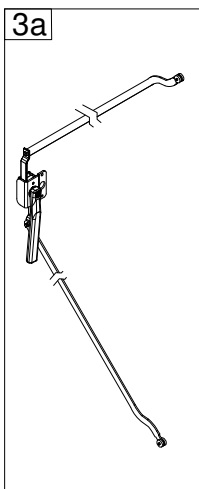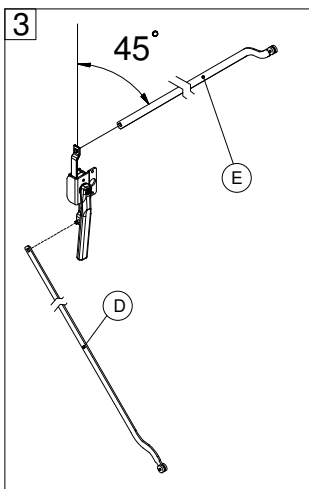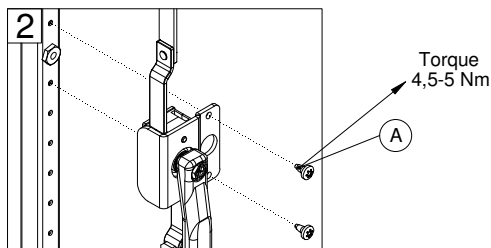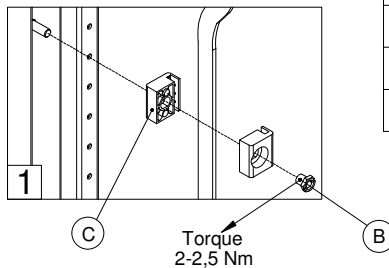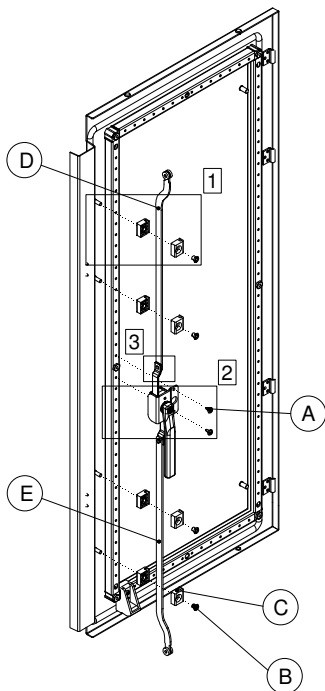

BOTTOM PLATE





Ref.	Pic.	Qty.
A		6



EKSS REAR PANEL




Ref.	Pic.	Qty.
A		24/26/28
B		6
C		1
D		1
E		2/4
F		2/4
G		2/4

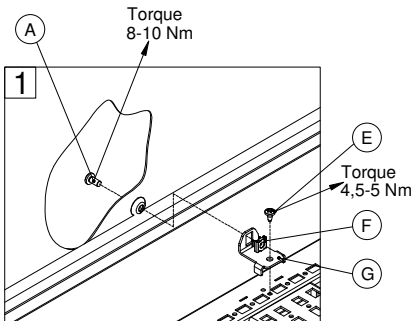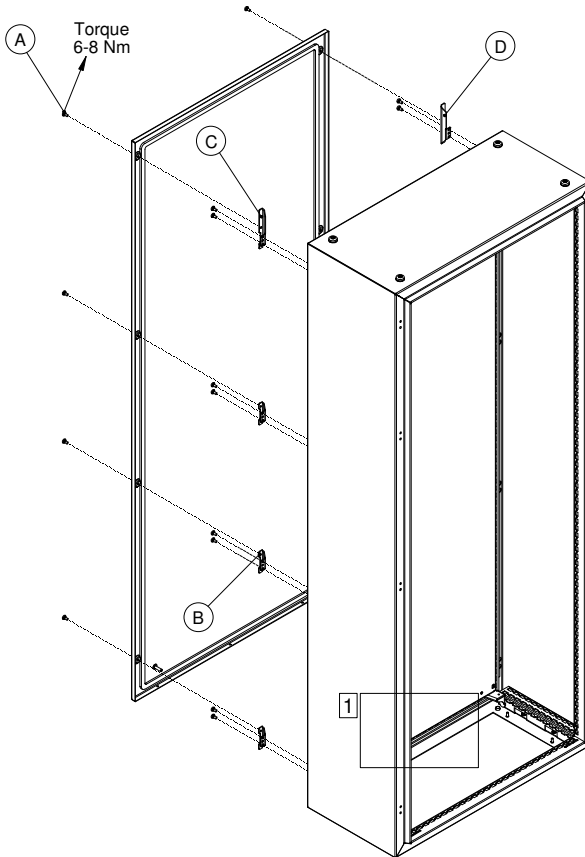


Enclosure width (mm)				
<1000	-	-	-	-
1000	2	2	2	2
1200	2	2	2	2
1600	4	4	4	4







MOUNTING PLATE

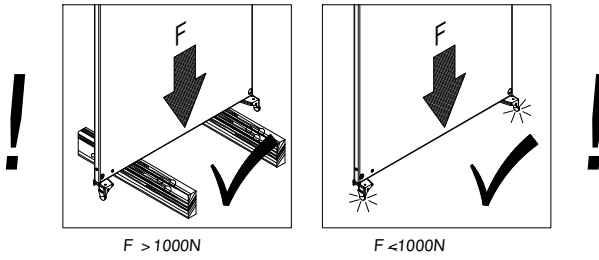



Ref.	Pic.	Qty.
A		2
B		2
C		2
D		1
E		1

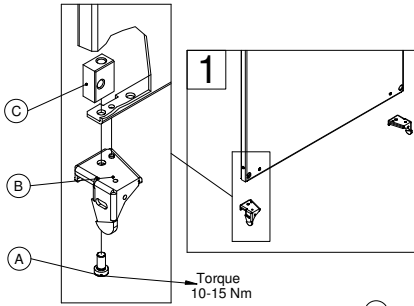


MOUNTING

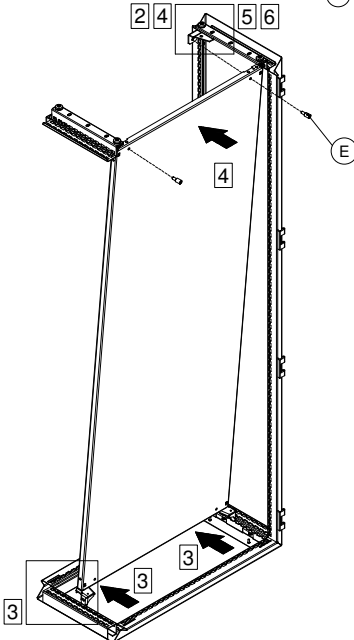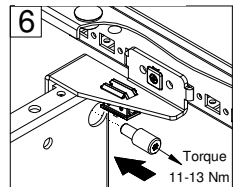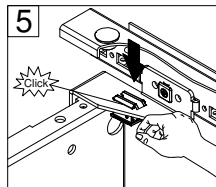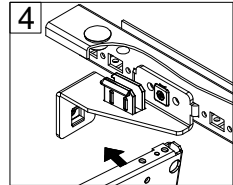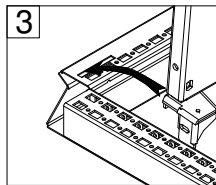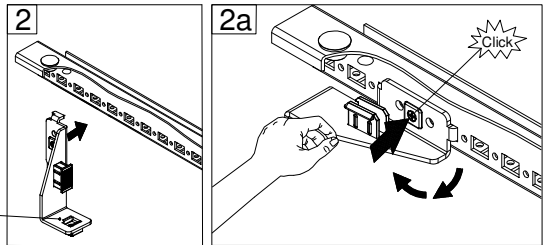


UNMOUNTING

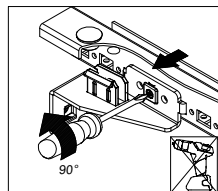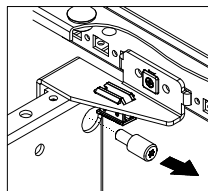







MPD02

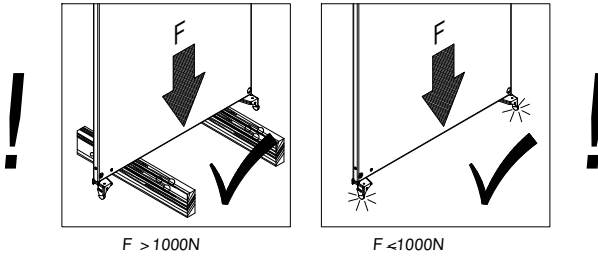



Ref.	Pic.	Qty.
A		2
B		2
C		2
D		1
E		1

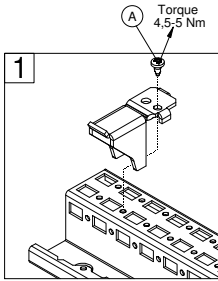

MOUNTING

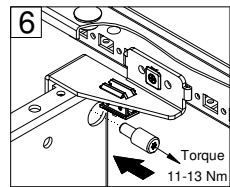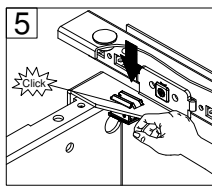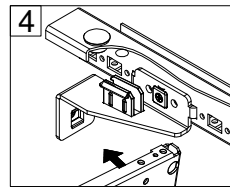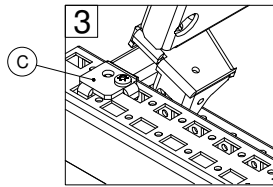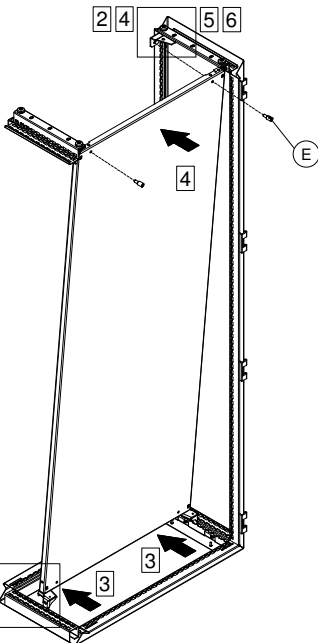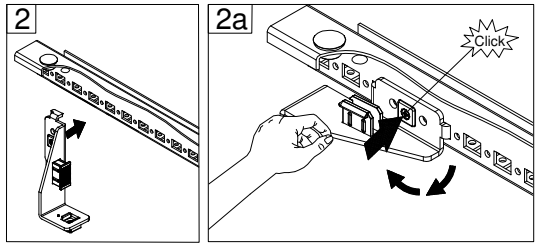


UNMOUNTING

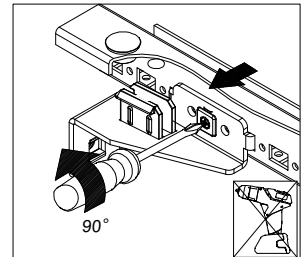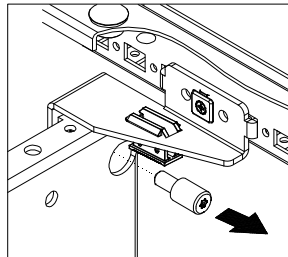


PFS/PSS








Ref.	Pic.	Qty.
A		4/8
B		4
C		4
D		4
E		4

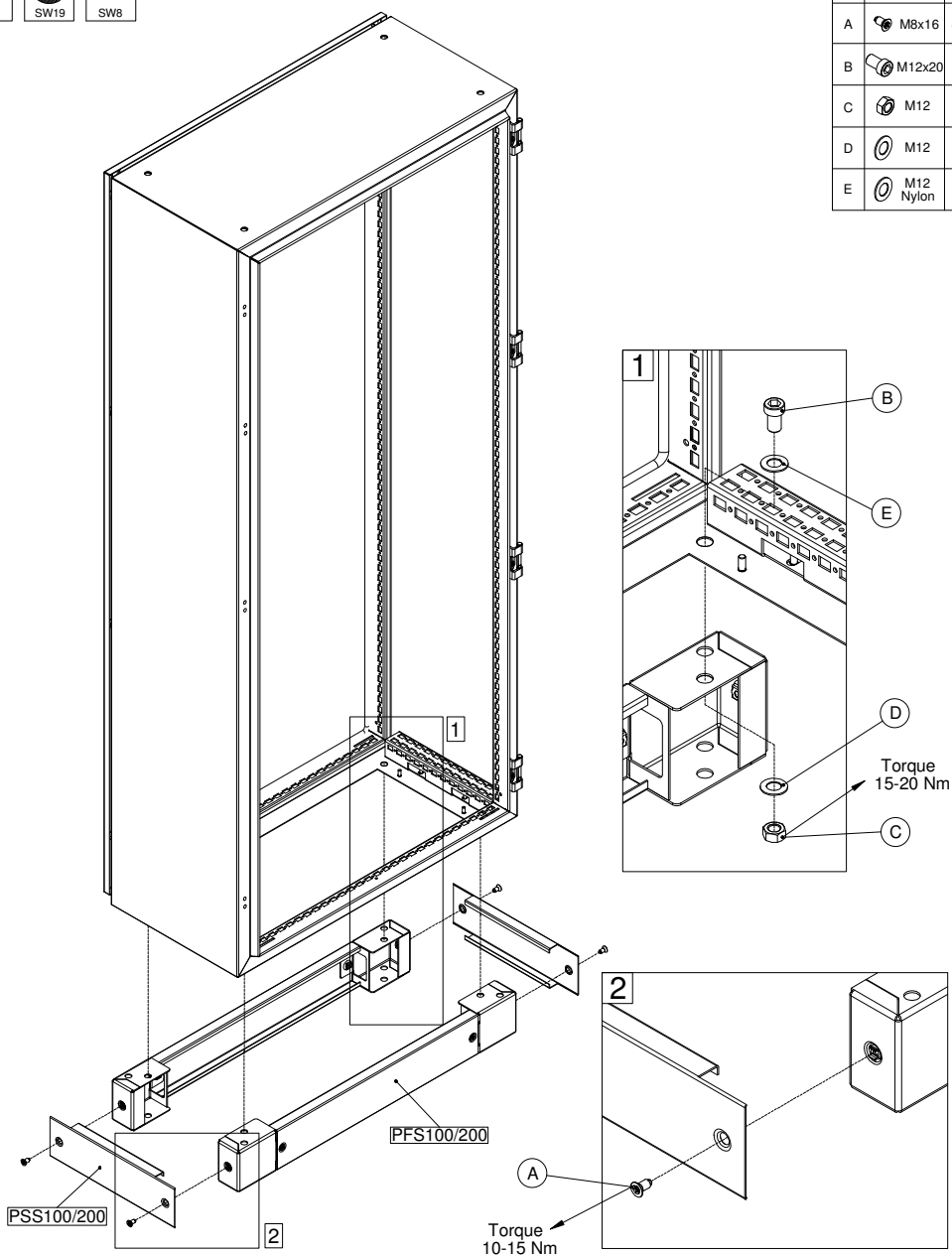

DHN 180





 






Ref.	Pic.	Qty.
A		8

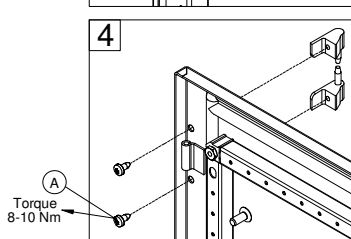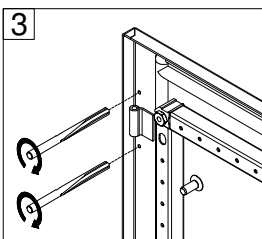
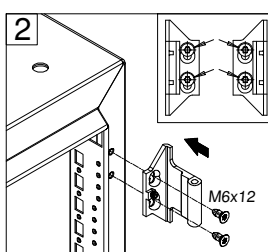
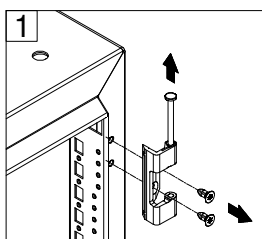
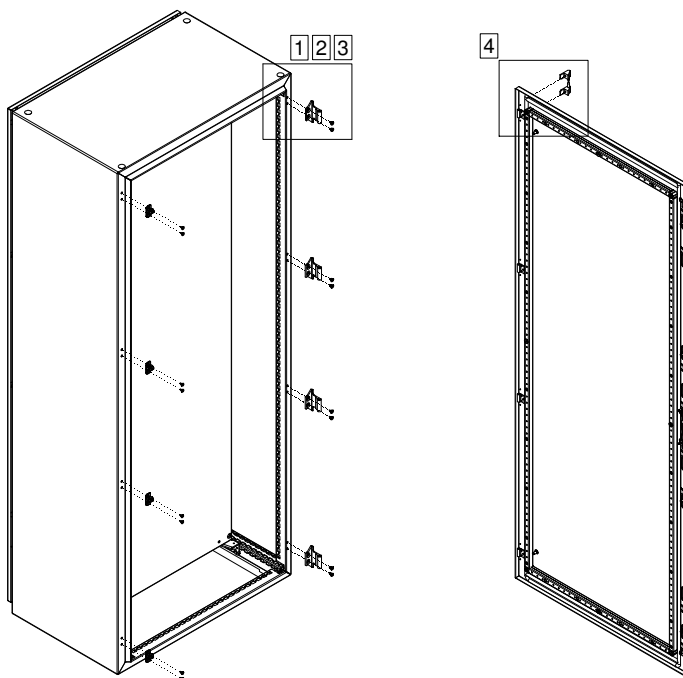


DHN 180

Door adjustment

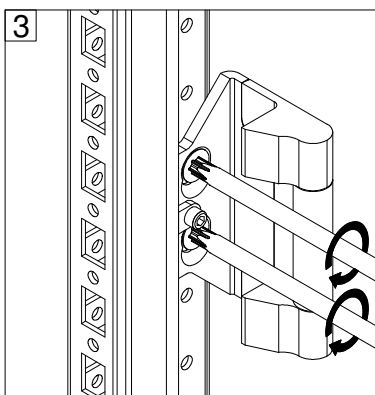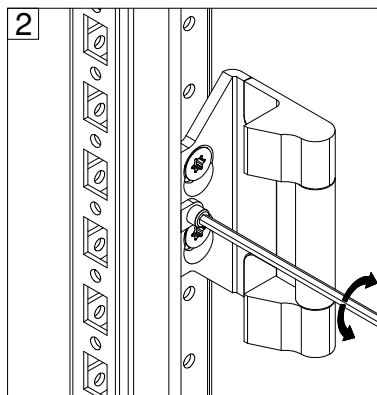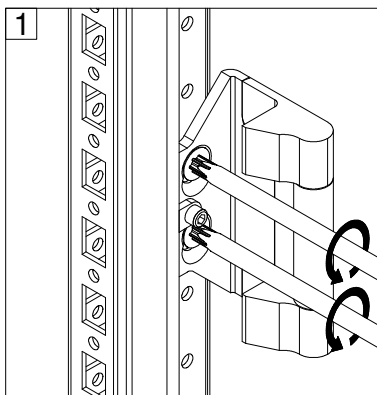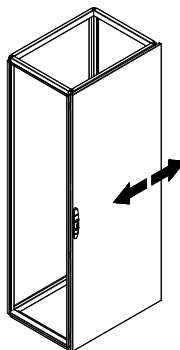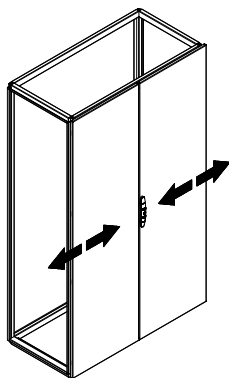

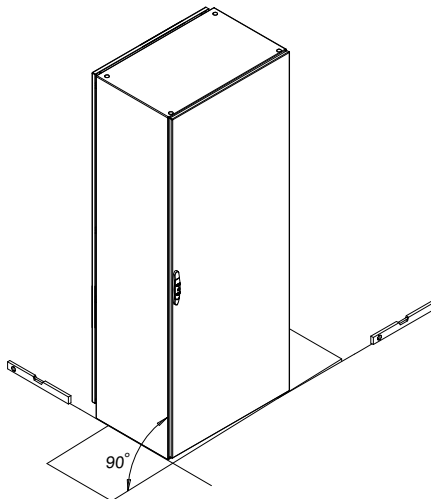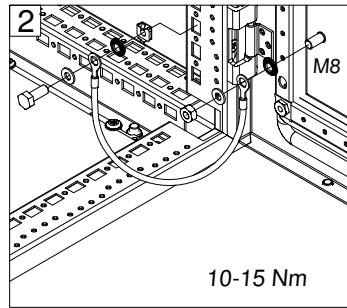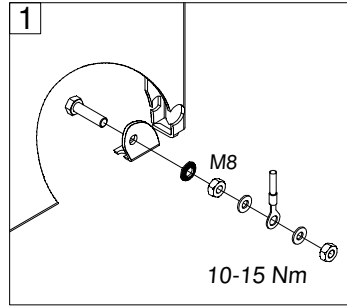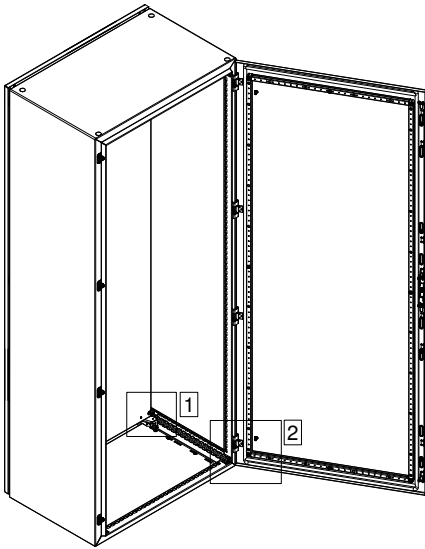


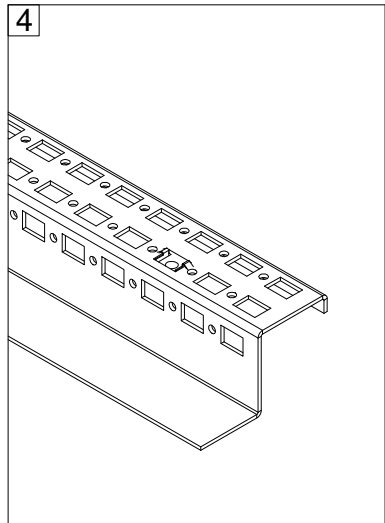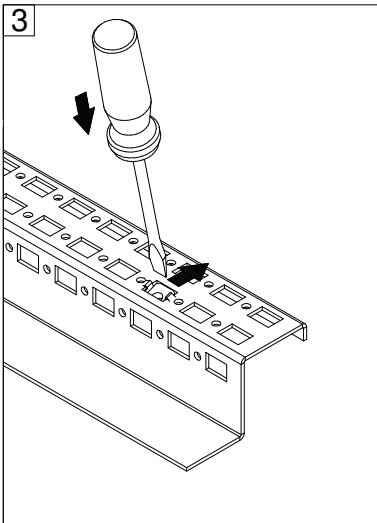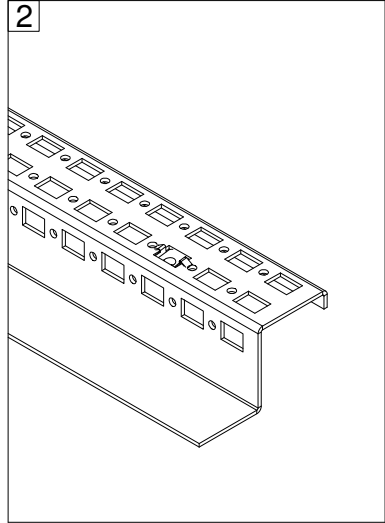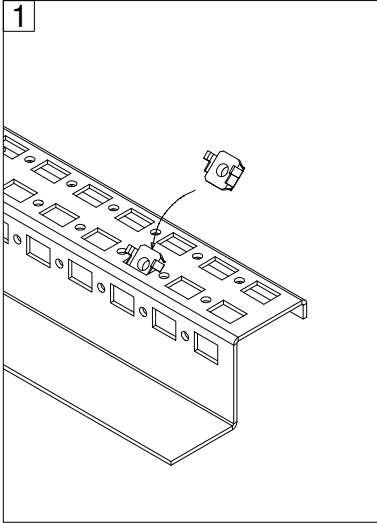





CCB02


Ref.	Pic.	Qty.
A		2
B		4
C		2

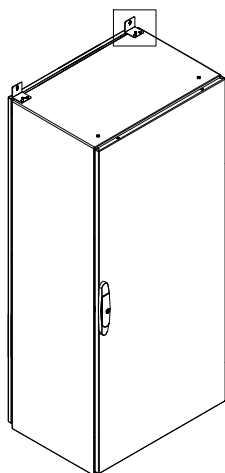

1xCCB02

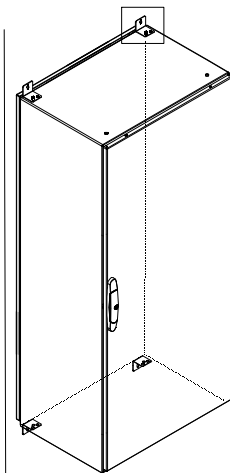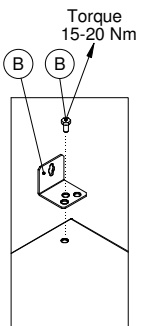

2xCCB02

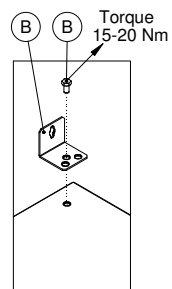

LE9304SS

