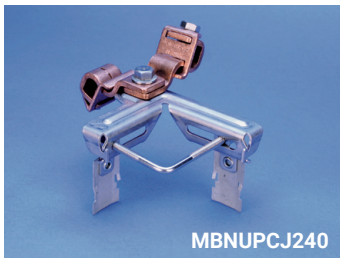


UNIVERSAL PEDESTAL CLAMP WITH CABLE MANAGEMENT FEATURE


MBNUPCJ240

MBNUPCJ82

FEATURES

- Only one attachment required for both mesh bonding and cable management
- Eliminates need for separate mounting brackets for different pedestal types or sizes
- Stainless steel construction of bracket and hardware reduces potential for galvanic corrosion
- Mesh bonding conductors do not have to be bent around each pedestal to conform to grid pattern
- Reduces material and labor cost
- Provides attachment points for nVent CADDY Cat Links J-Hooks
- Code compliance (NEC® Article 250 and NEC Article 300)
- UL® Listed as a grounding/bonding clamp in addition to a cable support

The Universal Pedestal Clamp, from nVent ERICO, allows for fast, simple and economical field construction of mesh bonding network (MBN) and cable management systems in data centers and computer rooms. In addition to multiple cross-wire bonding connections, each connector will also accommodate additional pigtails that can be used to connect to building steel and equipment.

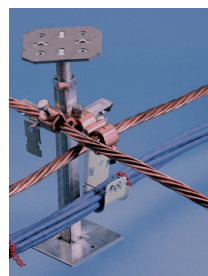
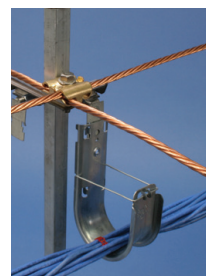
UNIVERSAL PEDESTAL CLAMP

Part Number	Pedestal Size (Round or Square)	Conductor Size Range	Standard Packaging Quantity
MBNUPCJ82	7/8" - 2" (2.2 cm - 5.1 cm)	#8 AWG - #2 AWG (10 mm ² - 35 mm ²) Solid or Stranded	25
MBNUPCJ240	7/8" - 2" (2.2 cm - 5.1 cm)	#2 AWG - 4/0 AWG (35 mm ² - 100 mm ²) Solid or Stranded	25

COMPATIBLE J-HOOK SIZES

Part Number	Diameter	Standard Packaging Quantity
CAT16HP	1" (25 mm)	50
CAT32HP	2" (50 mm)	50
CAT48HP	3" (75 mm)	25
CAT64HP	4" (100 mm)	25

J-Hooks may be combined in trees, with a load not exceeding 50 lbs (22.7 kg).


**MBNUPCJ240 +
CAT32HP (2" J-Hook)**

**MBNUPCJ82 +
CAT48HP (3" J-Hook)**

**MBNUPCJ82 +
CAT32HP (2" J-Hook) +
CAT48HP (3" J-Hook)**