

NVENT CADDY ALL-IN-ONE DATA SOLUTIONS



FEATURES

- Available with 4-11/16" or 5" boxes for increased capacity
- Adapter plate can be used without a box for data solutions that do not require an enclosure
- 4" mudrings can be used with 4-11/16" boxes reducing unnecessary components
- Adapter plate slides in the bracket to easily customize box location
- Easily allows 4-11/16" boxes to be attached to adapter plate without removing screws
- Can be used with 4" All-In-One boxes.

ALL-IN-ONE BETWEEN-STUD WITH REMOVABLE MUD RING, MULTI-BOX

- Comes with multiple boxes pre-assembled for side by side power and data applications
- Removable mud ring provides front access to the interior of the box
- Pre-bent tabs on support bracket help to quickly square assembly to stud
- Center marks provide easy height positioning
- Includes multiple knockouts on each side of the box

Material: Steel
 Finish: Pregalvanized
 Knockout Sizes, Box 1: (8) 1/2", 3/4"; (3) 1/2"



Part Number	Gang, Box 1	Ground Wire Included, Box 1	Volume, Box 1	Gang, Box 2	Ground Wire Included, Box 2	Volume, Box 2	Drywall Thickness	Stud Spacing	Depth	Height	Window Height
A1BF1G41NAO	1	Yes	32.8 in ³	1	No	–	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF2G41NAO	2	Yes	32.8 in ³	1	No	–	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF3G43NAO	1	Yes	32.8 in ³	1	No	–	1 1/4"	16" – 24"	3 5/8"	5 3/4"	4 1/8"


Knockout Sizes, Box 2: (4) 1"; (4) 1 1/4"

Part Number	Gang, Box 1	Ground Wire Included, Box 1	Volume, Box 1	Gang, Box 2	Ground Wire Included, Box 2	Volume, Box 2	Drywall Thickness	Stud Spacing	Depth	Height	Window Height
A1BF1G41N	1	Yes	32.8 in ³	1	No	42 in ³	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF1G51N	1	Yes	32.8 in ³	1	No	64 in ³	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF2G41N	2	Yes	32.8 in ³	1	No	42 in ³	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF2G51N	2	Yes	32.8 in ³	1	No	64 in ³	5/8"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF3G43N	1	Yes	32.8 in ³	1	No	42 in ³	1 1/4"	16" – 24"	3 5/8"	5 3/4"	4 1/8"
A1BF3G53N	1	Yes	32.8 in ³	1	No	64 in ³	1 1/4"	16" – 24"	3 5/8"	5 3/4"	4 1/8"

Ground wire pigtail is 10".
 24" stud spacing requires use of three mounting screws.
 Use only with All-In-One box assemblies.

ALL-IN-ONE BETWEEN-STUD WITHOUT MUD RING, MULTI-BOX

- Comes with multiple boxes pre-assembled for side by side power and data applications
- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Pre-bent tabs on support bracket help to quickly square assembly to stud
- Center marks provide easy height positioning
- Includes multiple knockouts on each side of the box
- Works with standard US and Canadian mud rings

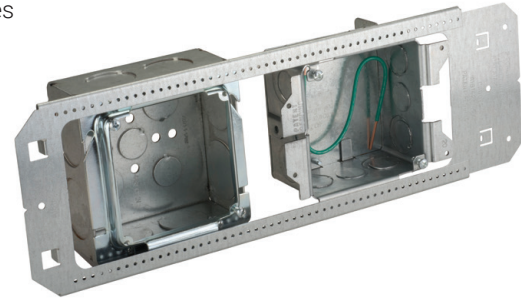

Material: Steel

Finish: Pregalvanized

Knockout Sizes, Box 1: (8) 1/2", 3/4"; (3) 1/2"



Part Number	Ground Wire Included, Box 1	Volume, Box 1	Ground Wire Included, Box 2	Volume, Box 2	Stud Spacing	Depth	Width	Window Height
A1BF0G40NAO	Yes	32.8 in ³	No	–	16" – 24"	3 5/8"	5 3/8"	4 1/8"

Knockout Sizes, Box 2: (4) 1"; (4) 1 1/4"

Part Number	Ground Wire Included, Box 1	Volume, Box 1	Ground Wire Included, Box 2	Volume, Box 2	Stud Spacing	Depth	Width	Window Height
A1BF0G40N	Yes	32.8 in ³	No	42 in ³	16" – 24"	3 5/8"	5 3/8"	4 1/8"

ADAPTER PLATE

- Supports 4-11/16" box to All-In-One Between-Stud Bracket
- Allows 4" mud ring to be attached to a 4-11/16" box

Material: Steel

Finish: Pregalvanized



Part Number

TBSBA4



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

UL, UR, cUL, cUR, cULus and cURus are registered certification marks of UL LLC

WARNING: nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at nVent.com/CADDY and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

©2018 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice.

CADDY-DS-F1287S-DF198LT17NAEN-EN-1805