


H - Spring Steel Clips

EM - Spring Steel Clips

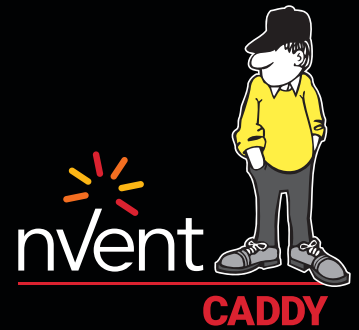

NEW FLANGE THICKNESS 21 – 28 MM

NEW!




FEATURES

- Time saving due to hammer-on installation
- No drilling, cutting, welding
- nVent CADDY H – Flange Clip – Thickness: 2 – 3 mm, 3 – 8 mm, 8 – 14 mm, 14 – 20 mm, **21 – 28 mm**
- Superior corrosion protection by nVent CADDY Armour

Product	Part Number	Article Number	Flange Thickness	Size	Static Load	PU
Universal Flange Clip						
	4H1318	170045	21 – 28 mm	7,1 mm Hole	900 N	50
Cable Tie Holder with Flange Clip						
	4H1318CT	178545	21 – 28 mm	max. 9 x 2 mm Cable Ties	150 N	100
Cable Retainer Strap with Flange Clip						
	4H1318ST3	171775	21 – 28 mm	69 mm Rod Length		100
H-PSM Conduit to Flange Clip, Side Mount						
	812M1318SM	160145	21 – 28 mm	18 – 30 mm Pipe Size	120 N	100




NEW FLANGE THICKNESS 21 – 28 MM

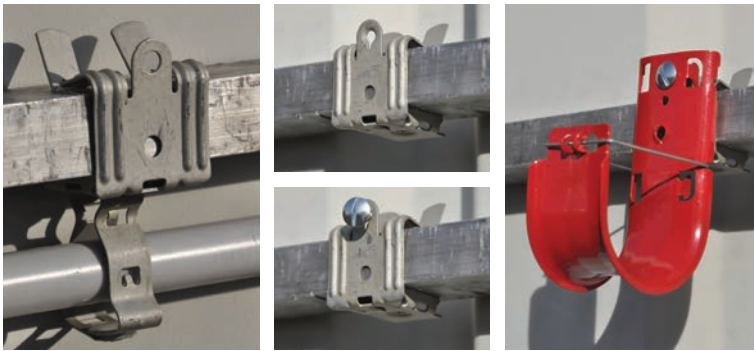NEW!



FEATURES

- Time saving due to hammer-on installation
- No drilling, cutting, welding
- nVent CADDY EM – Flange Clip – Thickness: 2 – 3 mm, 3 – 8 mm, 8 – 14 mm, 14 – 20 mm, **21 – 28 mm**
- Superior corrosion protection by nVent CADDY Armour

Product	Part Number	Article Number	Flange Thickness	Size	Static Load	PU
Hammer-On Flange Clip, Bottom Mount						
	EM1318	170075	21 - 28 mm	M6 Connections	450 N	50
Hammer-On Flange Clip, Bottom Mount with Stud						
	EM1318SM	171855	21 - 28 mm	M6 x 11 mm	450 N	50
EM-M Conduit/Pipe to Flange Clip						
	812EM1318	160075	21 - 28 mm	18 – 30 mm Pipe Size	330 N	50
	16EM1318	173745	21 - 28 mm	30 – 35 mm Pipe Size	330 N	50



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER

WARNING: nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at nVent.com/CADDY and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

©2019 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without notice. CADDY-DS-H84858-EM4HDataSheet-UKEN-1905