



# nVent CADDY Metal Deck Solutions

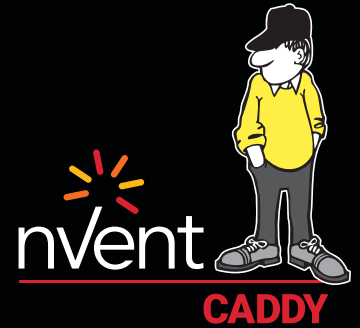

## SCD DOVETAIL MOUNT CABLE SNAP CLIP ADAPTOR

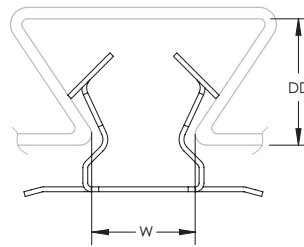

### FEATURES


- Adaptor to fix up to two 24SC Snap Clips to a dovetail deck
- Provides support for low voltage cables

Material: Spring Steel  
Finish: nVent CADDY Armour



Part Number	Article Number	Width W	Dovetail Depth DD	Standard Packaging Quantity	TATA Approved		
					ComFlor® 51+	ComFlor® 60	ComFlor® 80
SCD1217	188170	12 – 17 mm	14 mm min	100 pc	✓	✓	✓
SCD1722	188180	17 – 22 mm	14 mm min	100 pc	✓		

## SC CABLE SNAP CLIP

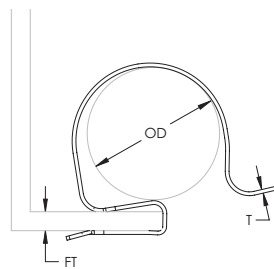


### FEATURES

- Easily attaches to both sides of the SCD Clip
- Simply pushes on

Material: Spring Steel  
Finish: nVent CADDY Armour

Part Number	Article Number	Flange Thickness FT	Outer Diameter OD	Thickness T	Standard Packaging Quantity
24SC67	187510	2 – 4 mm	6 – 7 mm	0.6 mm	100 pc
24SC78	187710	2 – 4 mm	7 – 8 mm	0.6 mm	100 pc
24SC89	187530	2 – 4 mm	8 – 9 mm	0.6 mm	100 pc
24SC910	187750	2 – 4 mm	9 – 10 mm	0.6 mm	100 pc
24SC1011	187550	2 – 4 mm	10 – 11 mm	0.6 mm	100 pc
24SC1214	187570	2 – 4 mm	12 – 14 mm	0.6 mm	100 pc
24SC1518	187590	2 – 4 mm	15 – 18 mm	0.6 mm	100 pc
24SC1924	187610	2 – 4 mm	19 – 24 mm	0.6 mm	100 pc
24SC2530	187630	2 – 4 mm	25 – 32 mm	0.6 mm	100 pc

# SCD MULTI-CABLE TO DECK CLIP

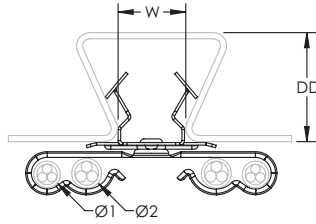

## FEATURES

- Provides support for low voltage cables
- Flared edges for cable protection
- Rotates 360 degrees to support various directional runs of cable
- No tools required for installation

Material: Spring Steel  
Finish: nVent CADDY Armour



Part Number	Article Number	Cable Capacity	Diameter 1 Ø1	Diameter 2 Ø2	Dovetail Depth DD	Width W	Standard Packaging Quantity	TATA Approved		
								ComFlor® 51+	ComFlor® 60	ComFlor® 80
SCD1217QSC	188175	4	7 – 8 mm	8 – 12 mm	14 mm min	12 – 17 mm	100 pc	✓	✓	✓
SCD1722QSC	188185	4	7 – 8 mm	8 – 12 mm	14 mm min	17 – 22 mm	100 pc	✓		



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**