


# Flat Rigid Box Support

## CONNECT AND PROTECT

The nVent CADDY FB16 Flat Rigid Box Support is rigid and completely flat with no offset, providing flexibility and strength within the stud wall. Regardless of the box and mud ring combination you're planning for, the FB16 bracket is able to accommodate and provide a mounting option. Because it is designed completely flat, you have multiple configuration options, limiting SKUs needed on a job, saving time. As part of the comprehensive line of nVent CADDY In-Wall products, the FB16 bracket delivers versatility and efficiency.

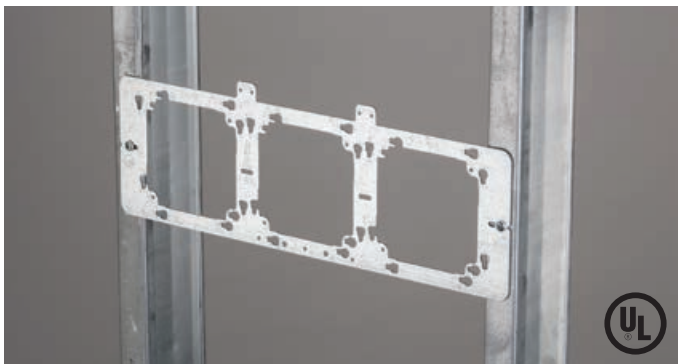

Material: Steel  
Finish: Pregalvanized

### FEATURES

- Created from one single piece of steel with no offset resulting in a completely flat bracket
- Accepts any mud ring shape in either vertical or horizontal orientation
- Mounting holes allow mounting of mud rings for both power and data applications
- Stamped with A- and B-side markings that allow mounting for all box types and configurations – no need for removal of screws – simply flip and it's ready to use
- Meets UL514 minimum thickness requirements to use for both power and datacom applications, without the need for extra adapter plate components

Part Number	Number of Boxes	Box Depth	Box Size	Stud Spacing
FB16	3	1 1/2", 2 1/8", 2 1/2", 2 7/8", 3", 3 1/4", 3 1/2"	4", 4 11/16", 5"	8" – 16"

## First means of support for Flat Rigid Box Support



Material: Steel  
Finish: Pregalvanized

### FEATURES

- Provides reliable, rigid, support when mounted to the top of the Flat Rigid Box Support
- Securely holds within the stud space and is compatible with the "Colorado Jim" Cable Support to secure flexible cables
- Use self drilling/tapping screws for mounting onto bracket

Part Number	Standard Packaging Quantity
FB16FM	50 pc