


Multi-Function Clip



CONNECT AND PROTECT

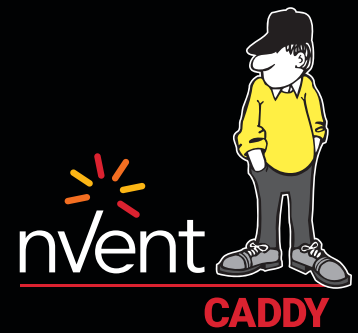

FEATURES

- Increased capability and application options by combining 4Z and 6Z products into one enhanced and efficient offering
- Improved multi-function clip allows for optimized inventory while reducing job site scheduling risks associated with multiple SKUs
- Instills more confidence installing conduit, MC/AC, and low voltage applications
- Can accommodate 1/4", 5/16" & 3/8" threaded rod sizes

Material: Spring Steel
Finish: nVent CADDY Armour



Part Number	Rod Size RS	Wire Size	Flange Thickness FT	Hole Size HS	Screw Included	Screw Diameter Sc	Static Load 1 F1	Static Load 2 F2	Certifications	Standard Packaging Quantity
4Z34	1/4", 5/16" & 3/8"	#12 – #8	1/8" – 7/16"	1/4"	No	–	25 lb	20 lb	cULus, ITB	100 pc
4Z4S	1/4", 5/16" & 3/8"	#12 – #8	1/8" – 7/16"	–	Yes	1/4"	25 lb	20 lb	cULus	100 pc
8Z34	1/2", 5/8"	–	–	1/4"	No	–	–	50 lb	cULus	100 pc
8Z4S	1/2", 5/8"	–	–	–	Yes	1/4"	–	50 lb	cULus	100 pc

1/2" and 5/8" rod sizes are to be installed on threaded rod only.

NEC® 300.11 requires dedicated drop wire/rod and EC311.

6Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER