


# Universal busbar support

Universal busbar support

nVent

HOFFMAN

CONNECT AND PROTECT

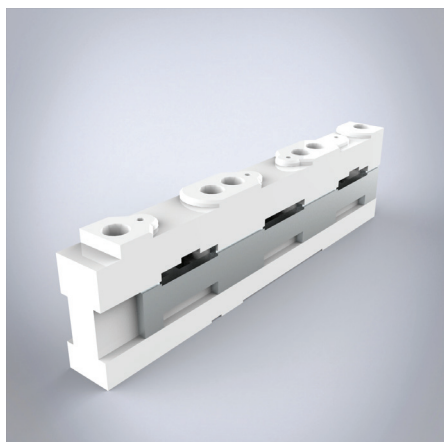

**Description:** Universal busbar support 3/4-Pole with internal screw holes, delivered without end cover.

**Rated voltage:** 690 V

**Rated frequency:** 50/60 Hz

**Rated isolation voltage  $U_i$ :** 1000 V

**Rated surge voltage  $U_{imp}$ :** 8 kV

**Approvals:** GL, DNV GL

N° of Poles	Dimensions	For busbar	Pack quantity	Item no.
4	20 × 242 × 51	12, 15, 20, 25, 30 × 5, 11	10 pcs.	01485
3	20 × 191 × 50	12, 15, 20, 25, 30 × 5, 10	10 pcs.	01495