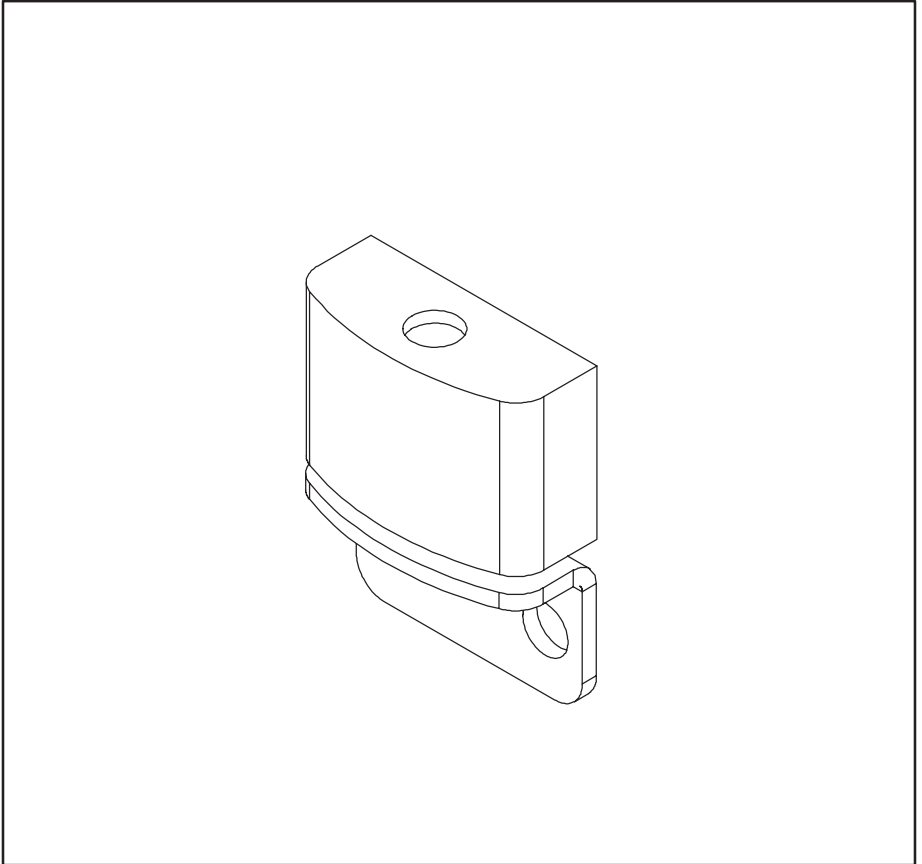
 

 
 


 







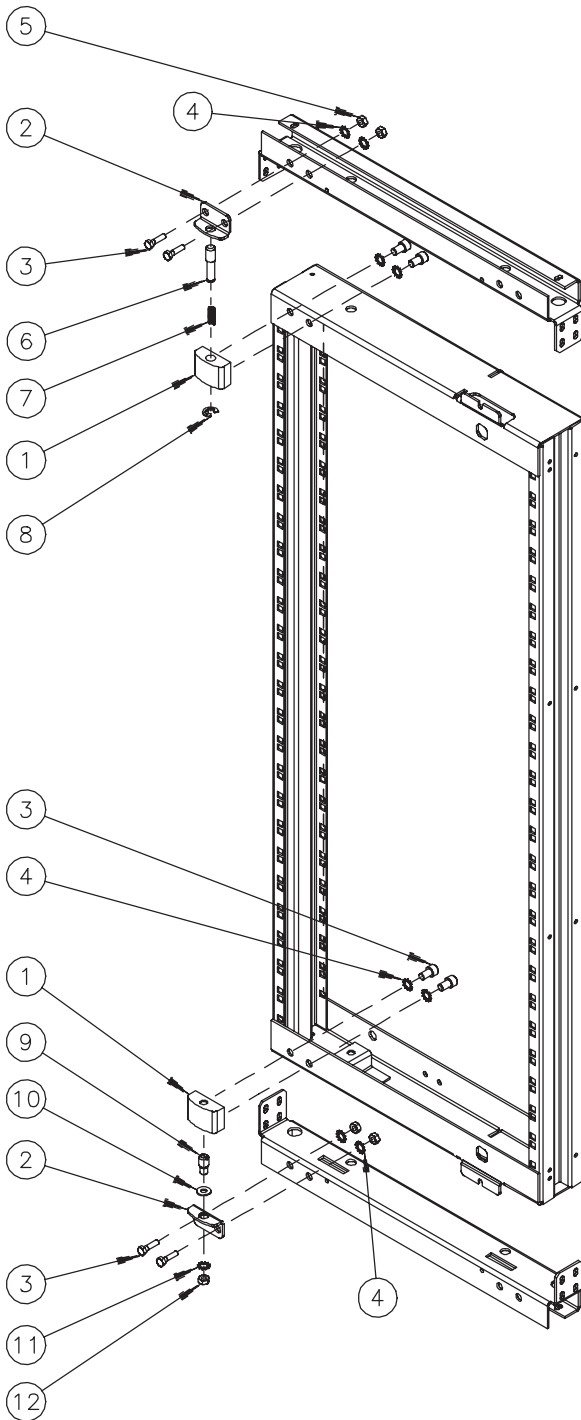


HOFFMAN

PROLINE®
170° Hinge Kit



<p>1</p>  <p>(2x)</p>	<p>5</p> <p>M10</p>  <p>(4x)</p>	<p>9</p>  <p>With Swing Frame</p>
<p>2</p>  <p>(2x)</p>	<p>6</p>  <p>With Swing Frame</p>	<p>10</p>  <p>With Swing Frame</p>
<p>3</p>  <p>(8x)</p>	<p>7</p>  <p>With Swing Frame</p>	<p>11</p>  <p>With Swing Frame</p>
<p>4</p>  <p>(8x)</p>	<p>8</p>  <p>With Swing Frame</p>	<p>12</p> <p>M10</p>  <p>With Swing Frame</p>





HOFFMAN