

**EMC FRAMES**

**FEATURES**

PROLINE offers the broadest range of standard sizes in the industry.

**SPECIFICATIONS**


- Plated finish
- All plated accessories electrically bonded to frame
- Welded corners with steel corner blocks that add strength and rigidity
- 12 gauge, roll-formed frame sections for strength
- Flange on door and side openings deflects liquids away from the enclosure interior
- Rectangular frame holes are designed for metric cage nut fasteners
- Round frame holes allow numerous grounding locations using M5 thread-forming screws
- Access to both sides of frame mounting holes allows standard components to be easily installed
- Provisions for slide-in subpanel, rack mounting and accessory mounting
- Simple means for joining frames to create multiple-bay enclosures
- An open roll-formed profile design affords complete surface corrosion protection and assembly access
- Sealed mounting for all external accessories

**BULLETIN: P20, P20EM**

**Standard Product**

Catalog Number	AxBxC mm	AxBxC in.	Nominal Frame Size A x B x C	Maximum Subpanel Size (mm)	Maximum Subpanel Size (in.)	Maximum Rack Mounting Space
PF786HF	700 x 800 x 600	27.56 x 31.50 x 23.62	700 x 800 x 600	585 x 530	23.03 x 20.87	13U
PF1466HF	1400 x 600 x 600	55.12 x 23.62 x 23.62	1400 x 600 x 600	1285 x 530	50.59 x 20.87	28U
PF1485HF	1400 x 800 x 500	55.12 x 31.50 x 19.69	1400 x 800 x 500	1285 x 530	50.59 x 20.87	28U
PF1488HF	1400 x 800 x 800	55.12 x 31.50 x 31.50	1400 x 800 x 800	1285 x 530	50.59 x 20.87	28U
PF1664HF	1600 x 600 x 400	62.99 x 23.62 x 15.75	1600 x 600 x 400	1485 x 530	58.46 x 20.87	28U
PF1668HF	1600 x 600 x 800	62.99 x 23.62 x 31.50	1600 x 600 x 800	1485 x 530	58.46 x 20.87	33U
PF1866HF	1800 x 600 x 600	70.87 x 23.62 x 23.62	1800 x 600 x 600	1685 x 530	66.34 x 20.87	33U
PF1868HF	1800 x 600 x 800	70.87 x 23.62 x 31.50	1800 x 600 x 800	1685 x 530	66.34 x 20.87	38U
PF1884HF	1800 x 800 x 400	70.87 x 31.50 x 15.75	1800 x 800 x 400	1685 x 730	66.34 x 28.74	38U
PF1885HF	1800 x 800 x 500	70.87 x 31.50 x 19.69	1800 x 800 x 500	1685 x 730	66.34 x 28.74	38U
PF1886HF	1800 x 800 x 600	70.87 x 31.50 x 23.62	1800 x 800 x 600	1685 x 730	66.34 x 28.74	38U
PF1888HF	1800 x 800 x 800	70.87 x 31.50 x 31.50	1800 x 800 x 800	1685 x 730	66.34 x 28.74	38U
PF18105HF	1800 x 1000 x 500	70.87 x 39.37 x 19.69	1800 x 1000 x 500	1685 x 930	66.34 x 36.61	38U
PF18106HF	1800 x 1000 x 600	70.87 x 39.37 x 23.62	1800 x 1000 x 600	1685 x 930	66.34 x 36.61	38U
PF2065HF	2000 x 600 x 500	78.74 x 23.62 x 19.69	2000 x 600 x 500	1885 x 530	74.21 x 20.87	42U
PF2066HF	2000 x 600 x 600	78.74 x 23.62 x 23.62	2000 x 600 x 600	1885 x 530	74.21 x 20.87	42U
PF2068HF	2000 x 600 x 800	78.74 x 23.62 x 31.50	2000 x 600 x 800	1885 x 530	74.21 x 20.87	42U
PF2078HF	2000 x 700 x 800	78.74 x 27.56 x 31.50	2000 x 700 x 800	1885 x 630	74.21 x 24.80	42U
PF2084HF	2000 x 800 x 400	78.74 x 31.50 x 15.75	2000 x 800 x 400	1885 x 730	74.21 x 28.74	42U
PF2085HF	2000 x 800 x 500	78.74 x 31.50 x 19.69	2000 x 800 x 500	1885 x 730	74.21 x 28.74	42U
PF2086HF2	2000 x 800 x 600	77.95 x 31.46 x 23.15	2000 x 800 x 600	1885 x 730	74.21 x 28.74	42U
PF2088HF	2000 x 800 x 800	78.74 x 31.50 x 31.50	2000 x 800 x 800	1885 x 730	74.21 x 28.74	42U
PF2089HF	2000 x 800 x 900	78.74 x 31.50 x 35.43	2000 x 800 x 900	1885 x 730	74.21 x 28.74	42U
PF20105HF	2000 x 1000 x 500	78.74 x 39.37 x 19.69	2000 x 1000 x 500	1885 x 930	74.21 x 36.61	42U
PF20106HF	2000 x 1000 x 600	78.74 x 39.37 x 23.62	2000 x 1000 x 600	1885 x 930	74.21 x 36.61	42U
PF20108HF	2000 x 1000 x 800	78.74 x 39.37 x 31.50	2000 x 1000 x 800	1885 x 930	74.21 x 36.61	42U
PF2266HF	2200 x 600 x 600	86.61 x 23.62 x 23.62	2200 x 600 x 600	2085 x 530	82.09 x 20.87	47U
PF2278HF	2200 x 700 x 800	86.61 x 27.56 x 31.50	2200 x 700 x 800	2085 x 630	82.09 x 24.80	47U
PF2279HF	2200 x 700 x 900	86.61 x 27.56 x 35.43	2200 x 700 x 900	2085 x 630	82.09 x 24.80	47U
PF2288HF	2200 x 800 x 800	86.61 x 31.50 x 31.50	2200 x 800 x 800	2085 x 730	82.09 x 28.74	47U
PF22105HF	2200 x 1000 x 500	86.61 x 39.37 x 19.69	2200 x 1000 x 500	2085 x 930	82.09 x 36.61	47U

1 rack unit = 1.75 in. (44 mm)

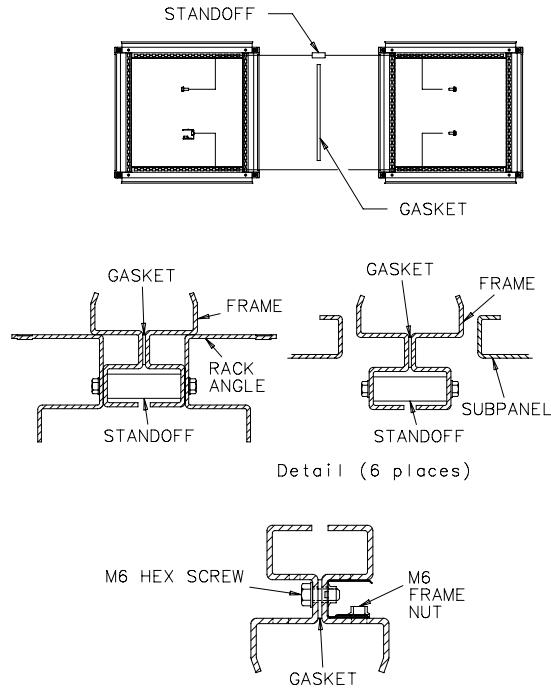

Detail (6 places)

Frame Nut Detail (optional 3 places)

87414918