

1 Phase 230V 20A basic PDU drawing & specification

RackPower

Basic Strip



Front view :



Rear view :



Top View :

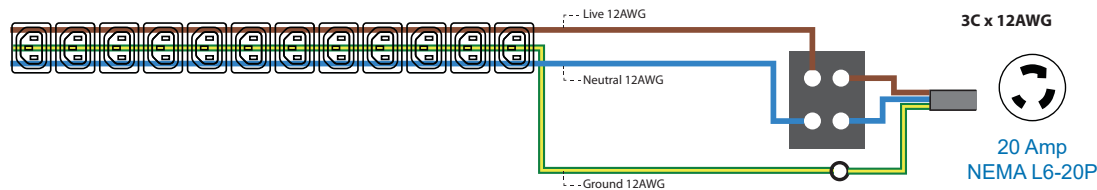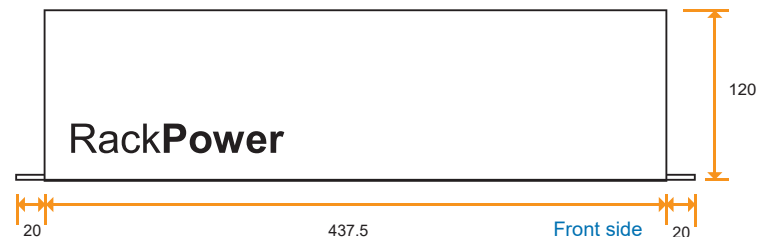

unit : mm

Single phase basic PDU

- Input Rating : 20A, 230V
- Outlet : 10A Rated C13 x 12
- Inlet : 20A NEMA L6-20P plug
- Cordset : 3 meter 12AWG cordset
- Protection : Nil
- Circuit Details : Output 20A max. C13 #1-12

- EMC Compliance : CE / EMC certified
- Safety Compliance : CE / LVD certified
- Environment Compliance : RoHS2 & REACH
- Operating Temperature : -5 to 60 °C
- Storage Temperature : -25 to 65 °C
- Operating Altitude : 0 to 2,000 m
- Storage Altitude : 0 to 15,000 m
- Humidity : 8 to 95% RH, non-condensing
- Chassis Material : Steel
- Chassis Color : Black
- Product Dimension : 17.2 (W) x 4.7 (D) x 1.7 (H) inch
- Net Weight : 7.04 lbs
- Packing dimension : 20.7 (W) x 9.4 (D) x 3.14 (H) inch
- PDU gross weight : 8.36 lbs