


Floor standing enclosures


Mild steel flange mount disconnect MCF

MOUNTING INSTRUCTIONS

7697-0502-31 REV.2



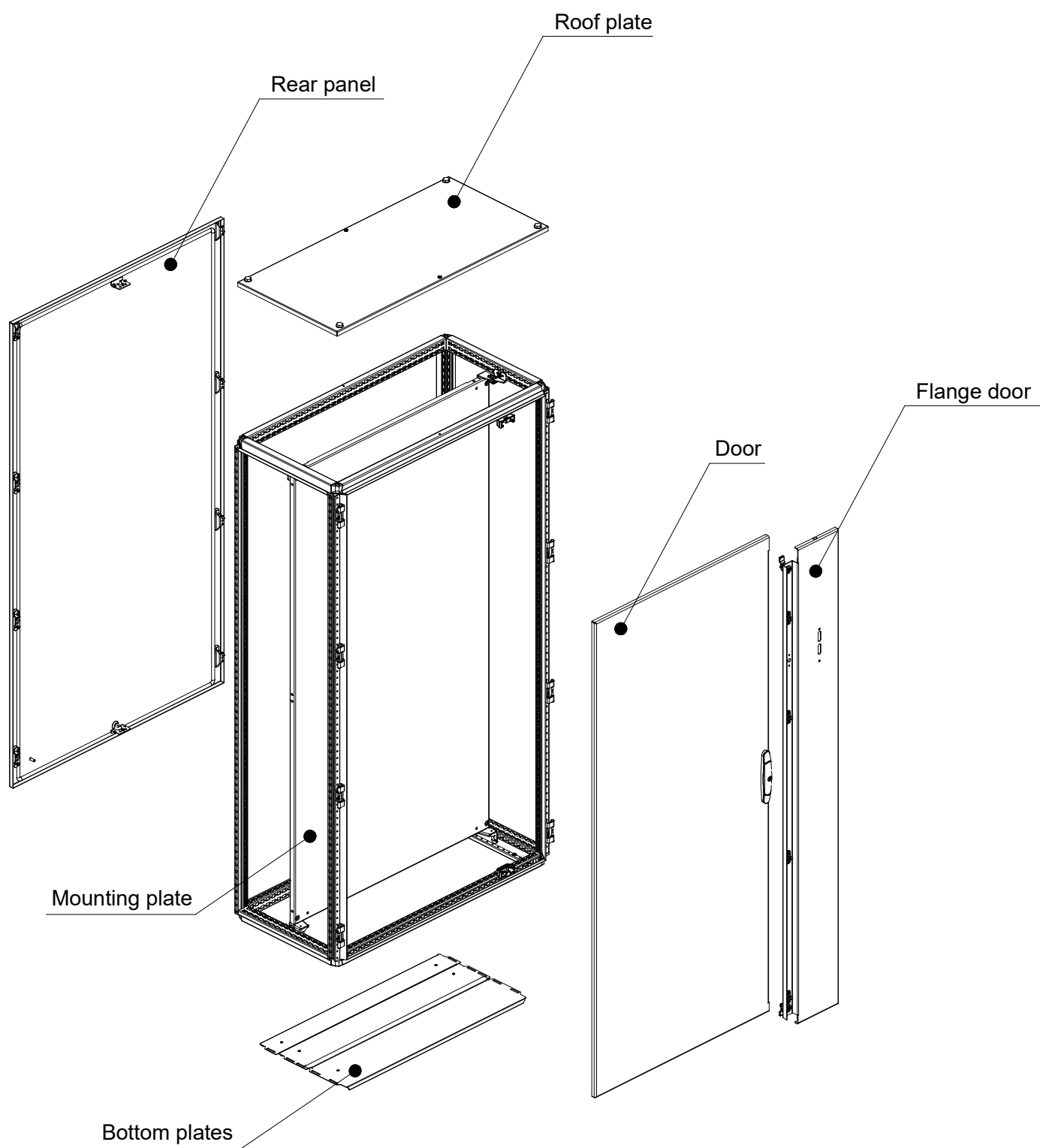


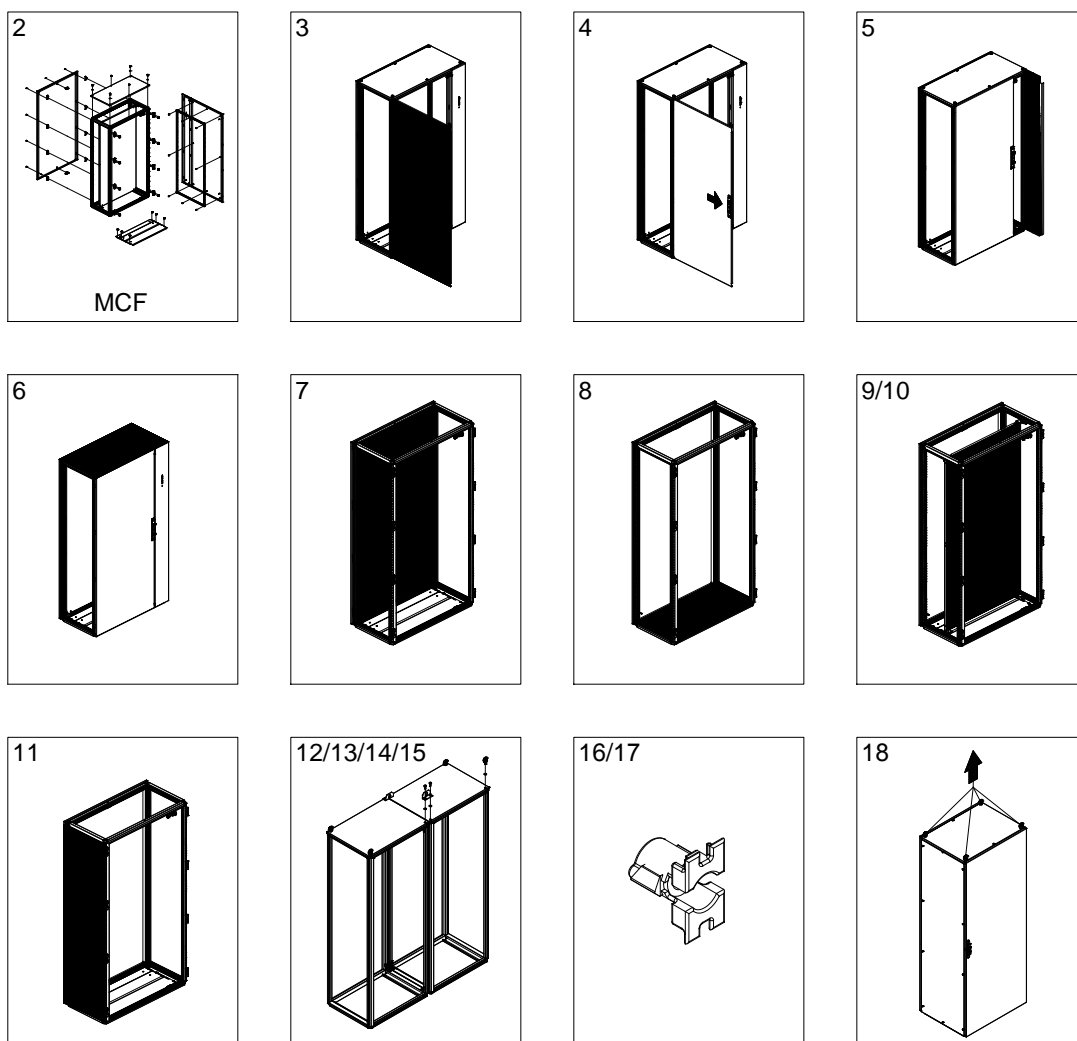

WARNING: When mounting on or over a combustible surface, a floor plate of at least 1.43 mm galvanized or 1.6 mm uncoated steel extended at least 150 mm beyond the equipment on all sides must be installed.

WARNING: In order to maintain the environmental integrity of the enclosure, devices with the same environmental ratings shall be used to close openings in customized enclosure.








MCF

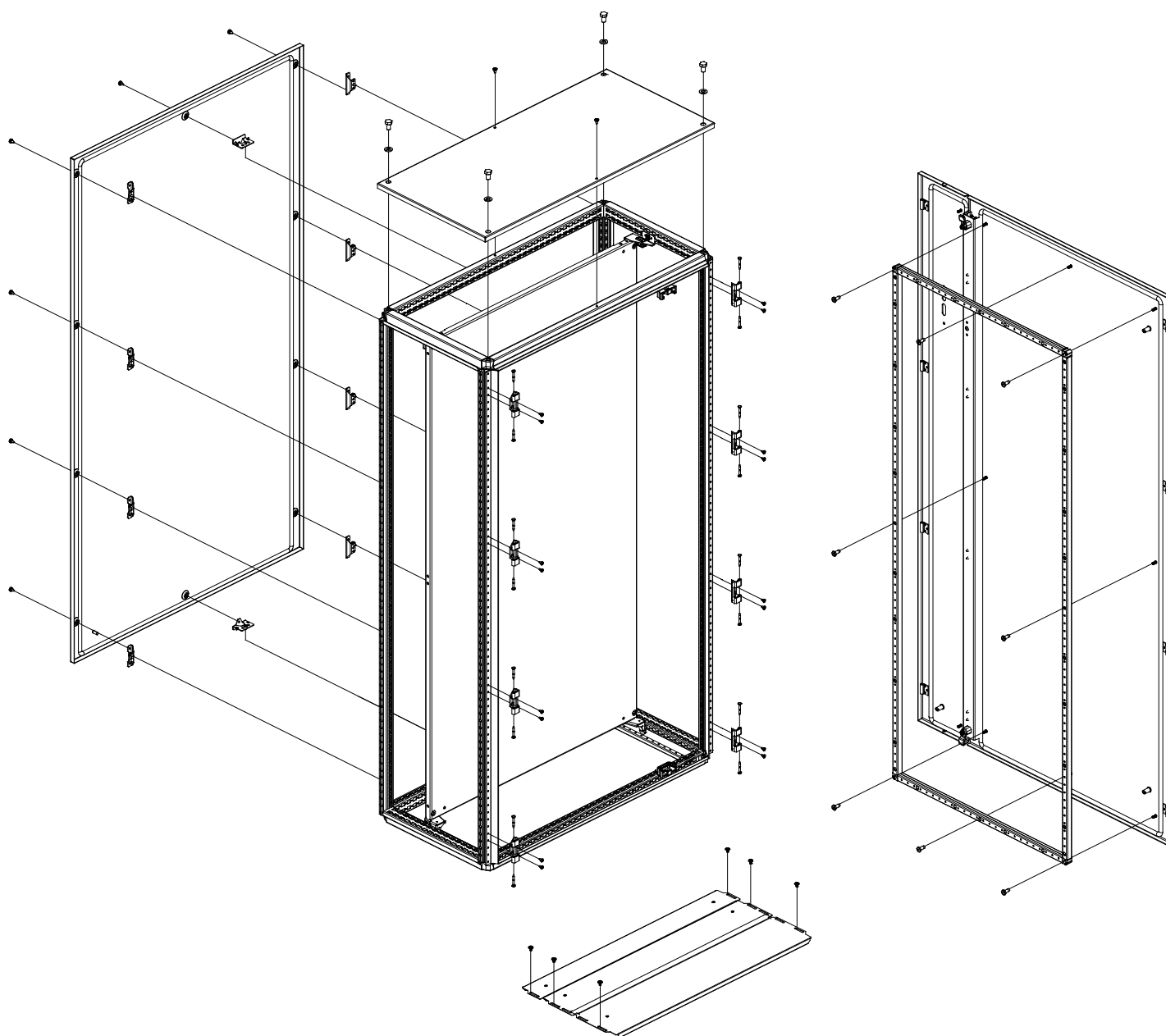



COMBINABLE ENCLOSURE





H	A
1800	525
2000	625

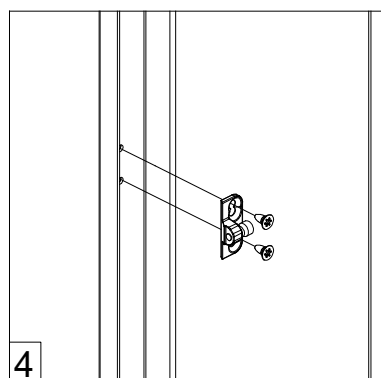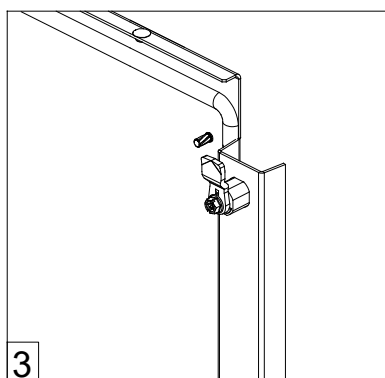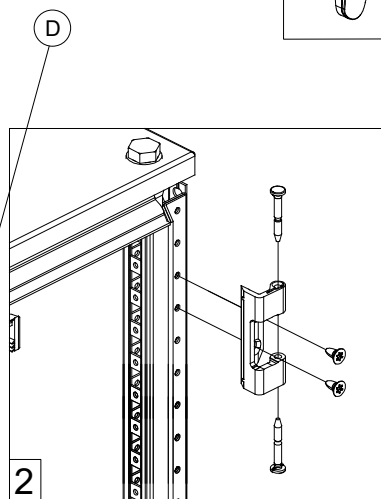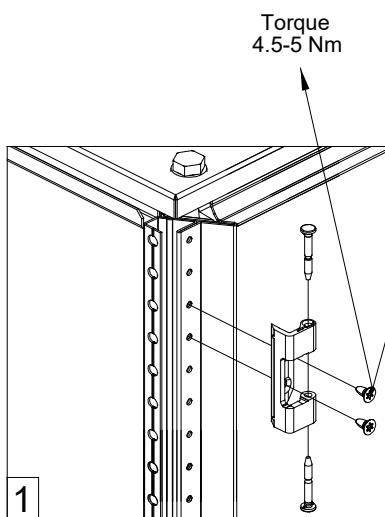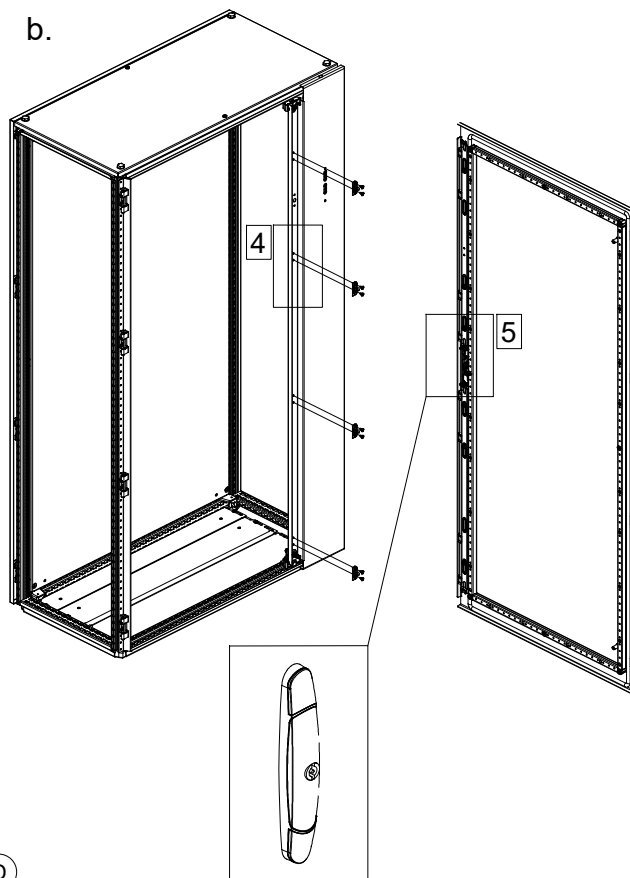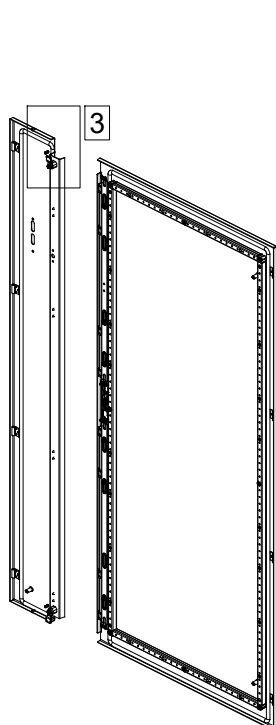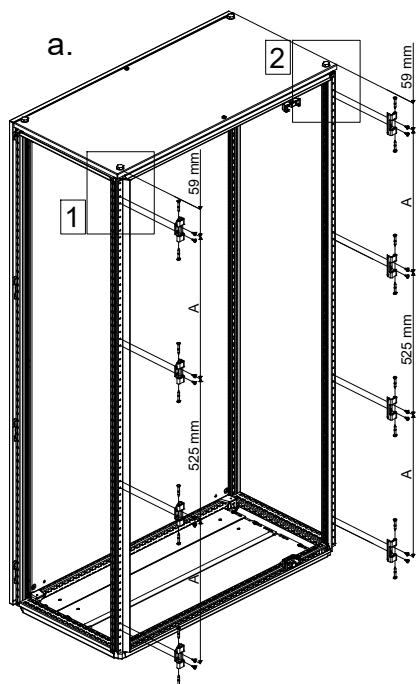






SW3

Ref.	Pic.	Qty.
A		2
B		4

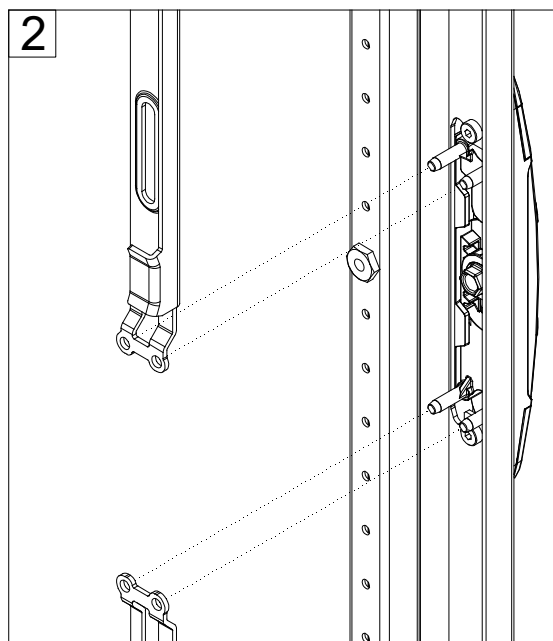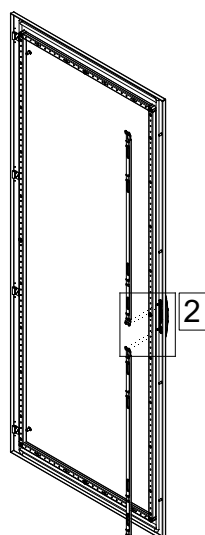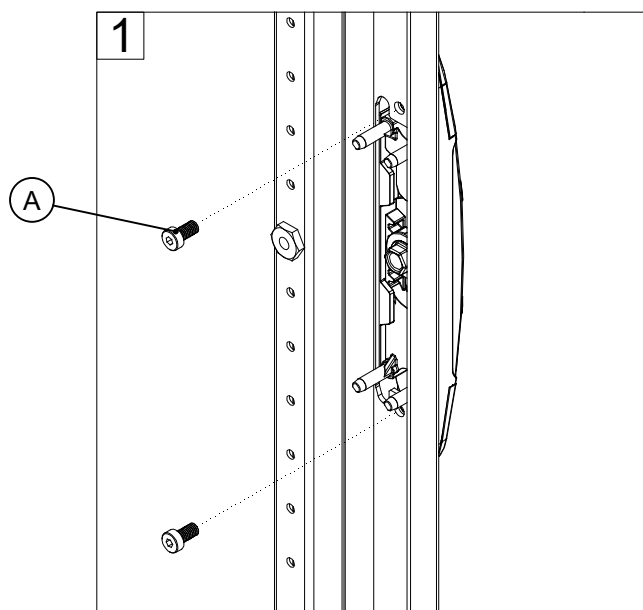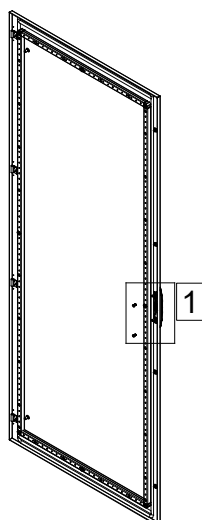

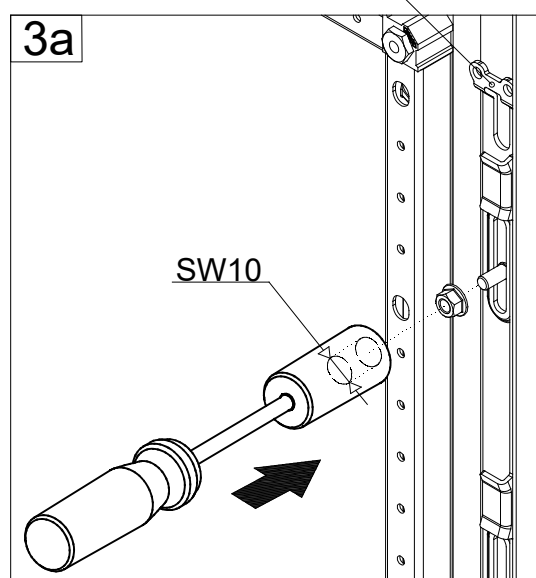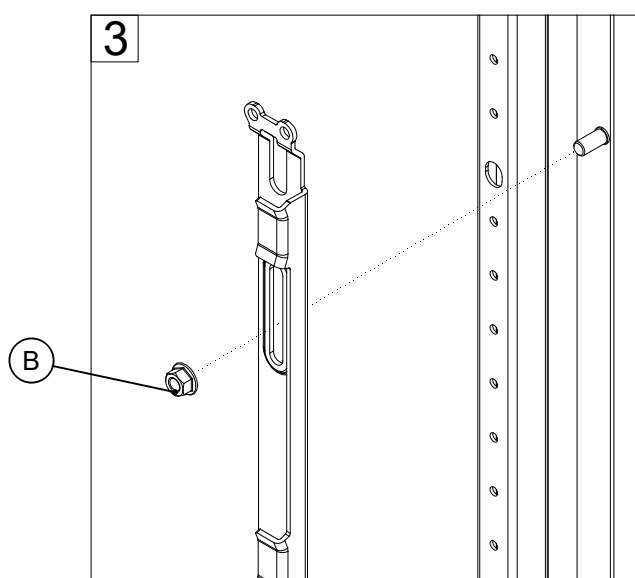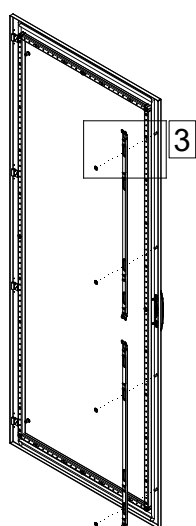





Metal Guider








MCF-Flange door

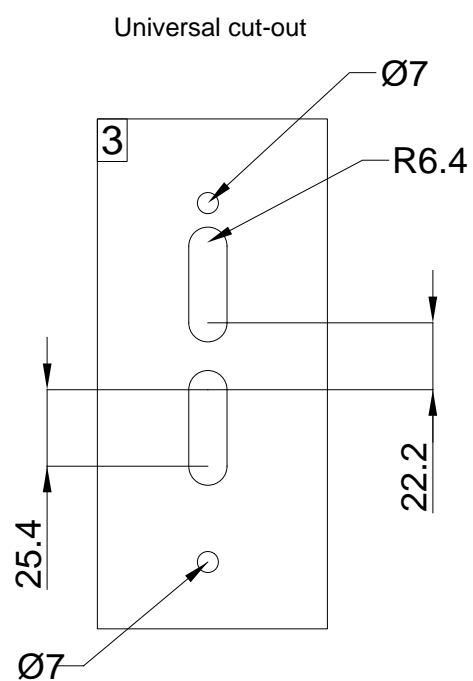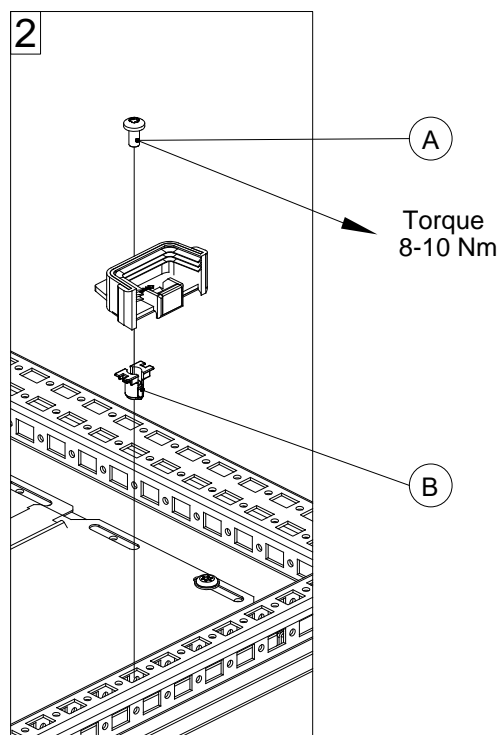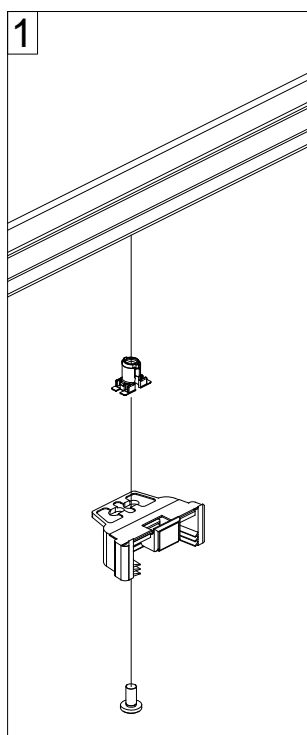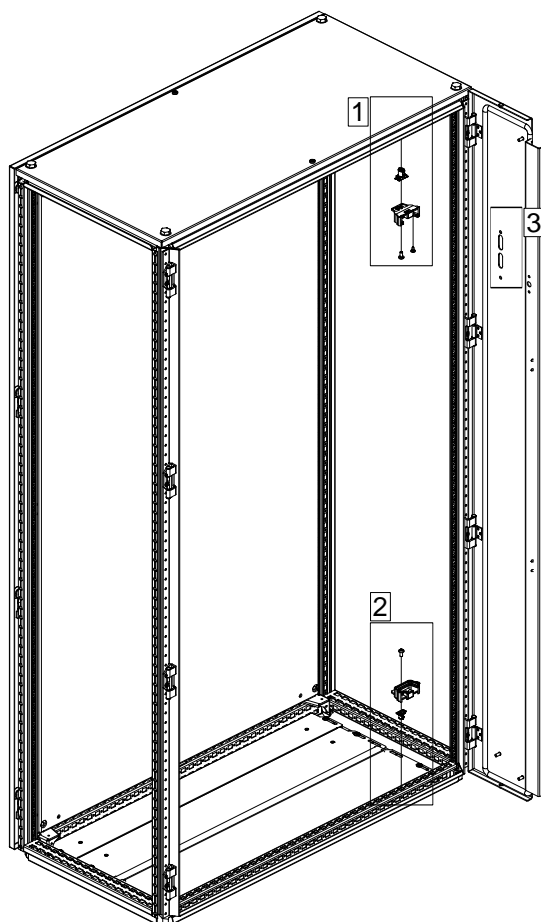
Ref.	Pic.	Qty.
A		2
B		2





MCF-Top Panel







Ref.	Pic.	Qty.
A	 M6x12	2
B	 M12x20	4
C	 M12	4

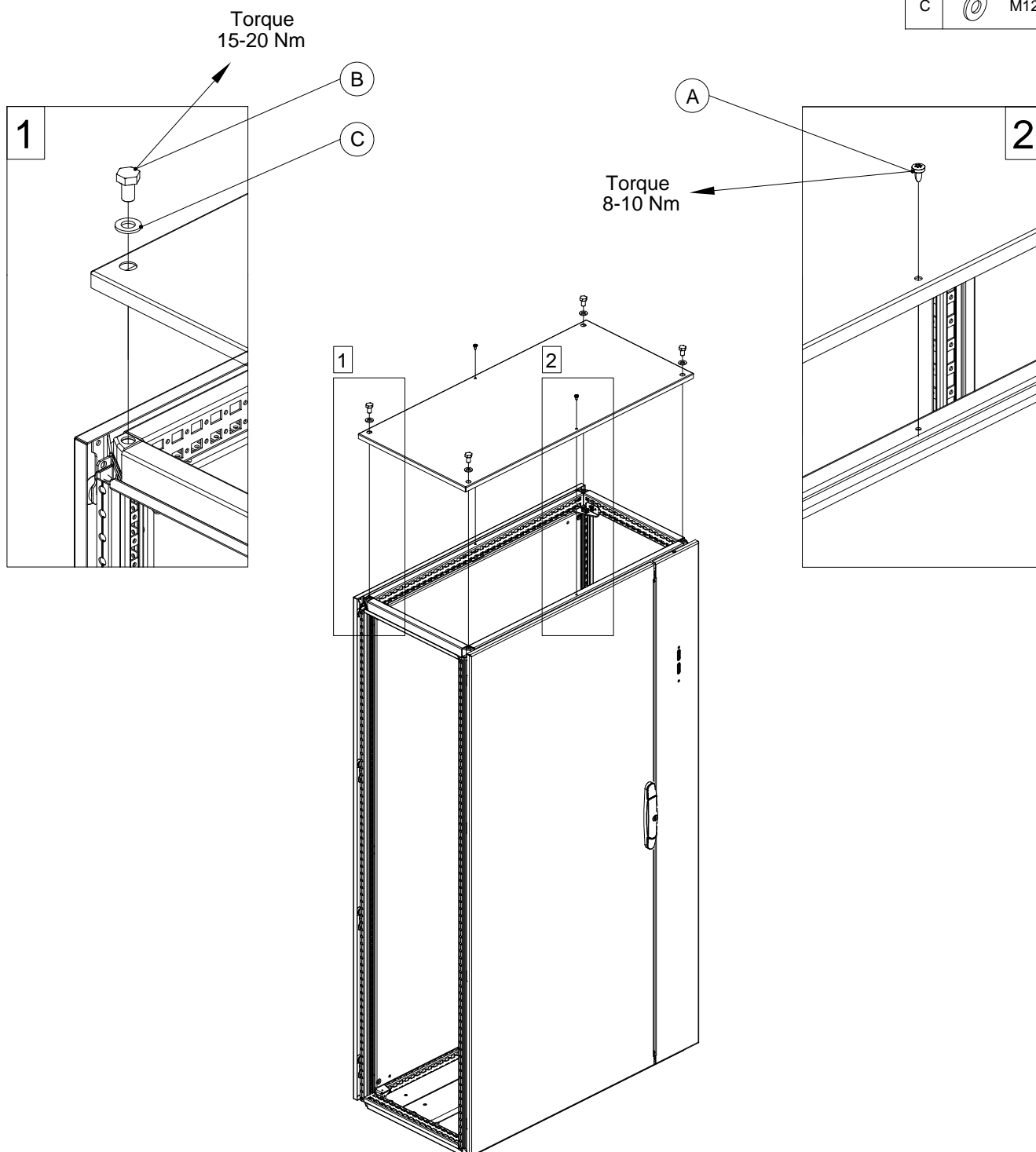



MCF-Rear Panel

Ref.	Pic.	W (mm)	<1000	≥1000
A			-	2
B			22	24

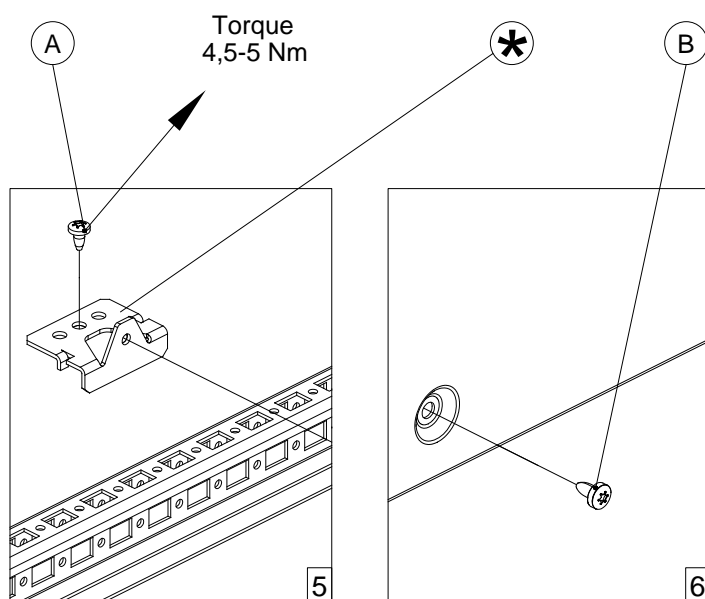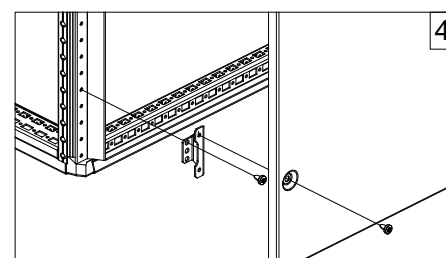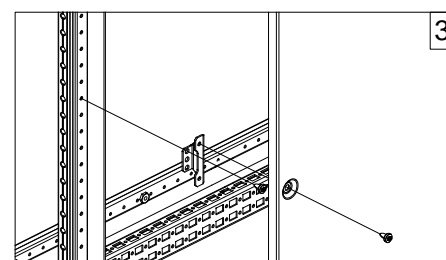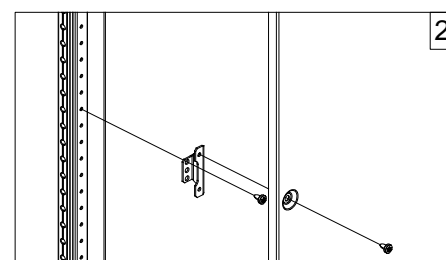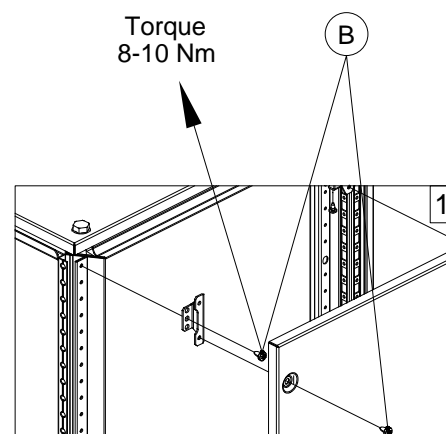
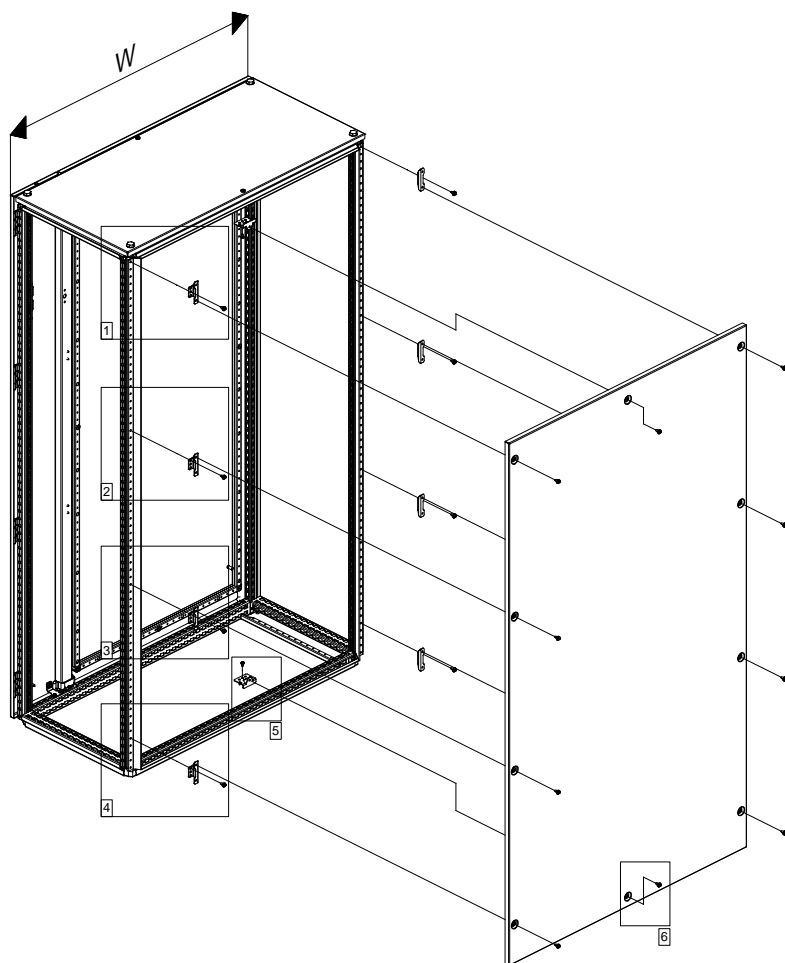


* - Used on enclosures 1000mm and 1200mm wide.




MCF

Ref.	Pic.	Qty.
A	St. 5.5x10	6
B		5

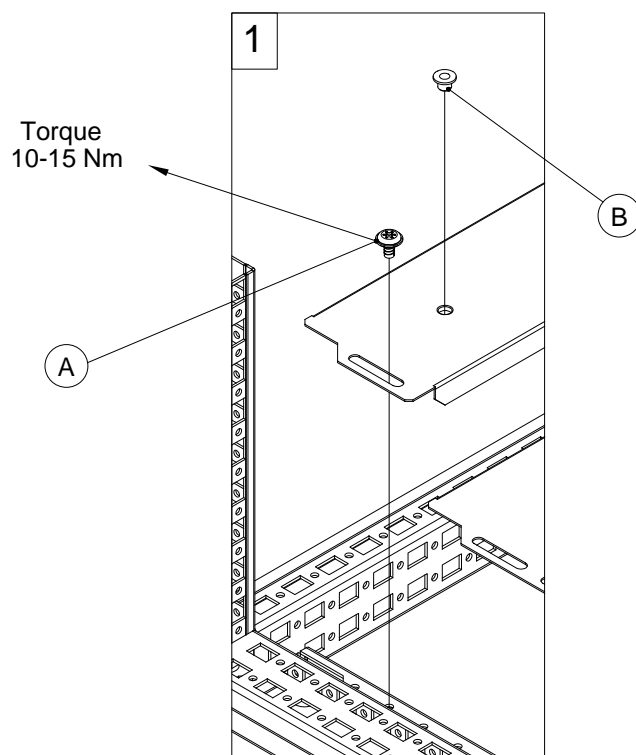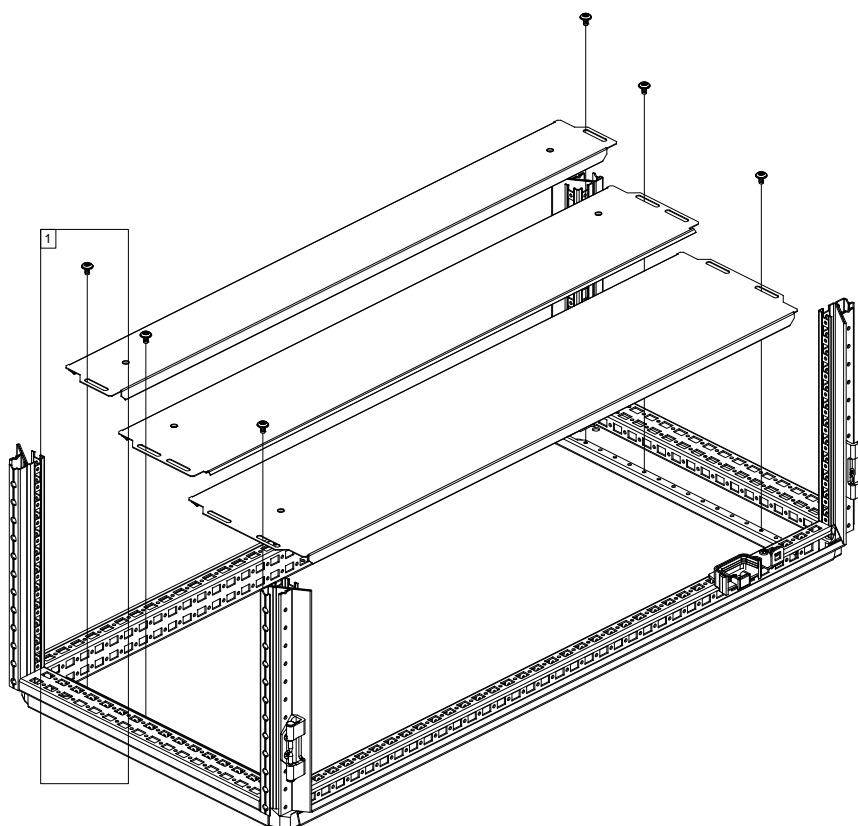




MOUNTING PLATE

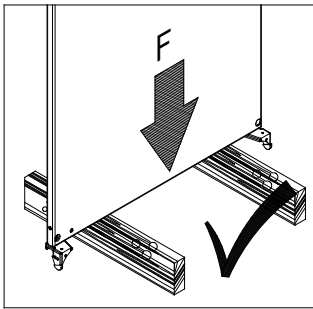


$F > 1000N$

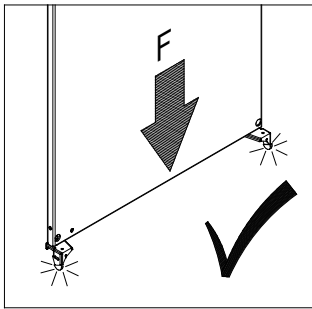








$F \leq 1000N$







Ref.	Pic.	Qty.
A		2
B		2
C		2
D		1
E		1
F		1
G		1

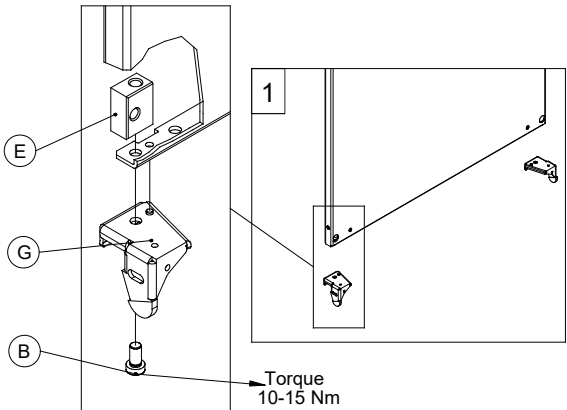

MOUNTING

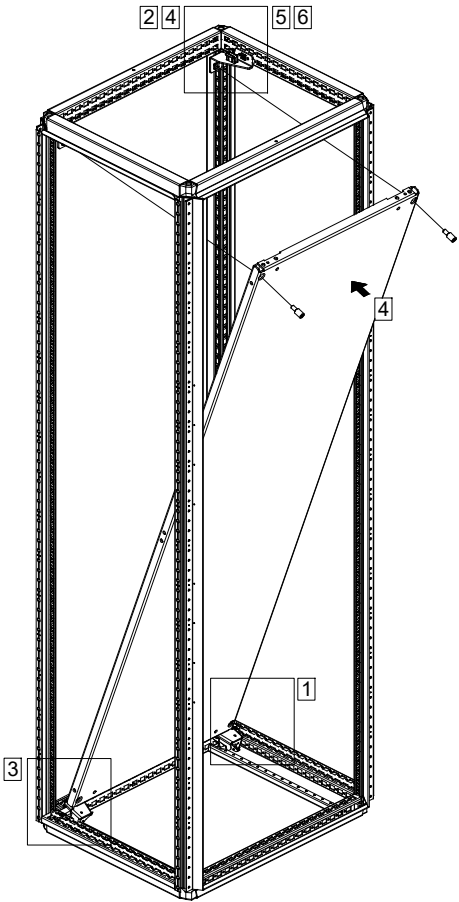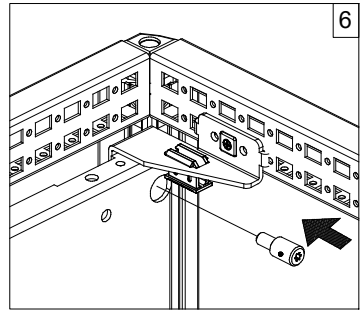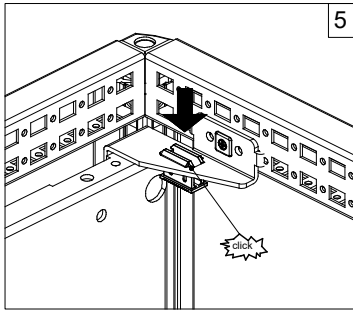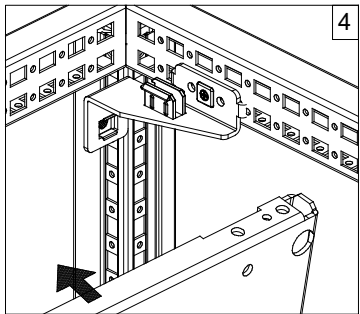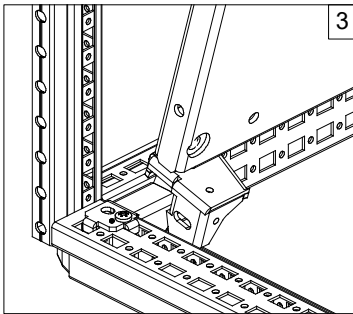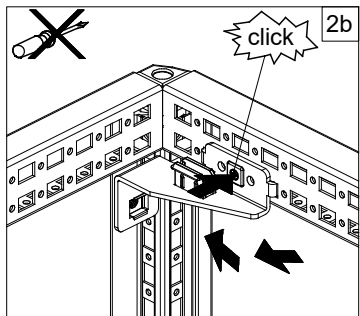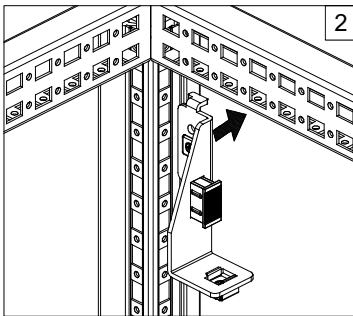



UNMOUNTING

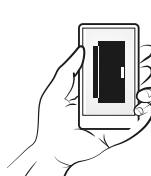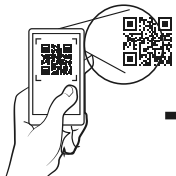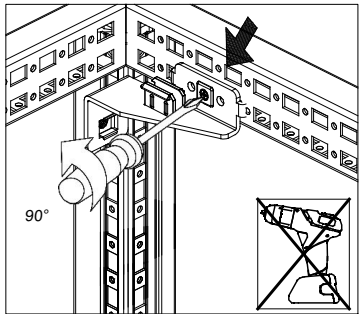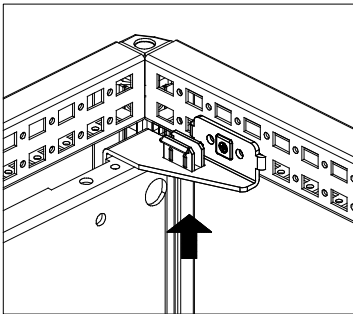









MPD02

Ref.	Pic.	Qty.
A	M5X12	2
B	Bottom left	1
C	Bottom right	1




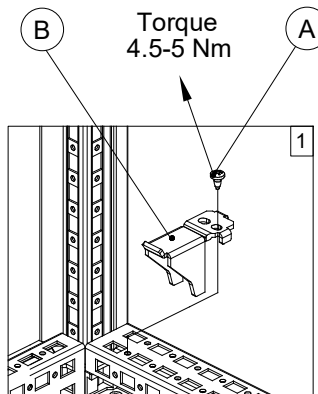
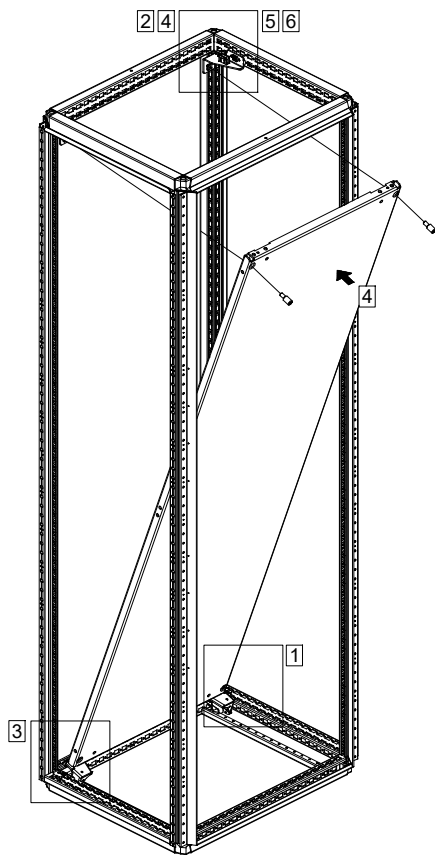


MOUNTING

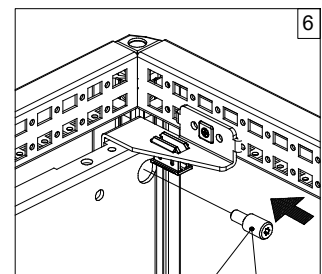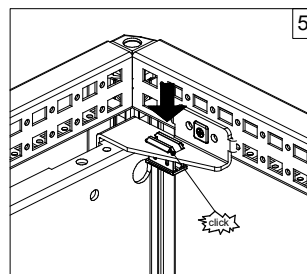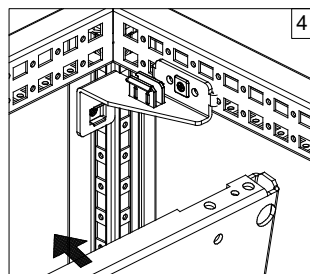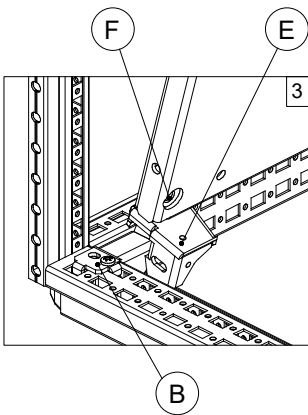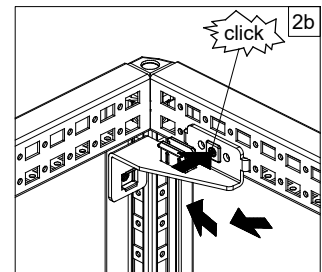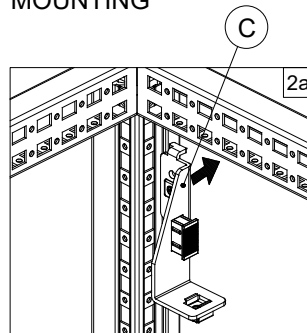

D Torque 4.5-5 Nm




UNMOUNTING

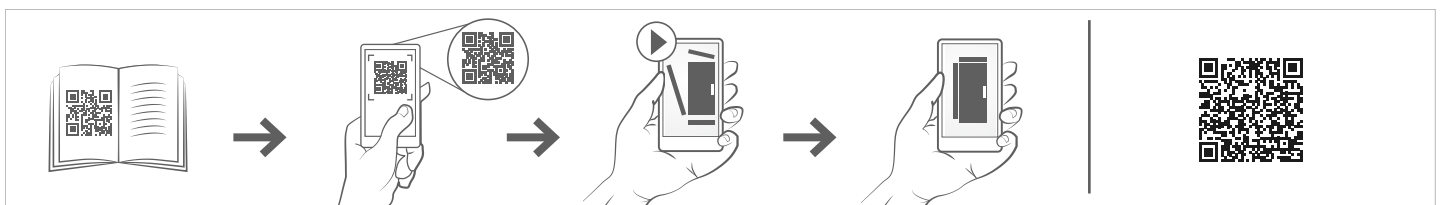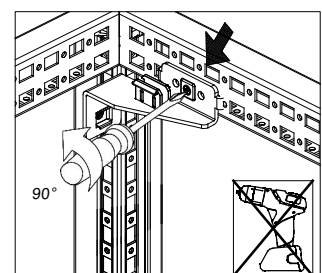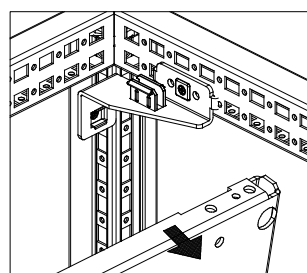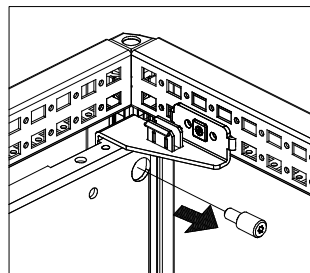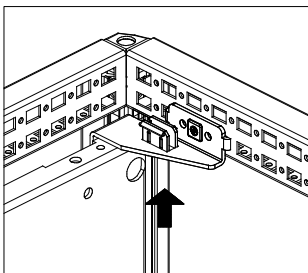






SPM


Ref.	Pic.	Qty.
A		M6x12 0/1
B		M6x16 6/8/9
C		M6 6/8/9
D		2

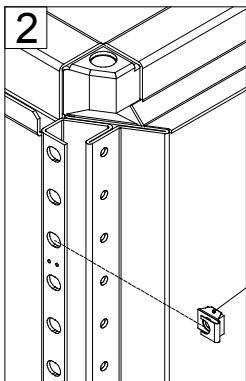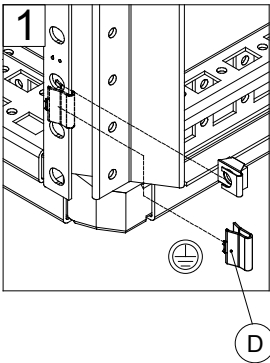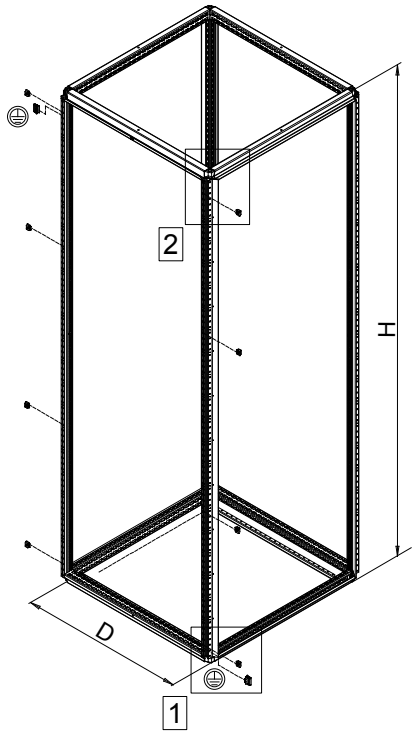


H	R	S
1800	525	575
2000	625	575

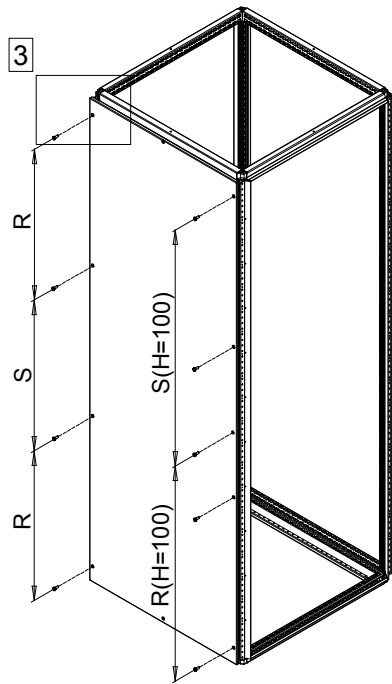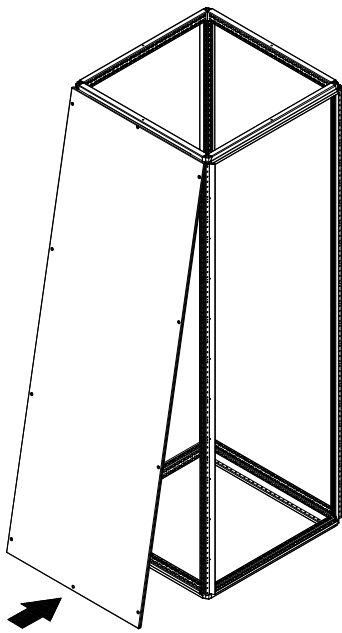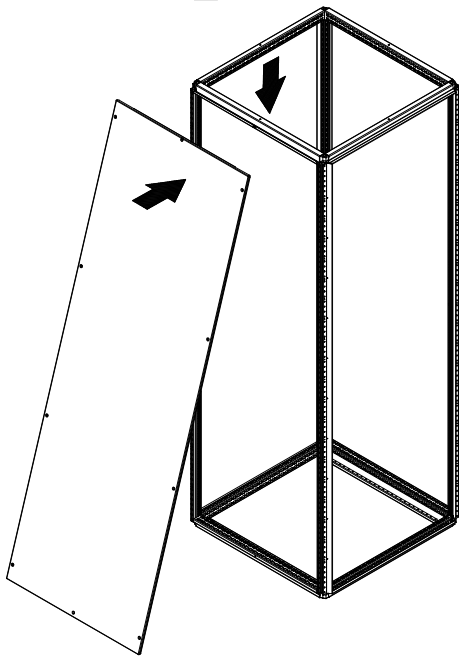

* - Used only on enclosures 800mm deep and above.






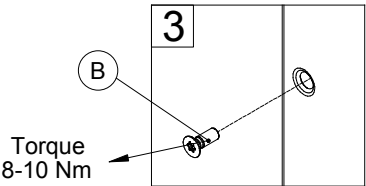


Torque
8-10 Nm

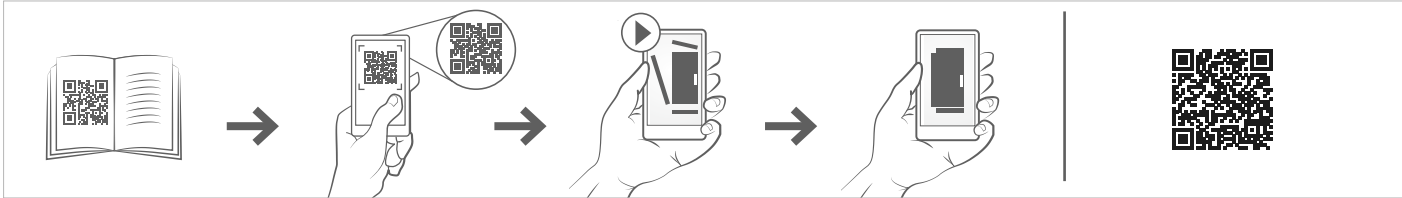







Ref.	Pic.	Qty.
A		8
B		6
C		12
D		6

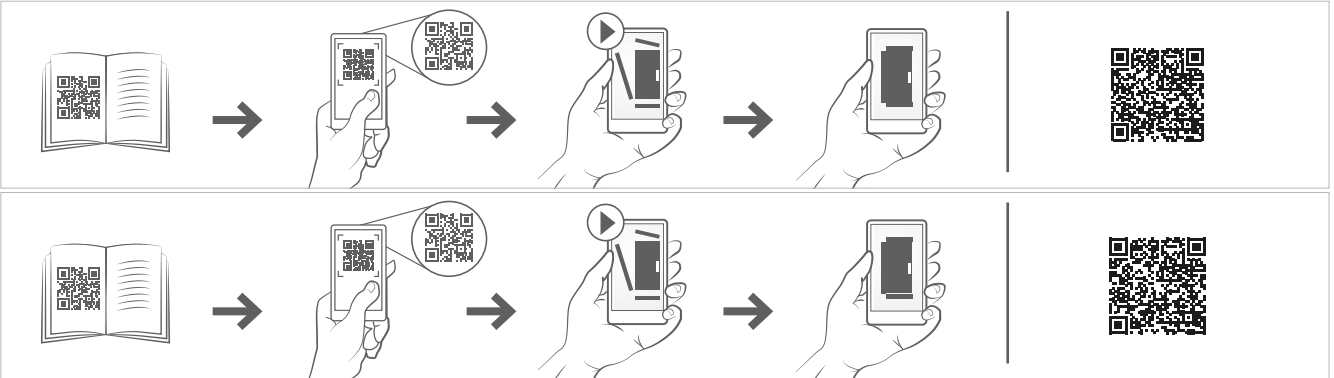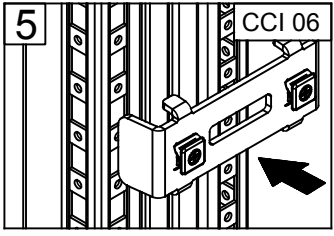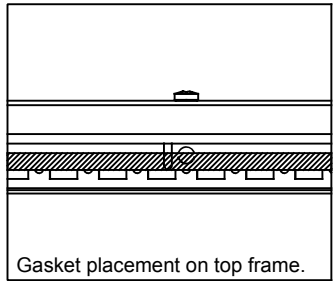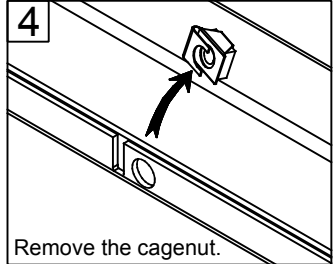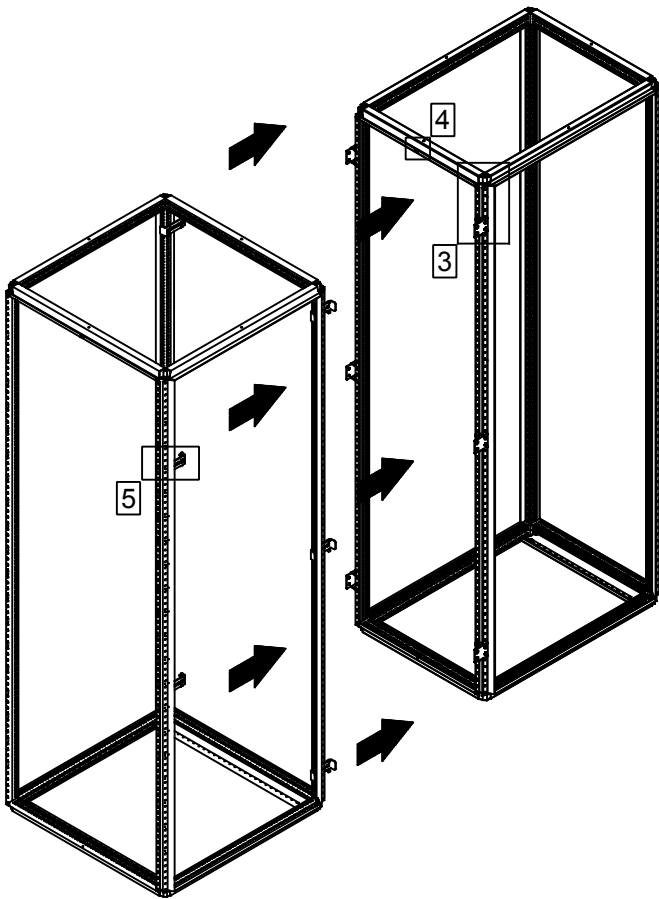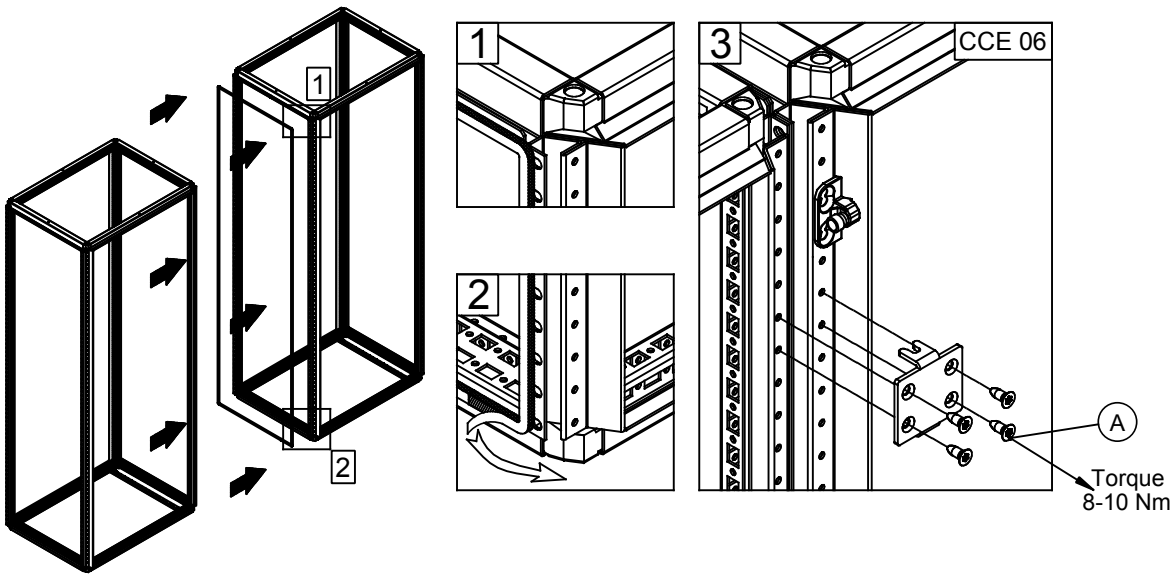



Ref.	Pic.	Qty.
A		4
B		4
C		2
D		4









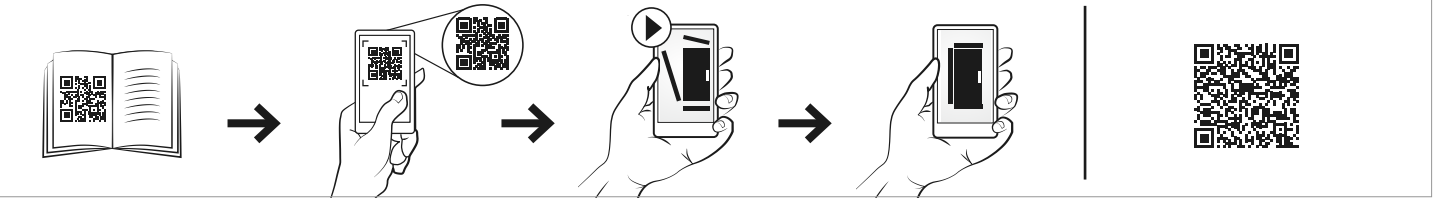
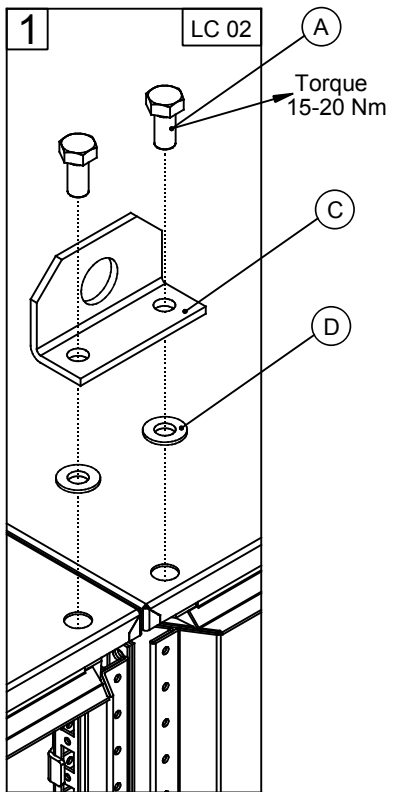
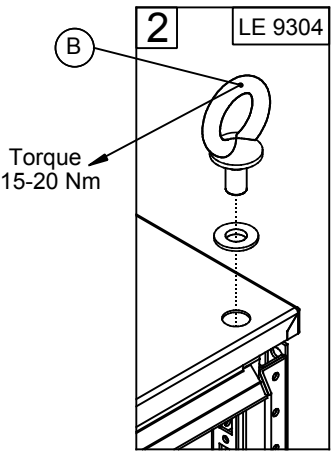
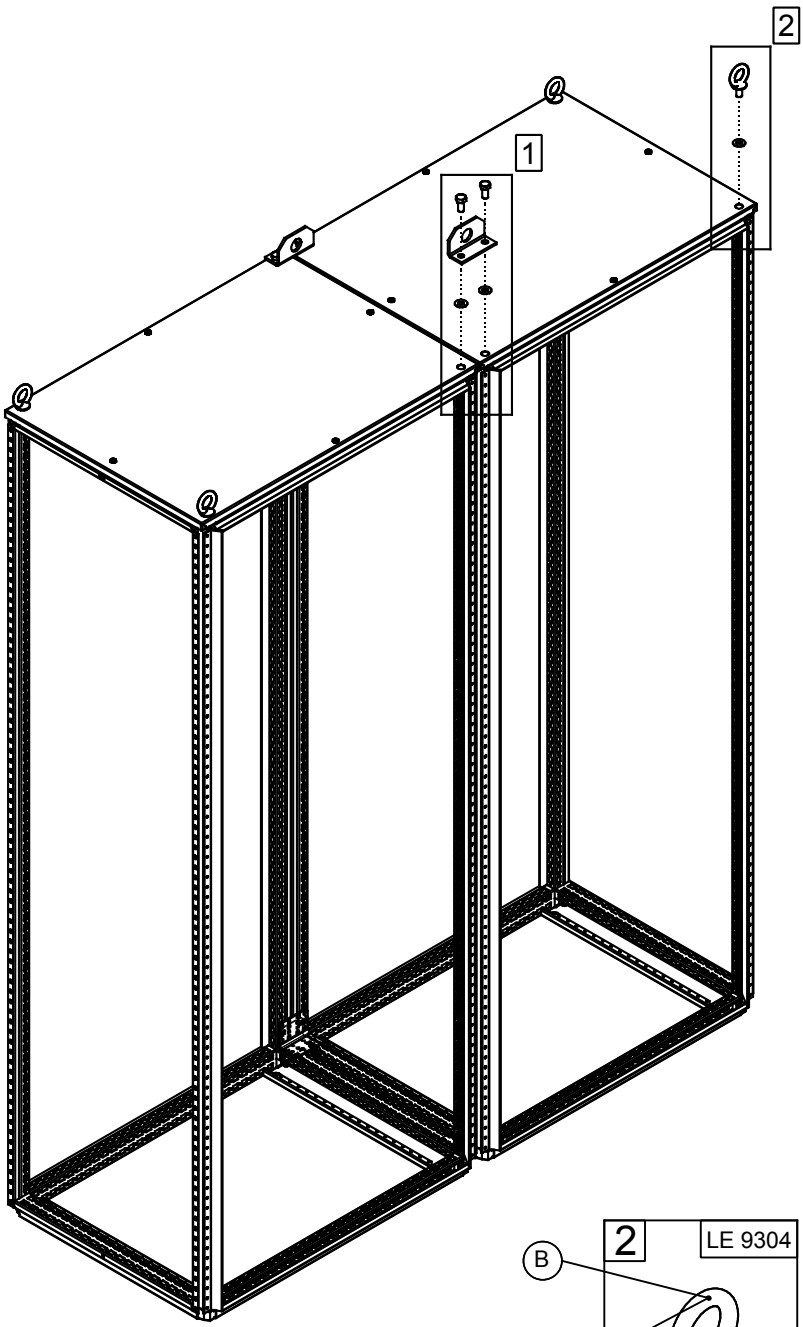




CCM 04

Ref.	Pic.	Qty.
A		4
B		8



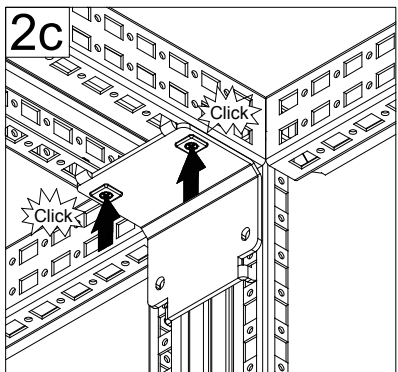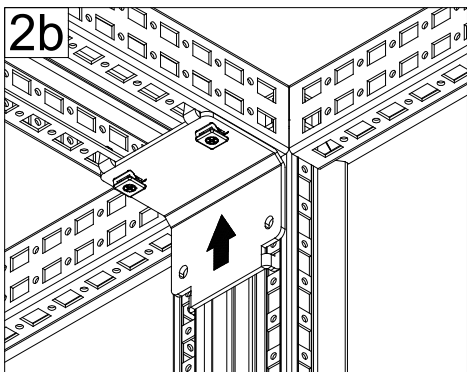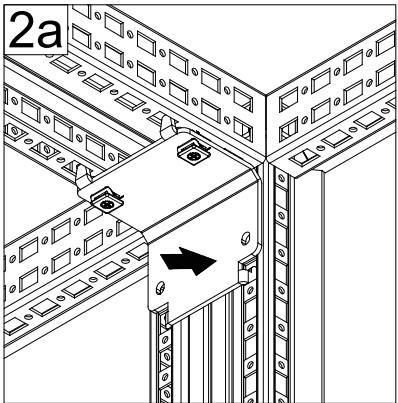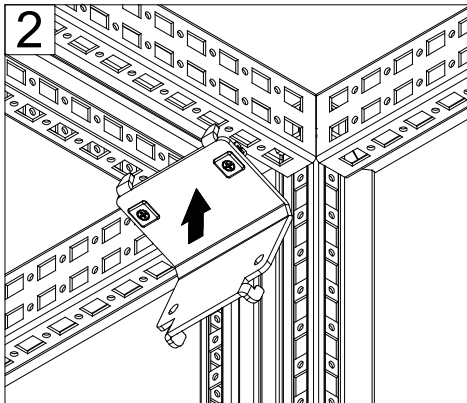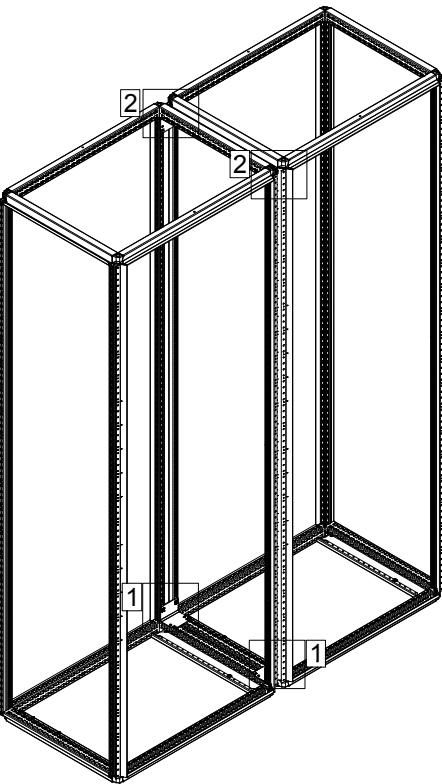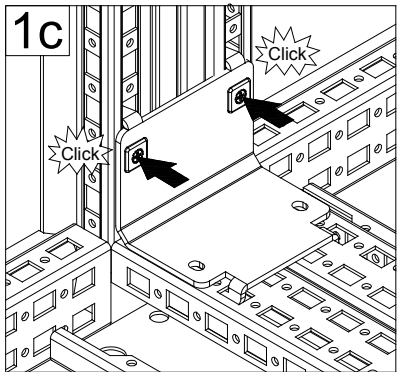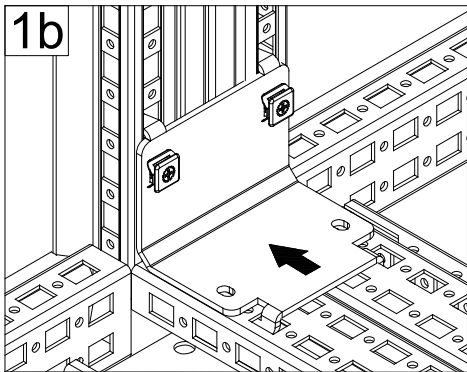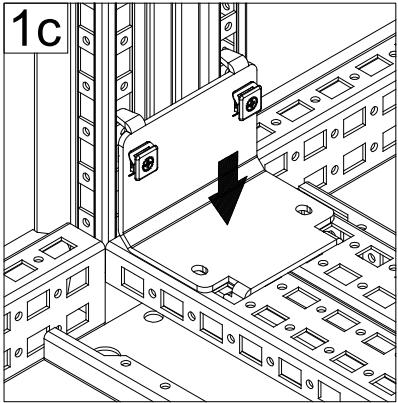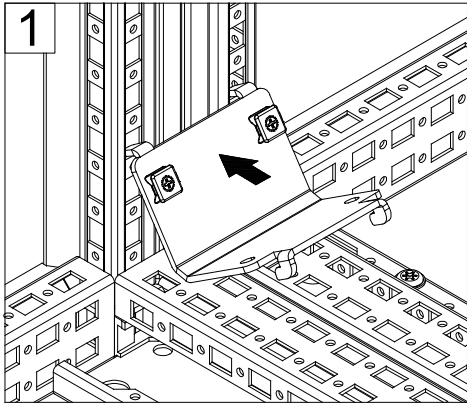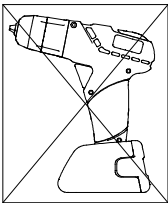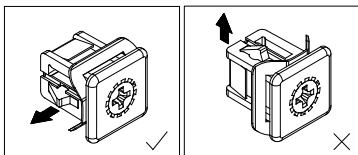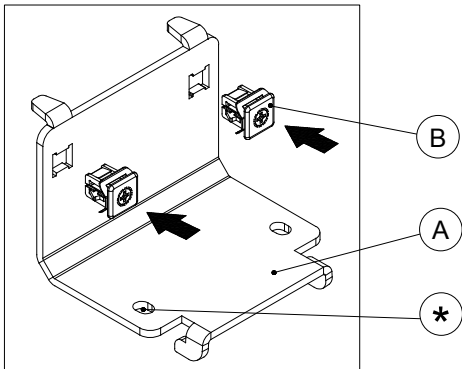

MOUNTING












Note: It is mandatory for all four brackets to be installed at all four corners !


★ The fixation holes can be used to better fix the bracket to the frame,using cage nuts and screws !



MPF

Ref.	Pic.	Qty.
A		1
B		1
C		2
D		2

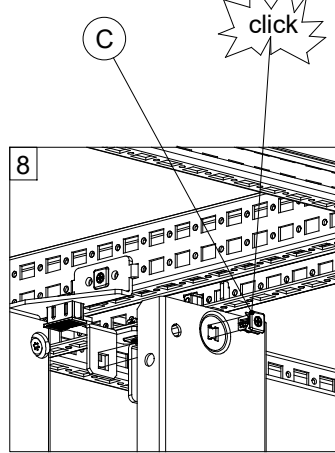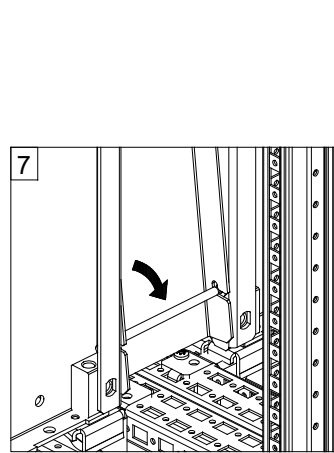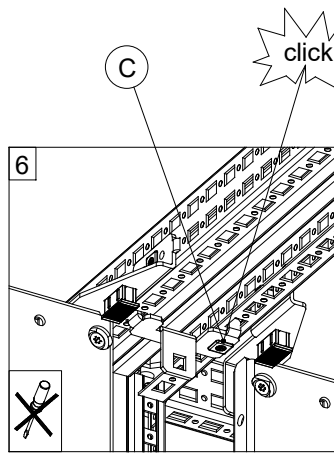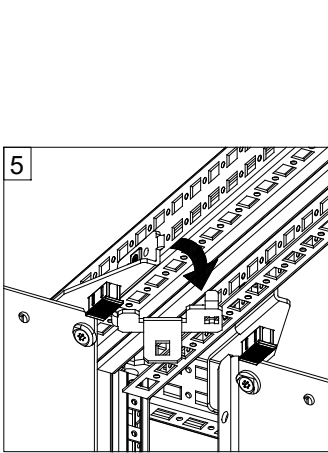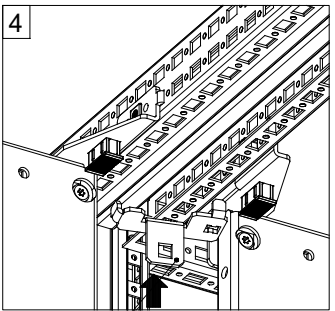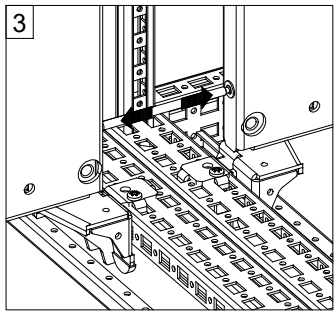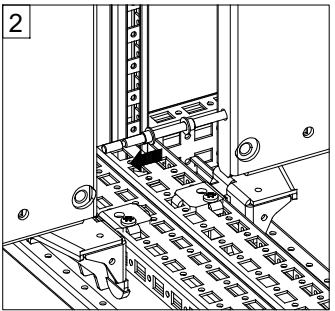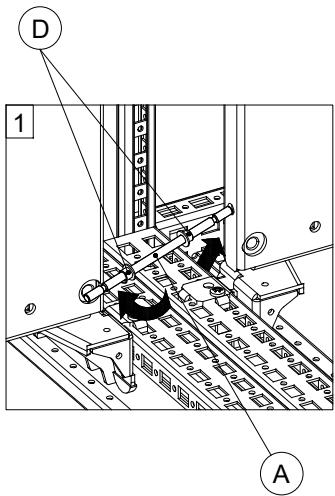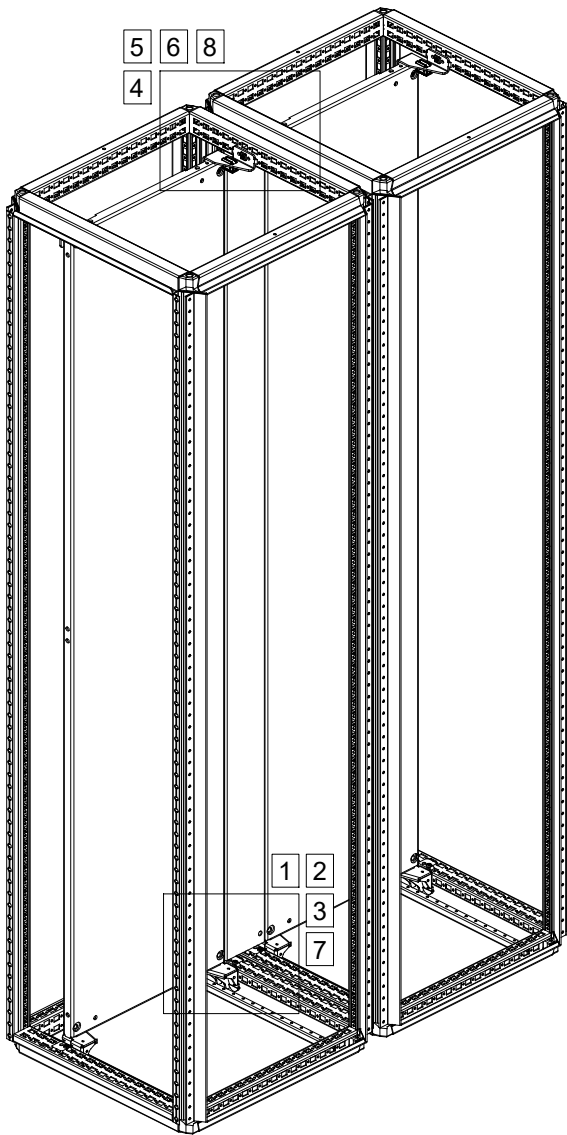


Back view

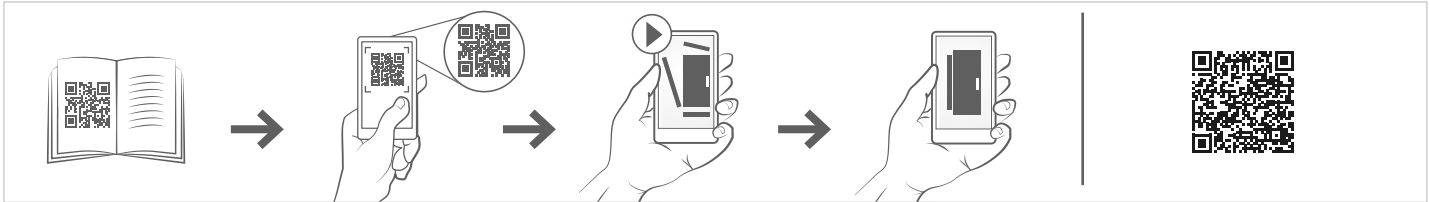

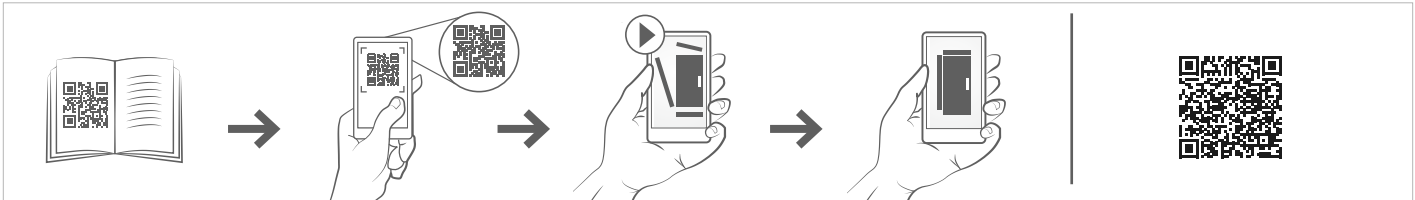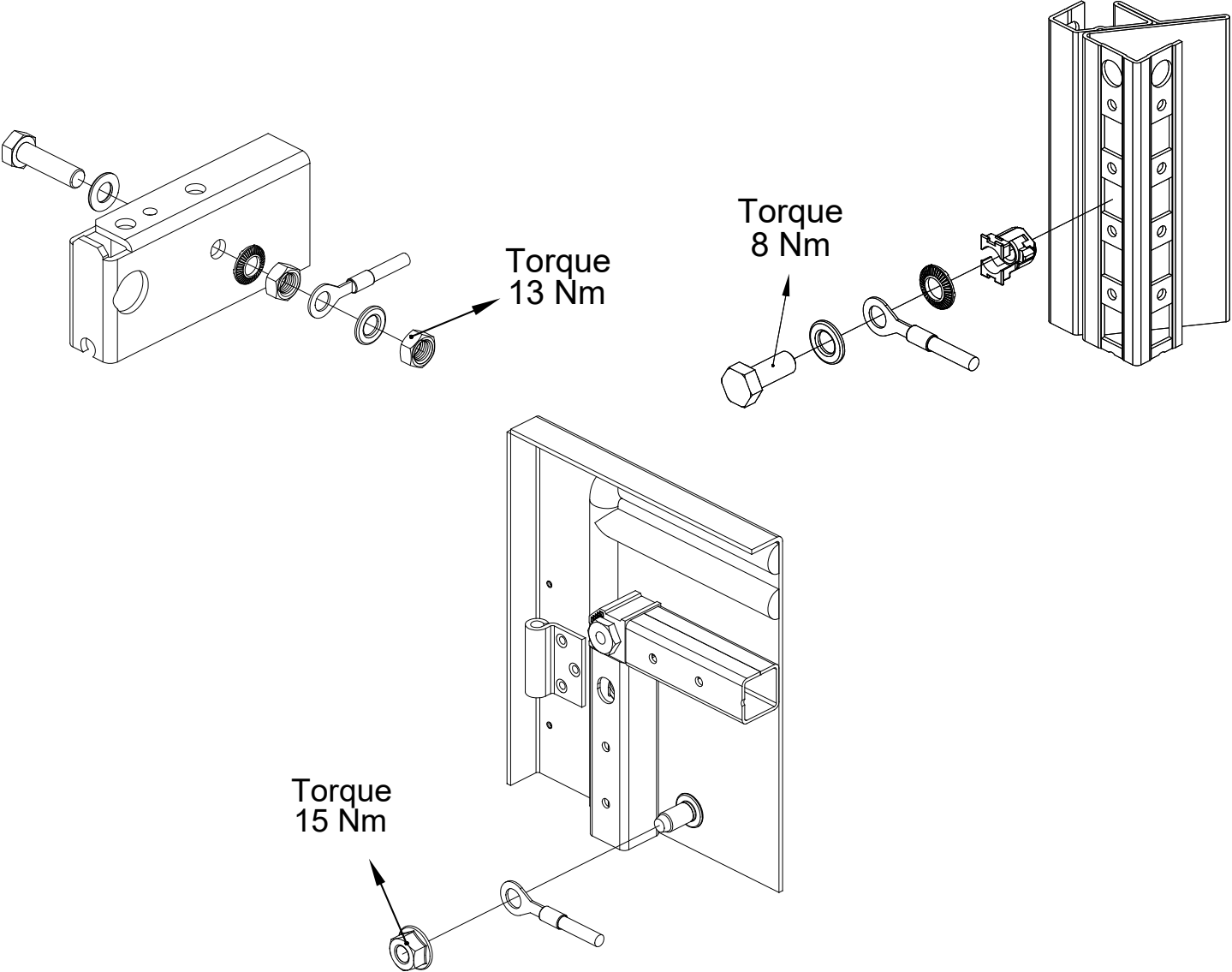

CNM

 Ref.	Pic.	Qty.
A	 M6 M8	1

