
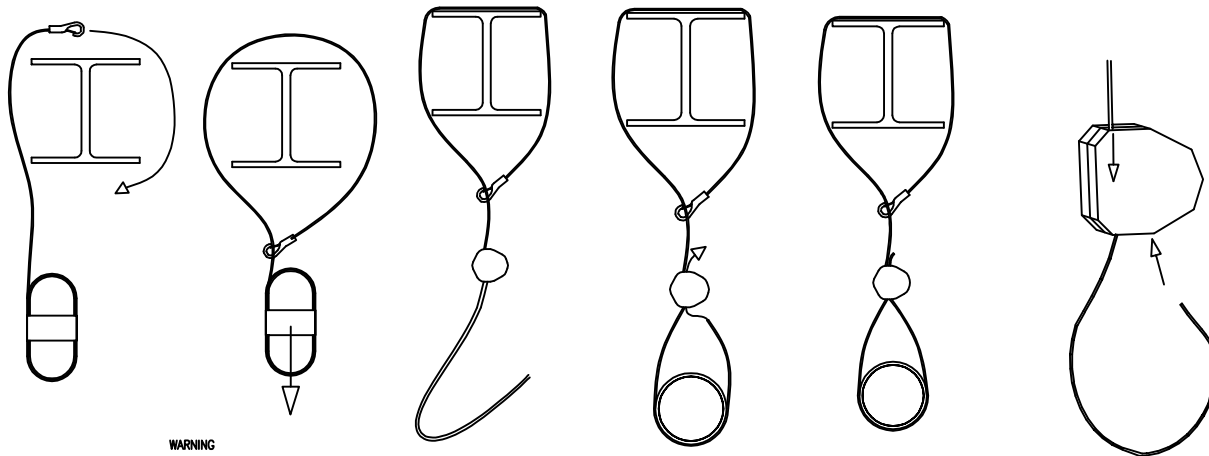
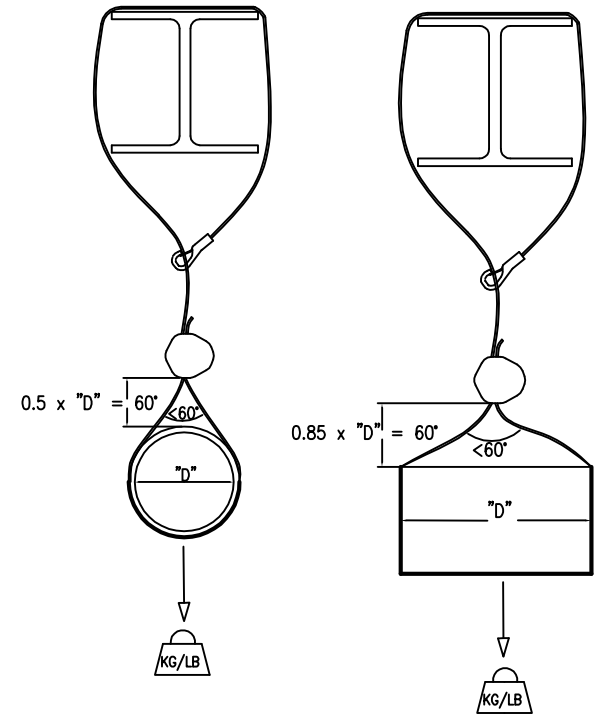


CADDY® SPEED LINK

US PART No	PART DESCRIPTION EUROPE	EUROPE PART No	CABLE ϕ	CABLE LENGTH [METERS/FEET]	LOAD [KG/LB]	
SLD2L1	SL 2/1	195800	2mm/.079"	1m/3.3ft	45kg/100lbs	
SLD2L2	SL 2/2	195805	2mm/.079"	2m/6.6ft	45kg/100lbs	
SLD2L3	SL 2/3	195810	2mm/.079"	3m/9.9ft	45kg/100lbs	
SLD2L5	SL 2/5	195815	2mm/.079"	5m/16.4ft	45kg/100lbs	
SLD2L7	SL 2/7	196019	2mm/.079"	7m/23.0ft	45kg/100lbs	
SLD2L10	SL 2/10	195820	2mm/.079"	10m/32.8ft	45kg/100lbs	
SLD3L1	SL 3/1	195825	3mm/.118"	1m/3.3ft	90kg/200lbs	
SLD3L2	SL 3/2	195830	3mm/.118"	2m/6.6ft	90kg/200lbs	
SLD3L3	SL 3/3	195835	3mm/.118"	3m/9.9ft	90kg/200lbs	
SLD3L5	SL 3/5	195840	3mm/.118"	5m/16.4ft	90kg/200lbs	
SLD3L7	SL 3/7	196020	3mm/.118"	7m/23.0ft	90kg/200lbs	
SLD3L10	SL 3/10	195845	3mm/.118"	10m/32.8ft	90kg/200lbs	
SLD3L2SS	SL 3/2SS	195831	3mm/.118"	2m/6.6ft	90kg/200lbs	
SLD3L3SS	SL 3/3SS	195836	3mm/.118"	3m/9.9ft	90kg/200lbs	

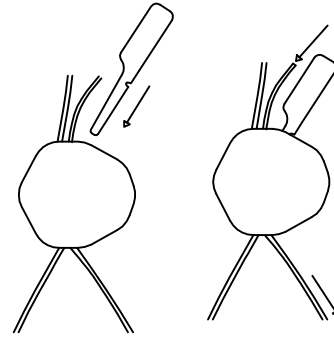

WARNING

1. ERICO products shall be installed and used only as indicated in ERICO product instruction sheets and training materials. Instruction sheets are available at www.ericoint.com and from your ERICO customer service representative.
2. ERICO products must never be used for a purpose other than the purpose for which they were designed or in a manner that exceeds specified load ratings.
3. All instructions must be completely followed to ensure proper and safe installation and performance.
4. Improper installation, misuse, misapplication or other failure to completely follow ERICO's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death.
5. Products that are manufactured using spring steel components shall be used only in a non-corrosive indoor environment.
6. All pipe supports, hangers, intermediate components and structural attachments must ONLY be used as described herein and are NEVER to be used for any other purpose.

NOTE: All load ratings are for static conditions and do not account for dynamic loading such as wind, water or seismic loads, unless otherwise noted.

The customer is responsible for:

- a. Conformance to all governing codes.
- b. The integrity of structures to which the products are attached, including their capability of safely accepting the loads imposed, as evaluated by a qualified engineer.
- c. Using appropriate industry standard hardware as noted above.

SAFETY INSTRUCTIONS: All governing codes and regulations and those required by the job site must be observed. Always use appropriate safety equipment such as eye protection, hard hat, and gloves as appropriate to the application.

CADDY, CADWELD, CRITEC, ERICO, ERIFLEX, ERITECH and LENTON are registered trademarks of ERICO International Corporation.



TECHNICAL SUPPORT:
www.erico.com


IS40_4

1 of 2

© 2008 ERICO INTERNATIONAL CORPORATION



TOOLS & ACCESSORIES

US PART No	DESCRIPTION
SLWC	CADDY® SPEED LINK WIRE CUTTER
SLADCP	AIR DUCT CORNER PROTECTOR
SLEBM6	EYE BOLT METRIC M6 BY 30MM (1-3/16 INCHES)
SLEBM8	EYE BOLT METRIC M8 BY 40MM (1-9/16 INCHES)
SLLC250	LIGHT FIXTURE CLIP  22.75KG/50LBS ULTIMATE
SLEBWS	EYE BOLT WOOD SCREW H6 BY 60MM (2-3/8 INCHES)
SLWPT	WIRE INSULATION PROTECTION TUBE (25 METERS PER BOX)
SLADS	AIR DUCT SUPPORT
SL1214	CLIP .468 TO .562 MC/AC CABLE TO CADDY SPEED LINK WIRE
SL1518	CLIP .500 TO .718 MC/AC CABLE TO CADDY SPEED LINK WIRE

