


SABP181815GE

Medium ABS terminal box

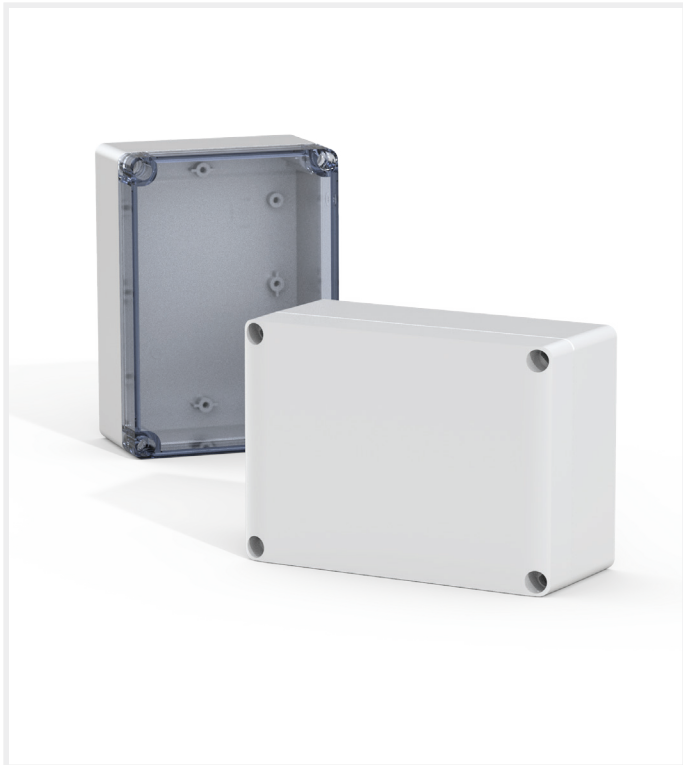

H	175
W	175
D	150
Inner depth (mm)	135.5
Weight (kg)	0.60
Item no.	SABP181815GE

Description: ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material: Body: ABS. Plain cover: ABS. Transparent cover: polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +60 °C.

Flammability: UL94 HB.

Protection: IP 66, 67 | IK 06 (-25 °C), IK 07 (+35 °C).

Finish: RAL 7035.

Delivery: Body, cover, cover screws manufactured from polyamide and mounting screws.

This small ABS terminal box range, SABP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The SABP range is well suited for demanding environments, since water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that unnecessary downtime.



IP 66,67 | IK 06/07